



Conditions


VIN: 34V
IO : 0mA

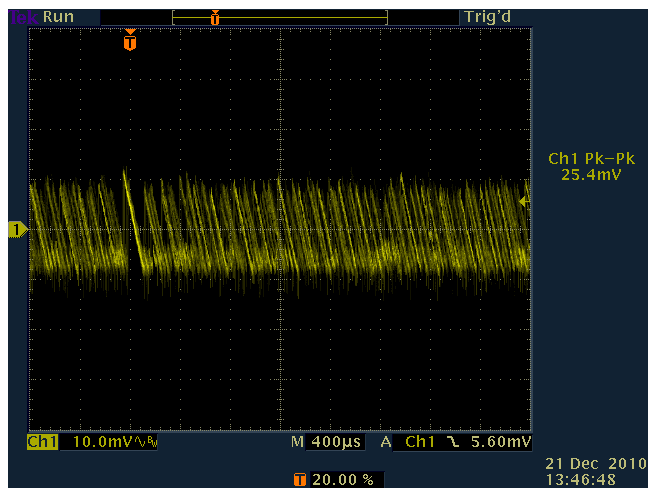


VIN: 34V
IO : 50mA

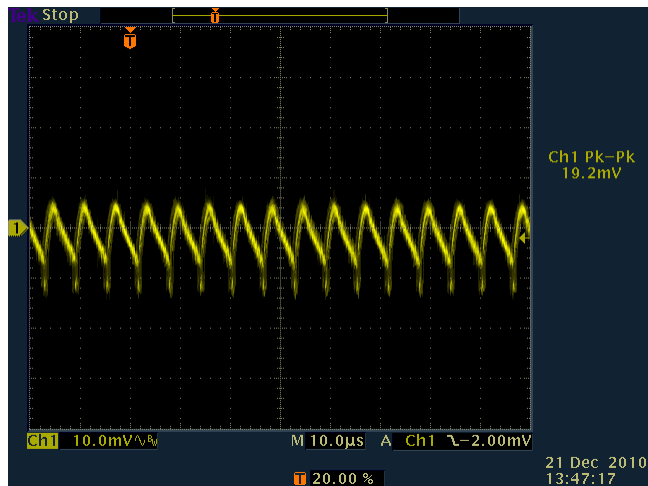


VIN: 34V
IO : 100mA

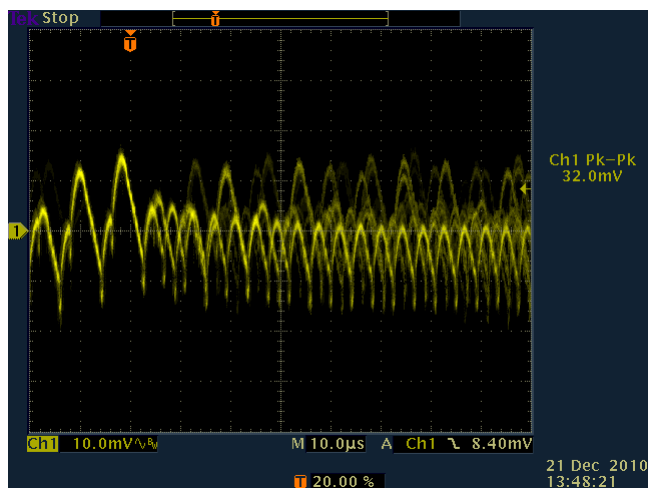


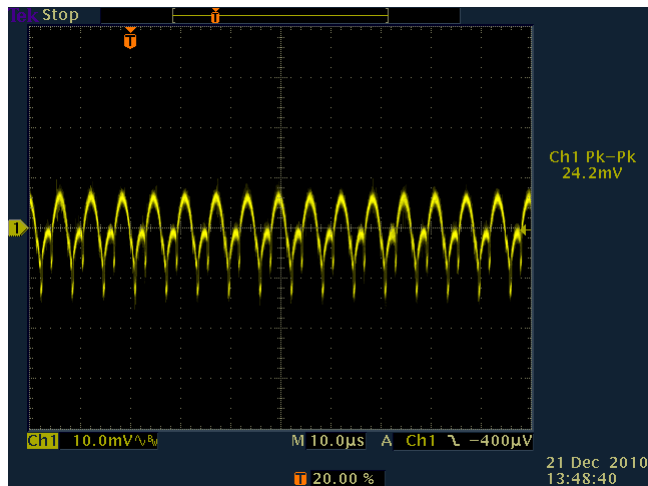


VIN: 34V
IO : 150mA

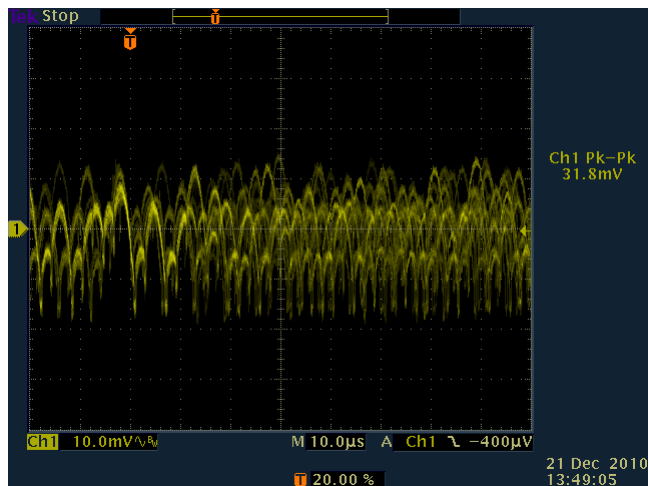


VIN: 34V
IO : 200mA

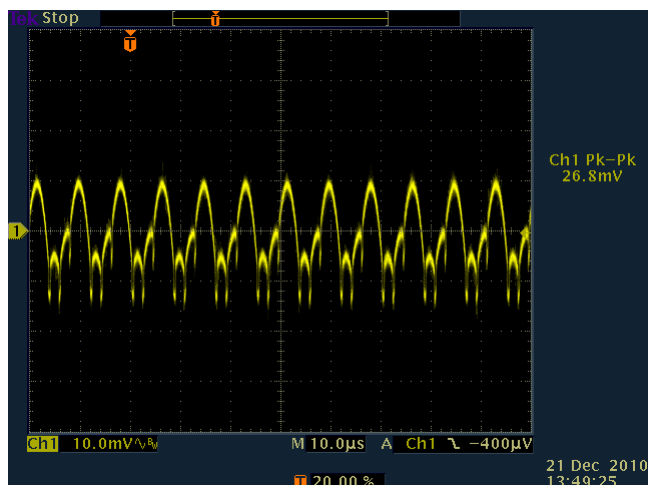


VIN: 34V
IO : 250mA

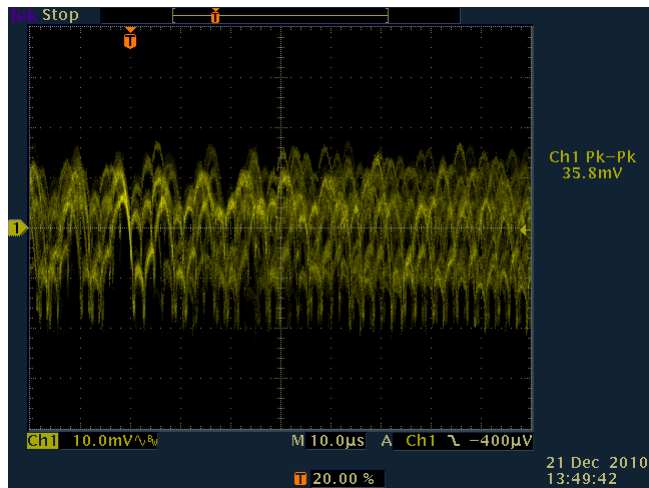


VIN: 34V
IO : 300mA

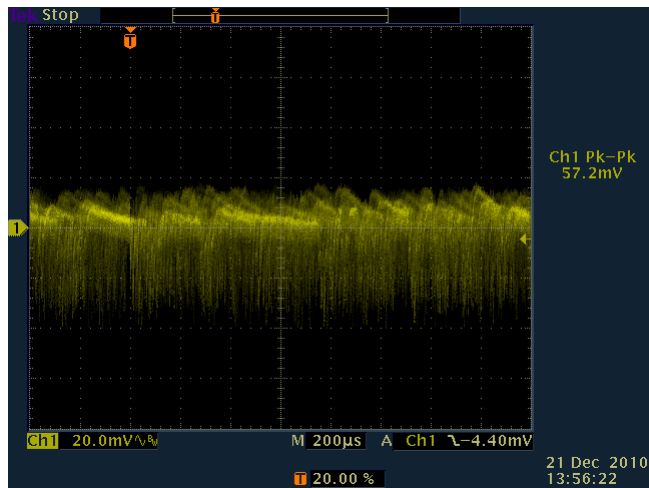


VIN: 34V
IO : 336mA
(worst condition)

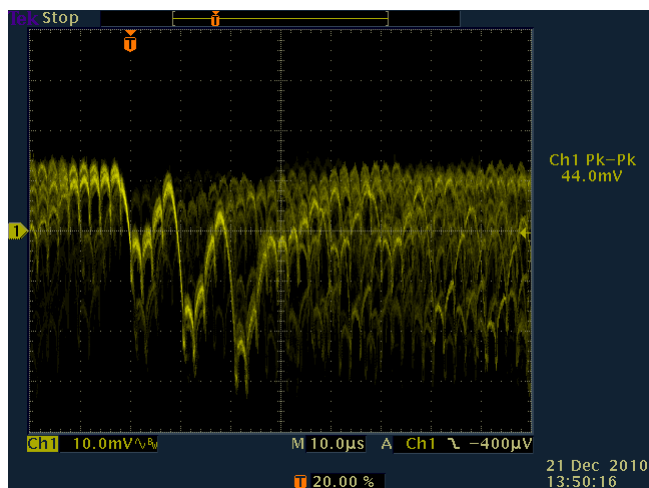


VIN: 34V
IO : 350mA

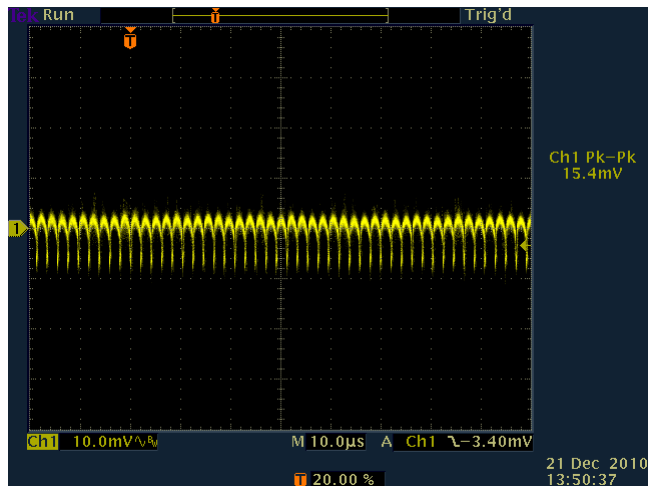

VIN: 34V
IO : 400mA

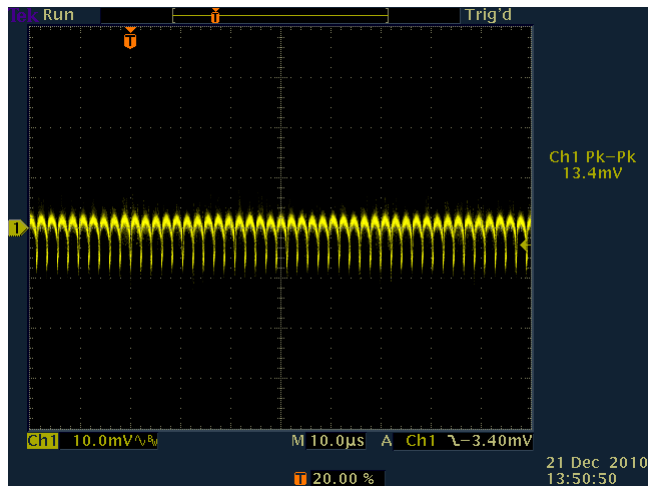

VIN: 34V
IO : 450mA

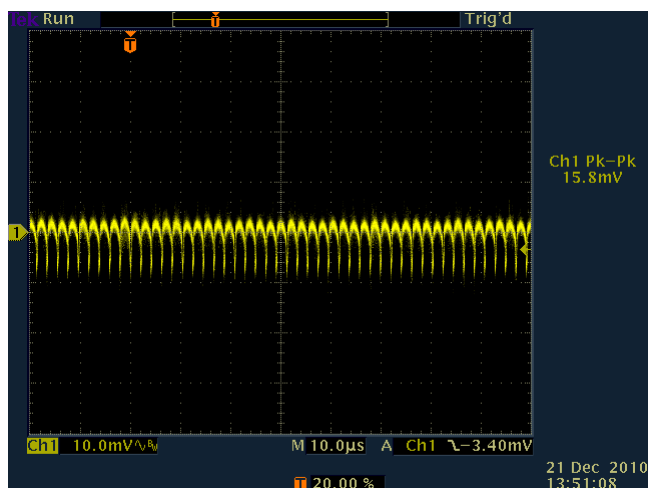

VIN: 34V
IO : 500mA