


RL 0dBm

10dB/

STOP  
250.0 MHz

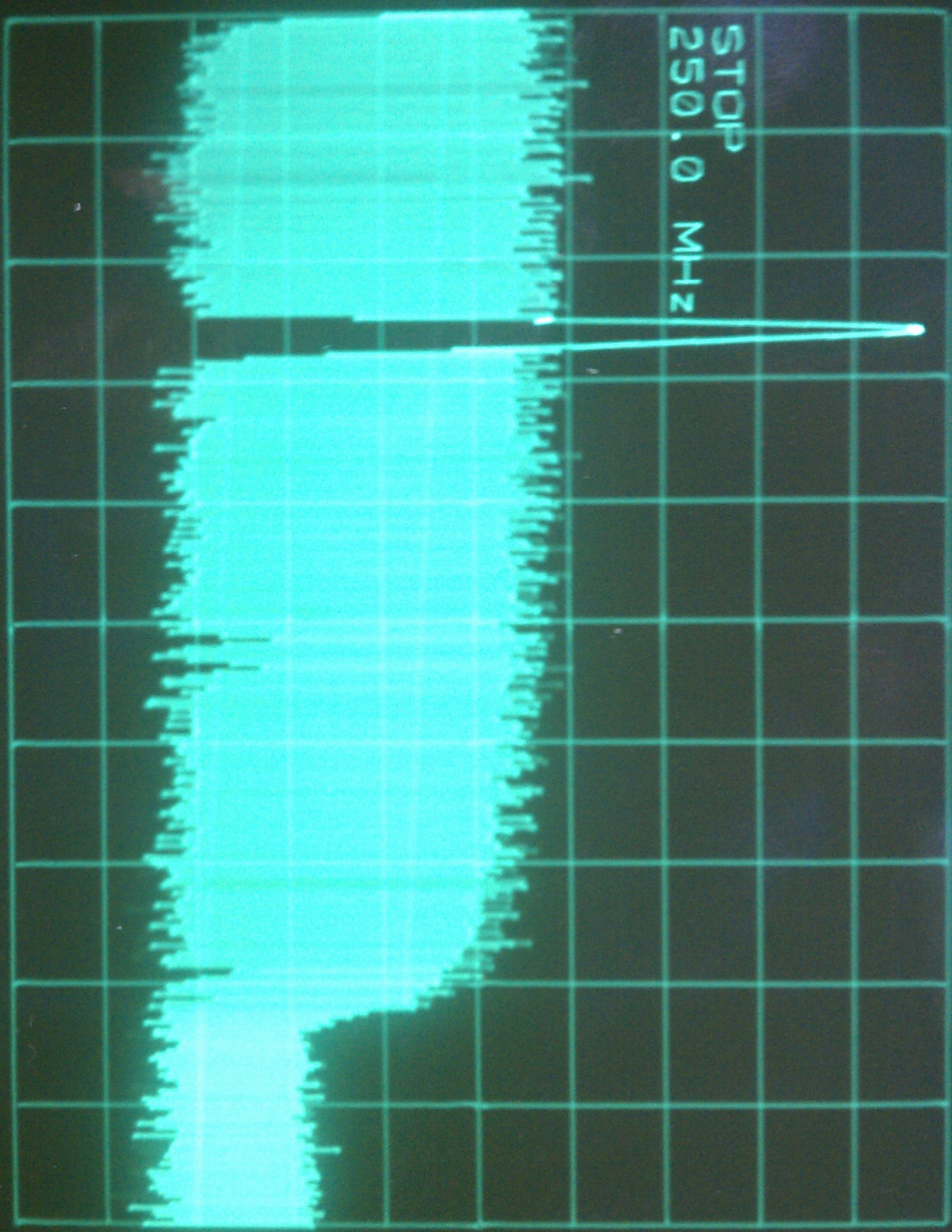

START 3.0MHz  
RBW 1.0MHz

STOP 250.0MHz  
VBW 1.0MHz

SWP 50ms

FREQ

CENT

STA

ST

CF ST  
AUTO M

FF  
OFFS