
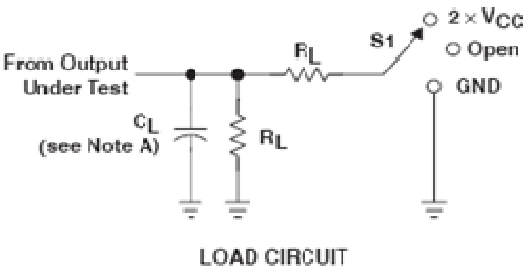


I_I	$V_{CC} = 3.6\text{ V},$	$V_I = V_{CC}\text{ or GND}$	± 1	μA
-------	--------------------------	------------------------------	---------	---------------

LOADING CONDITIONS

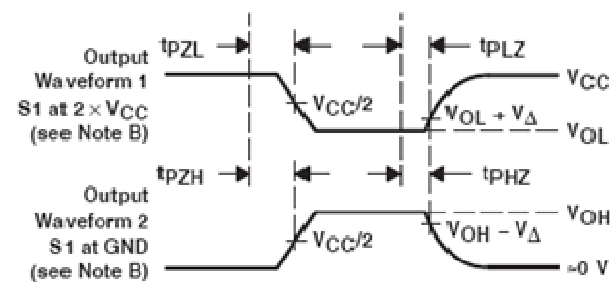

B. Waveform 1 is for an output with internal conditions such that the output is low except when disabled by the output control. Waveform 2 is for an output with internal conditions such that the output is high except when disabled by the output control.