


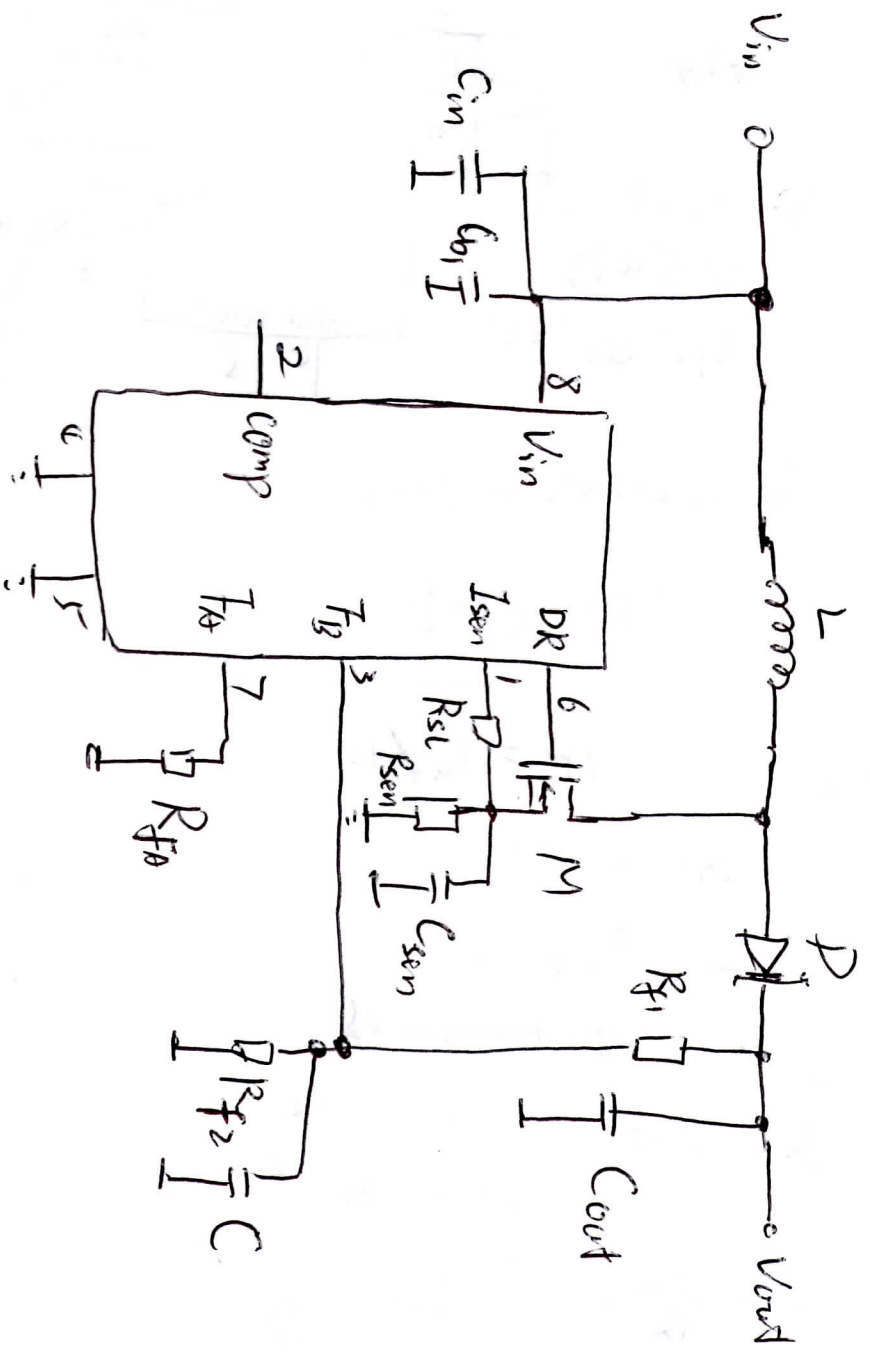

$V_{in} = 24VDC$ $V_{out} = 150VDC$ D MUR1520G

$C_{in} = 22\mu F$ $R_{S1} = 270\Omega$ M PHP33NQ20T.127

$C_{b1} = 10\mu F$ $R_{f1} = 260k\Omega$

$C = 100pF$ $R_{f2} = 2.2k\Omega$

$C_{out} = 220\mu F$

$L = 10\mu H$