


8V out 300W

V375A8C300BL

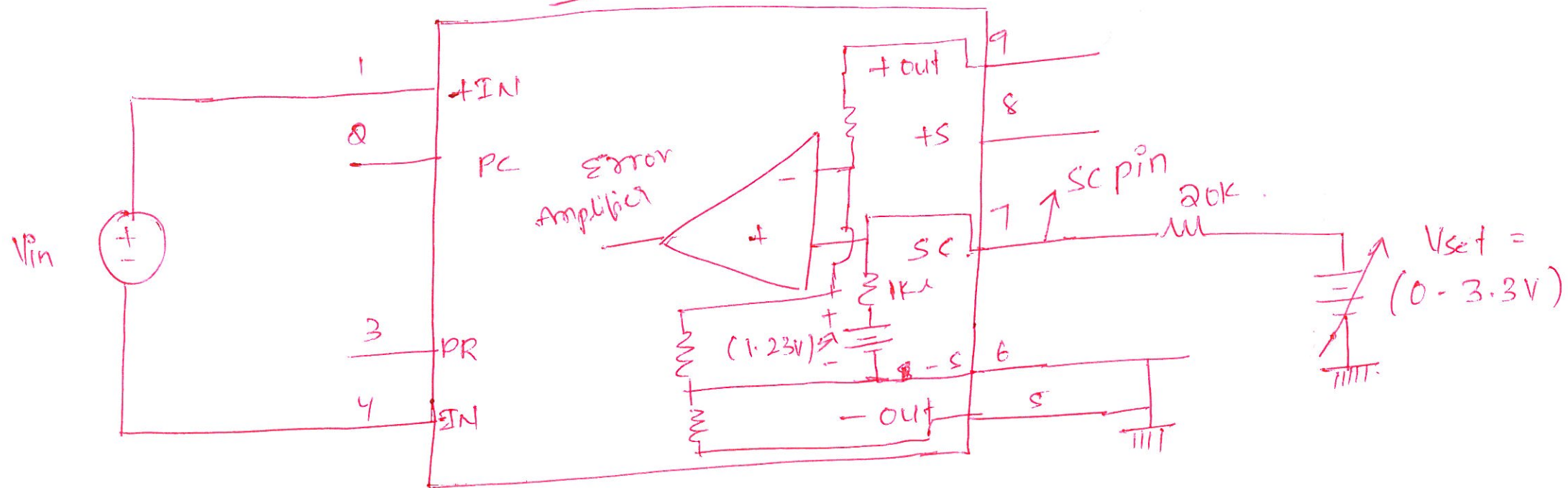

Vset	Vout	I out	Vsc
0V	7.62V	10A	1.17V
1.023V	7.93V	10A	1.22V
2.013V	8.25V	10A	1.26V
3.305V	8.65V	10A	1.328V
Open	8V	10A	1.23V