


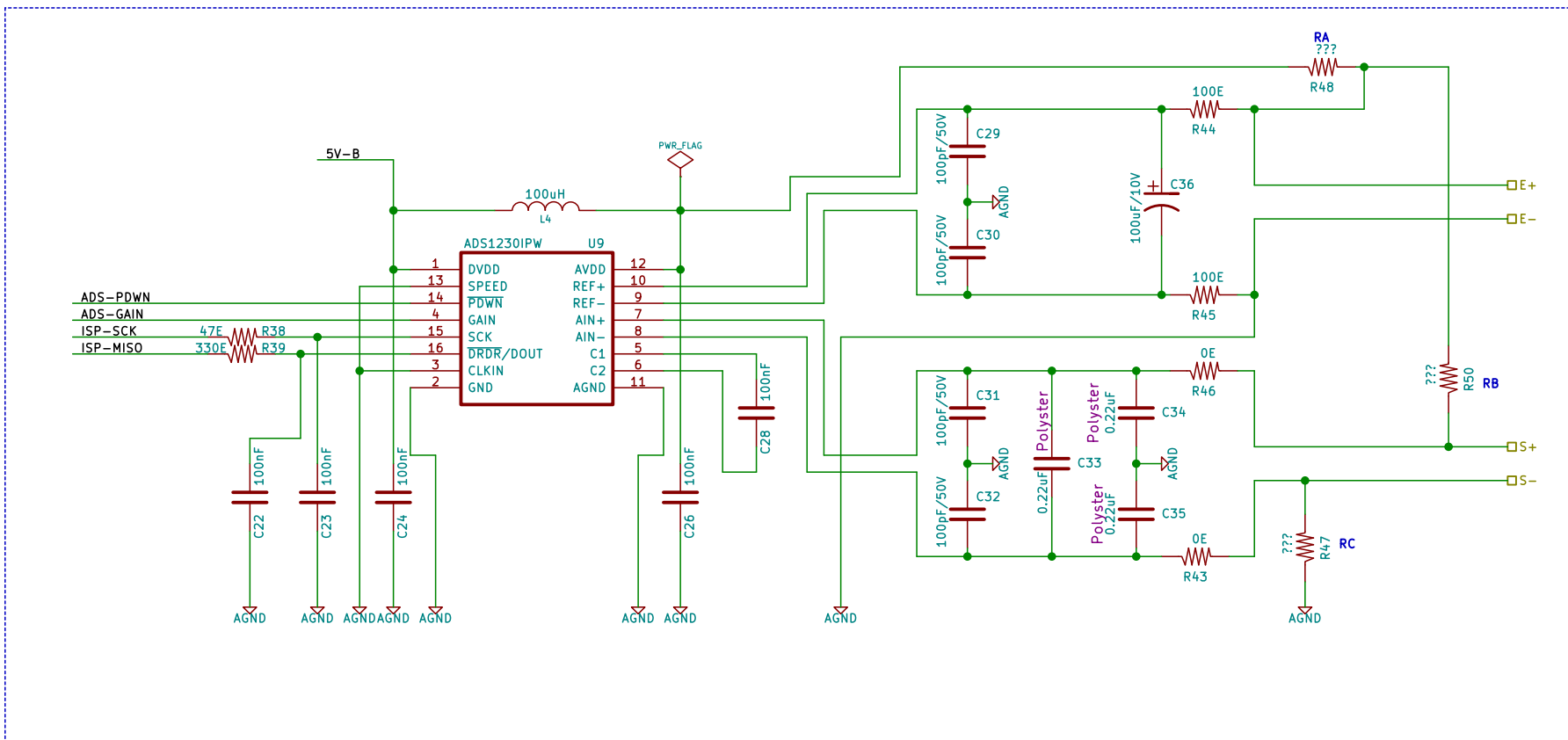

ADS1230 Config:
 PGA=64, SPEED=10SPS,
 AVDD=DVDD=5V,
 Aref = Ratiometric, Depending on PT100 value.
 = 3.99V @ 400 Deg C
 Ain(max) = 36mV @ 400 Deg C

Pt100: 2-Wire Interface:
 Connections: PT100+ <--> S+, Pt100- <--> S-
 RA = 6k8, RB = 27k & RC = 0E