

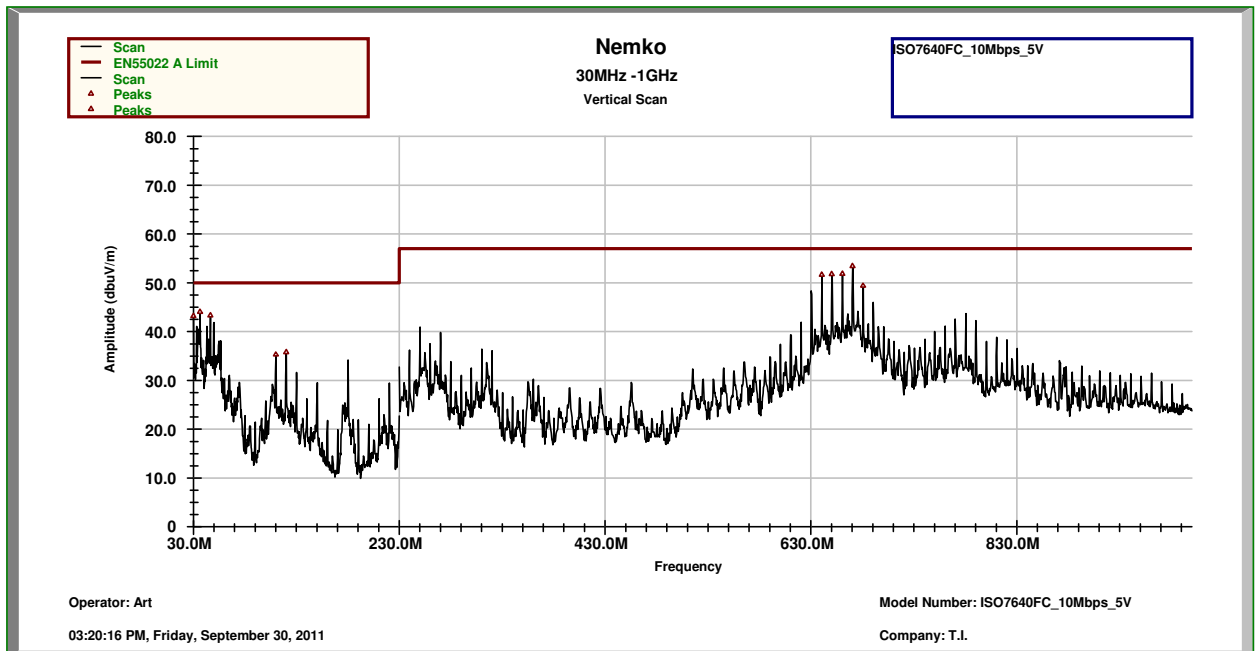
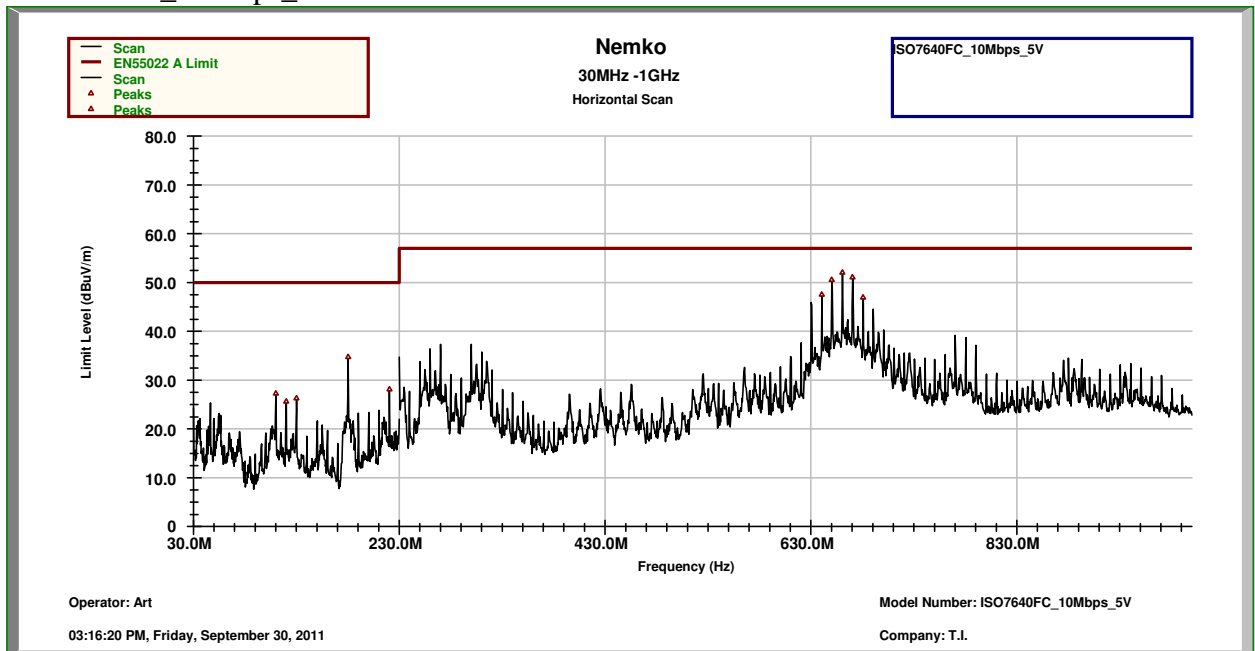


ISO7640FC_10Mbps_5V


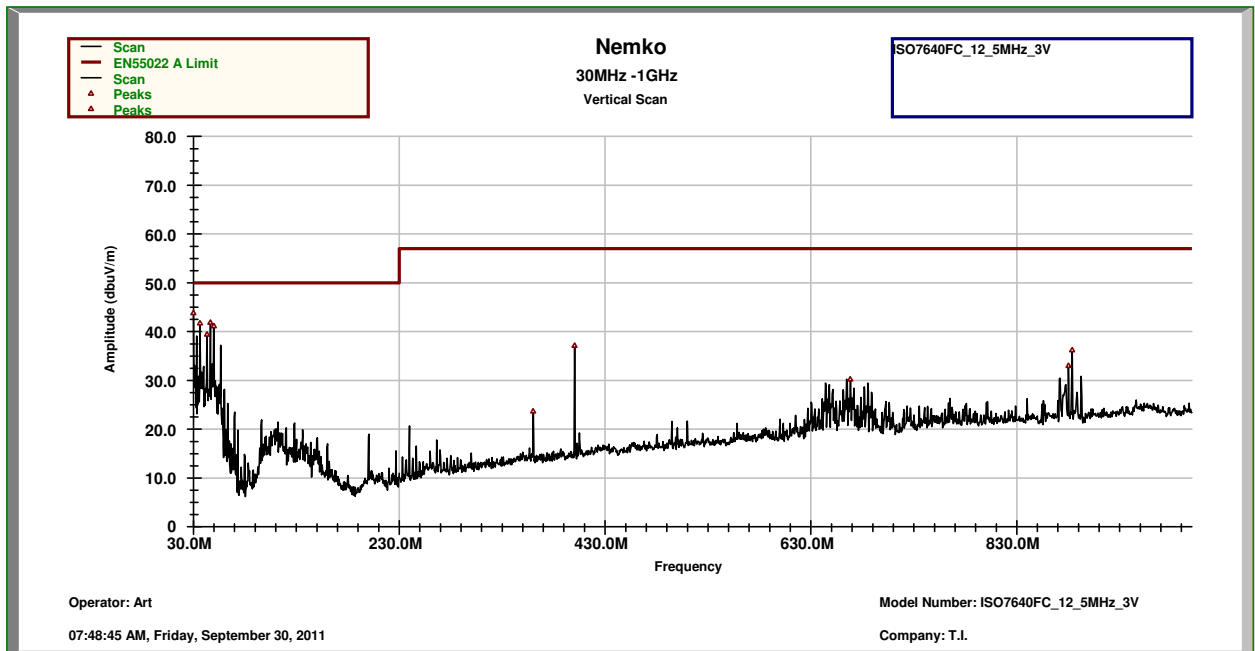


ISO7640FC_12_5MHz_3V


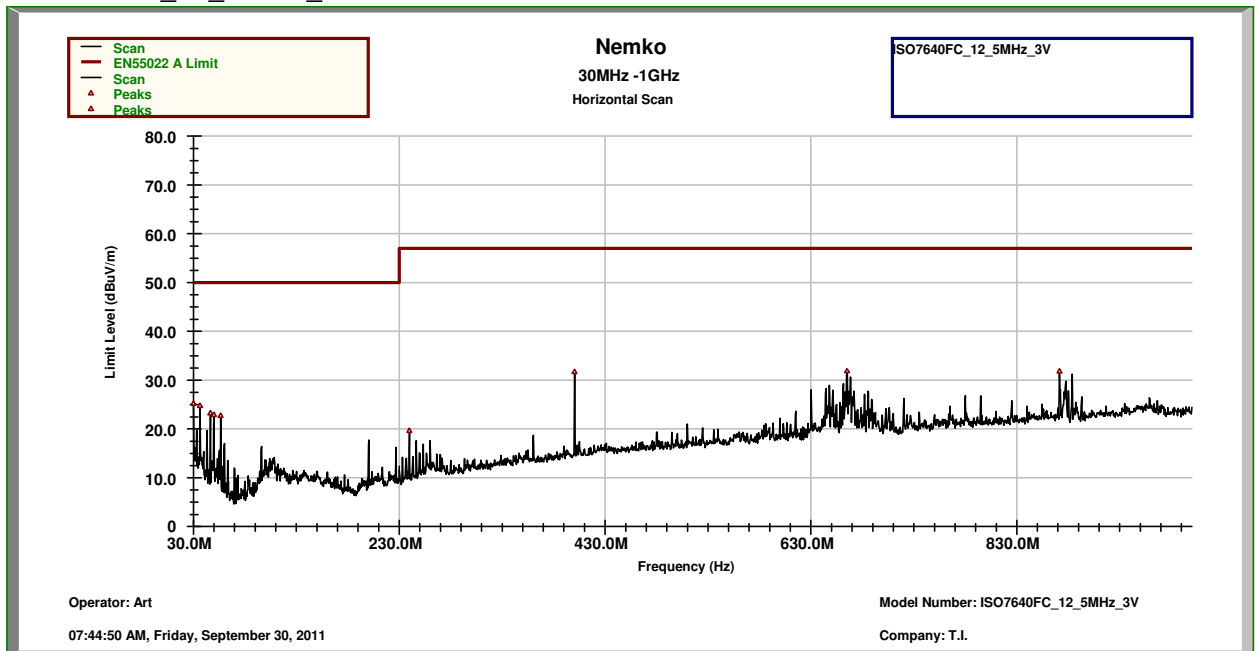


Frequency MHz	Limit Limit	Horizontal QP	QP Margin	Vertical QP	Vertical Margin
36.6328	50			39.827	-10.173
36.6928	50	19.787	-30.213		
43.3265	50			37.368	-12.632
46.6529	50	22.741	-27.259	41.416	-8.584
50.0201	50	22.018	-27.982	39.039	-10.961
56.6729	50	20.441	-29.559		
239.993	57	16.72	-40.28		
359.994	57			20.991	-36.009
400.234	57	26.874	-30.126	34.883	-22.117
664.65	57	29.559	-27.441		
667.976	57			31.346	-25.654
871.629	57	29.694	-27.306		
880.014	57			31.2	-25.8
883.614	57			33.367	-23.633

ISO7640FC_1MHz_3V

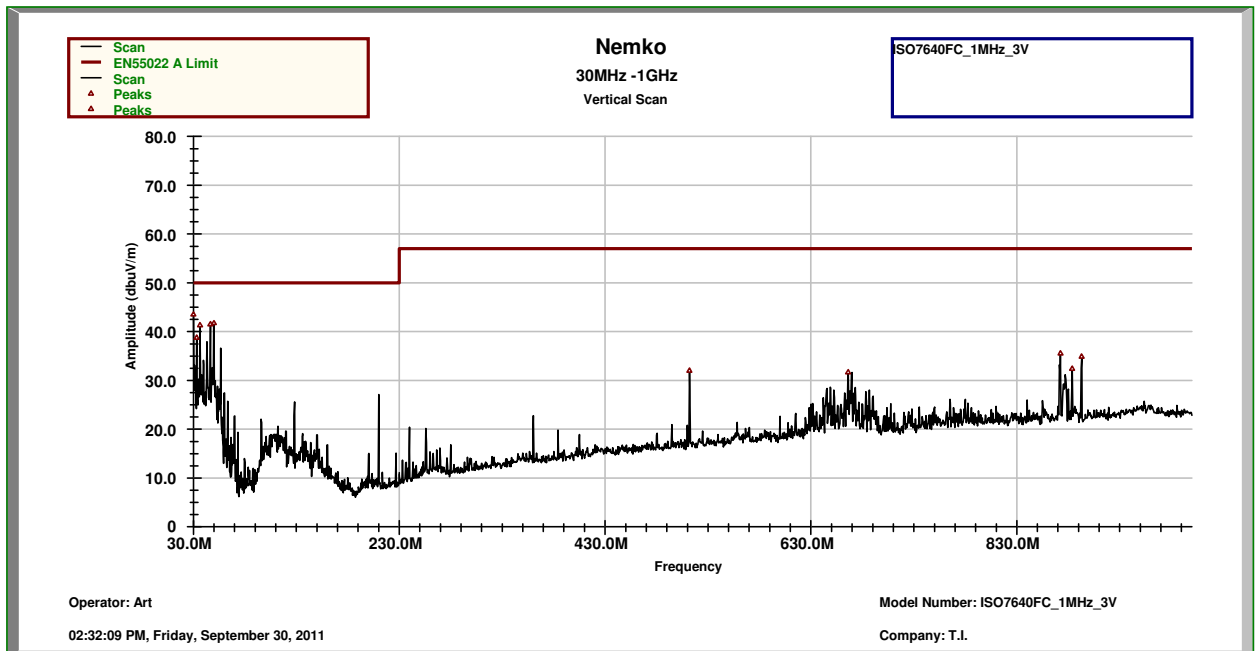
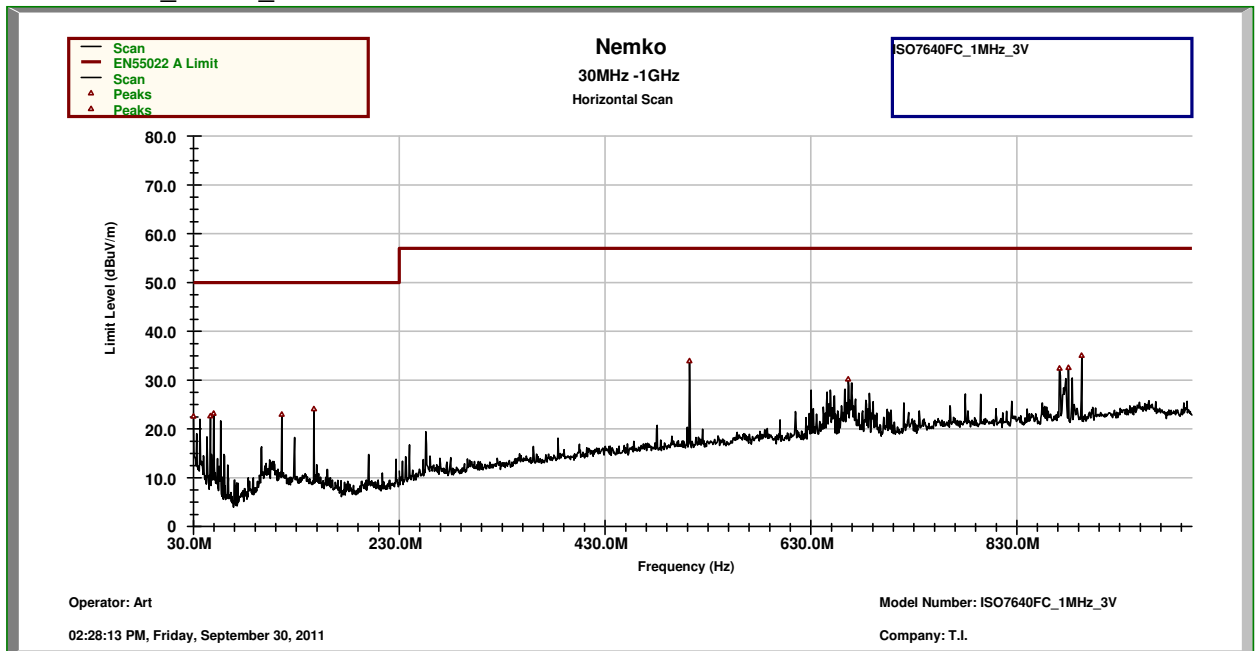


ISO7640FC_25Mbps_3V

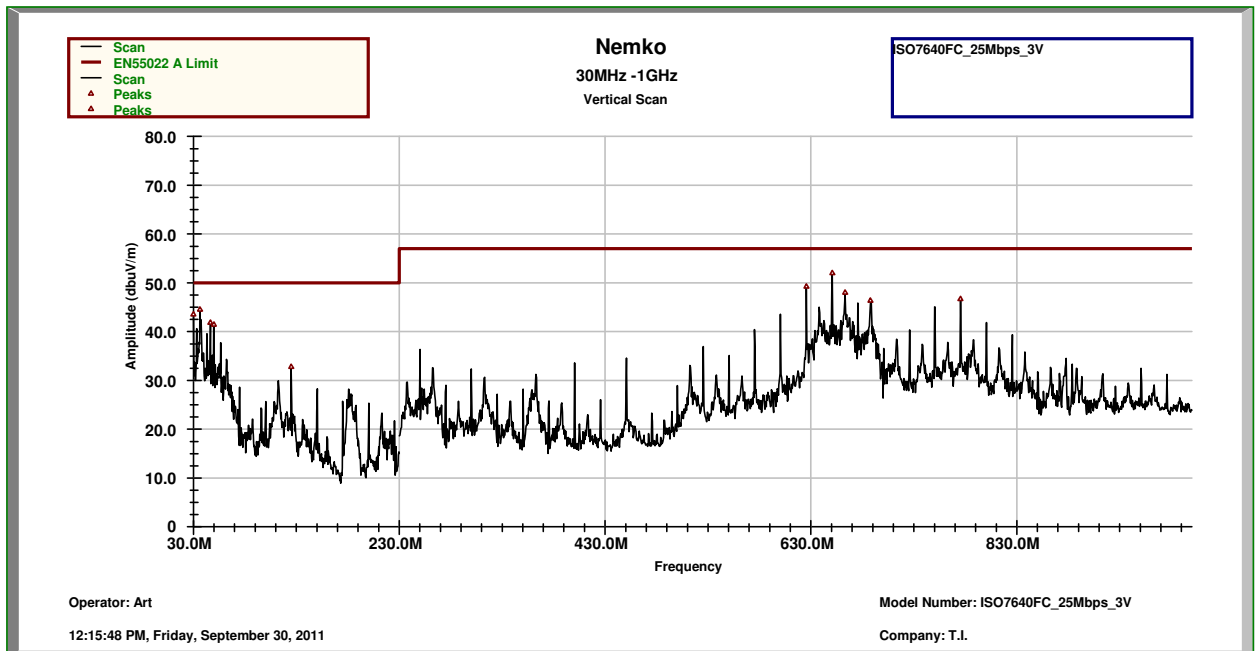
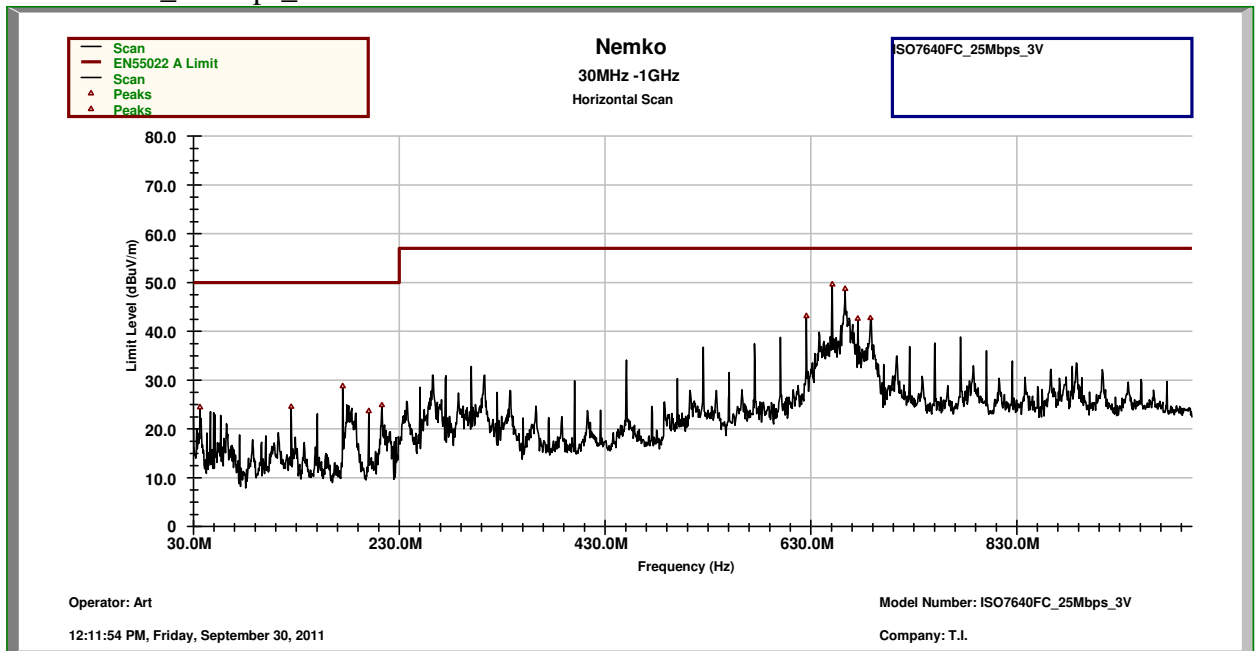


Frequency MHz	Limit Limit	Horizontal QP	QP Margin	Vertical QP	Vertical Margin
36.6928	50	19.973	-30.027	40.891	-9.109
46.6529	50			40.292	-9.708
50.0201	50			39.065	-10.935
124.49	50	8.852	-41.148		
125.09	50			32.903	-17.097
175.13	50	27.549	-22.451		
200.141	50	23.807	-26.193		
212.786	50	24.391	-25.609		
625.404	57			49.353	-7.647
625.464	57	41.073	-15.927		
650.488	57	50.375	-6.625	56.625	-0.375
662.833	57	49.295	-7.705	54.338	-2.662
675.478	57	45.695	-11.305		
687.762	57			45.422	-11.578
687.822	57	45.8	-11.2		
775.564	57			42.93	-14.07



ISO7640FC_25Mbps_3V_ 1GHz-6GHz

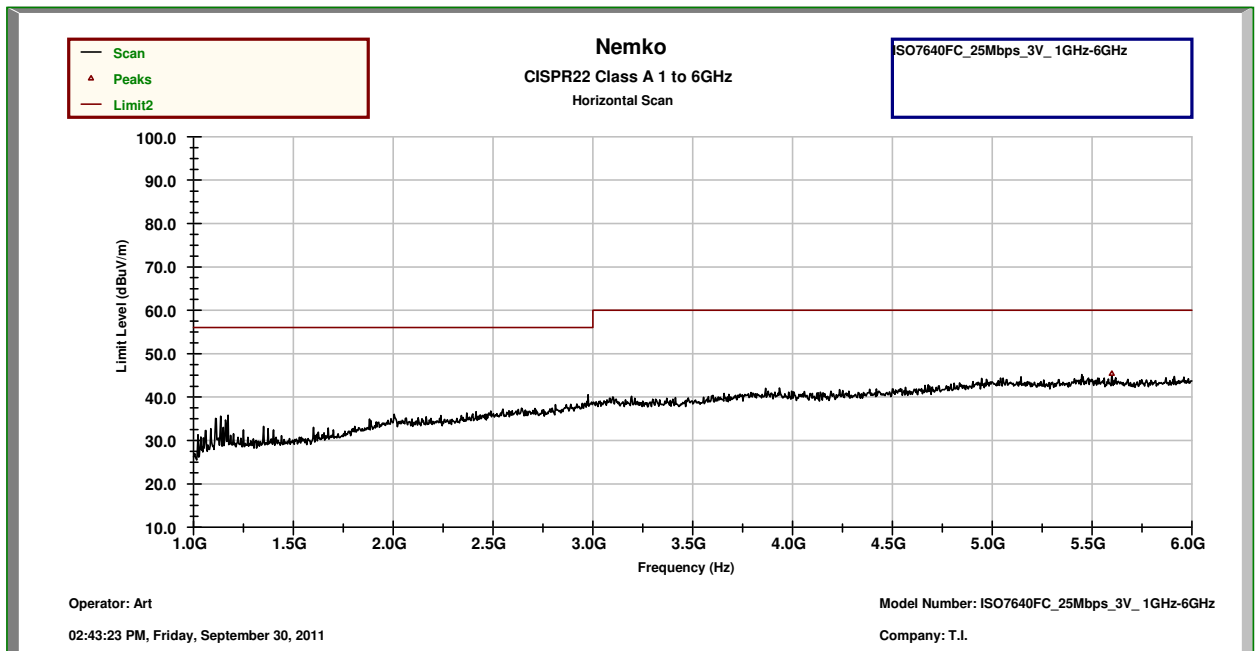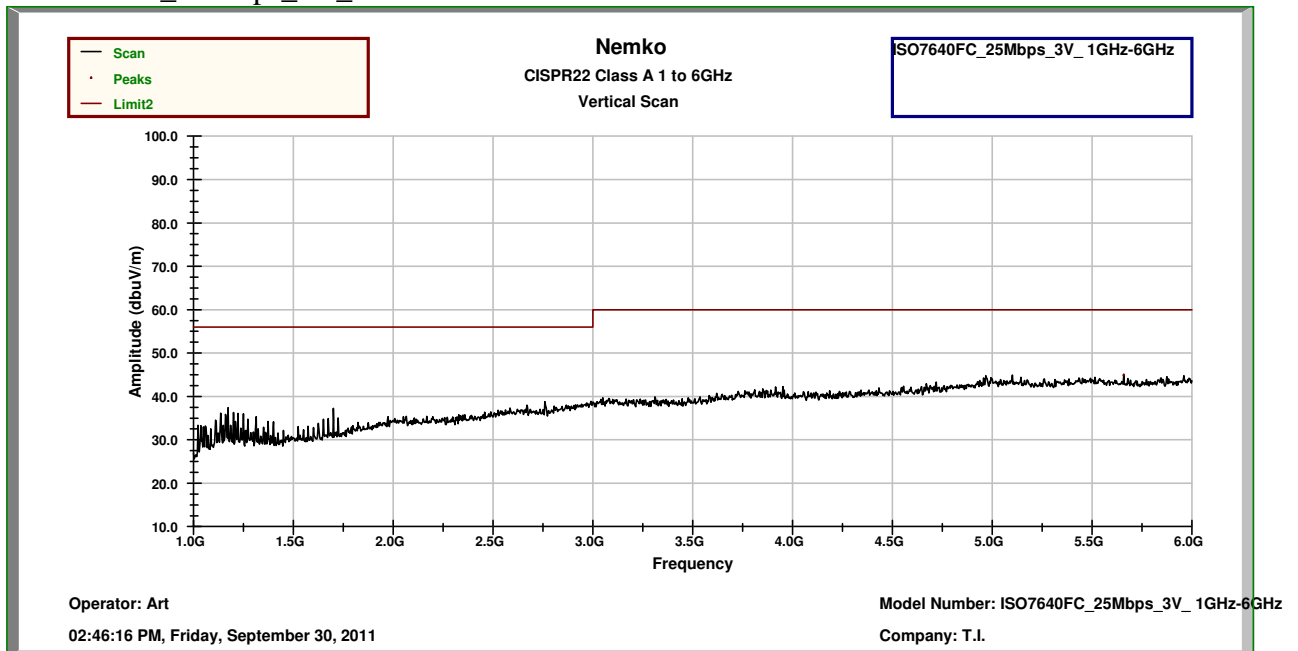



ISO7640FC_5MHz_5V

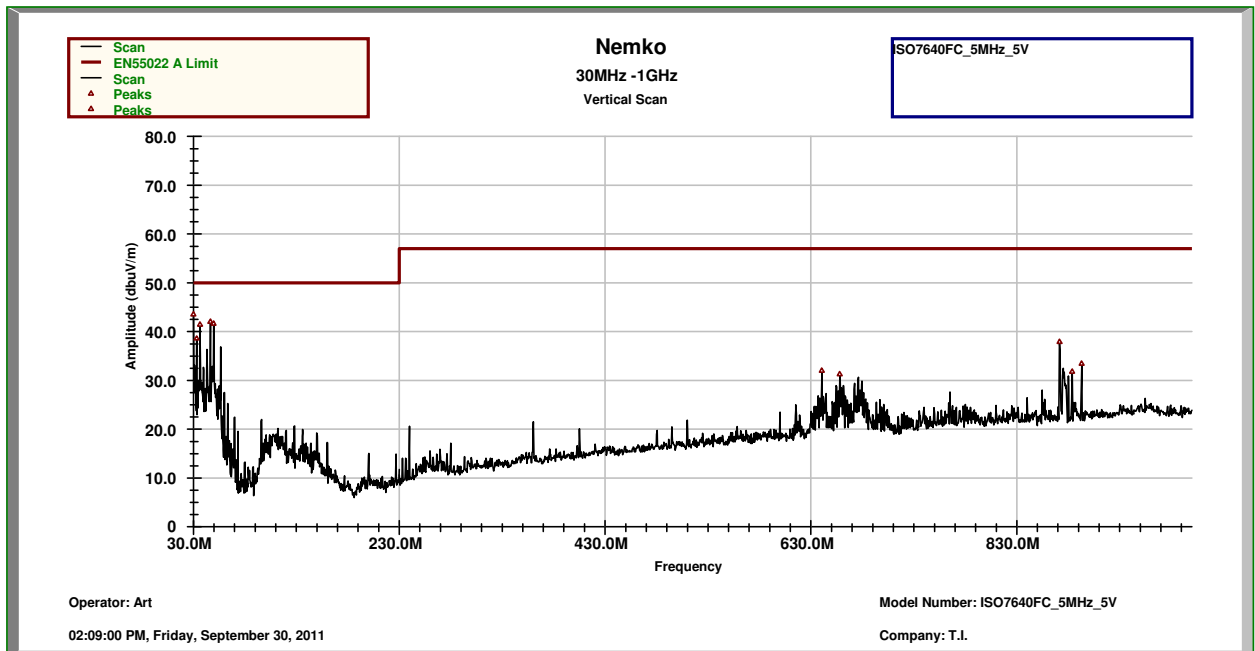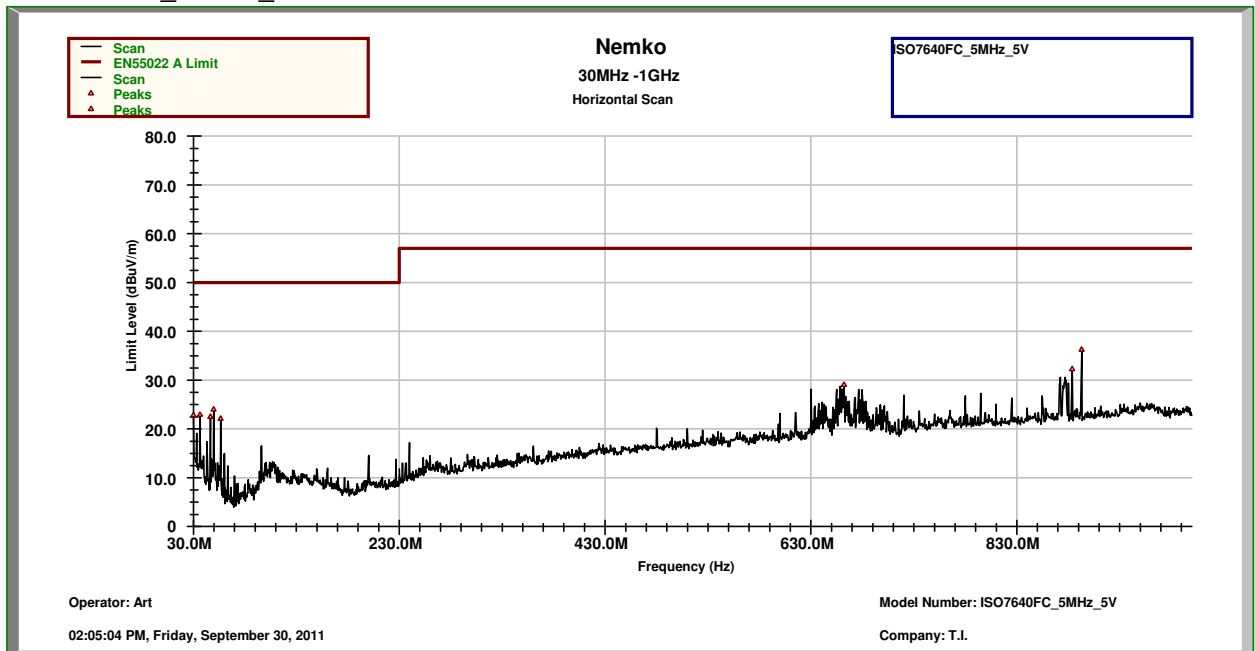

Pat Gen Baseline_10Mbps_5V

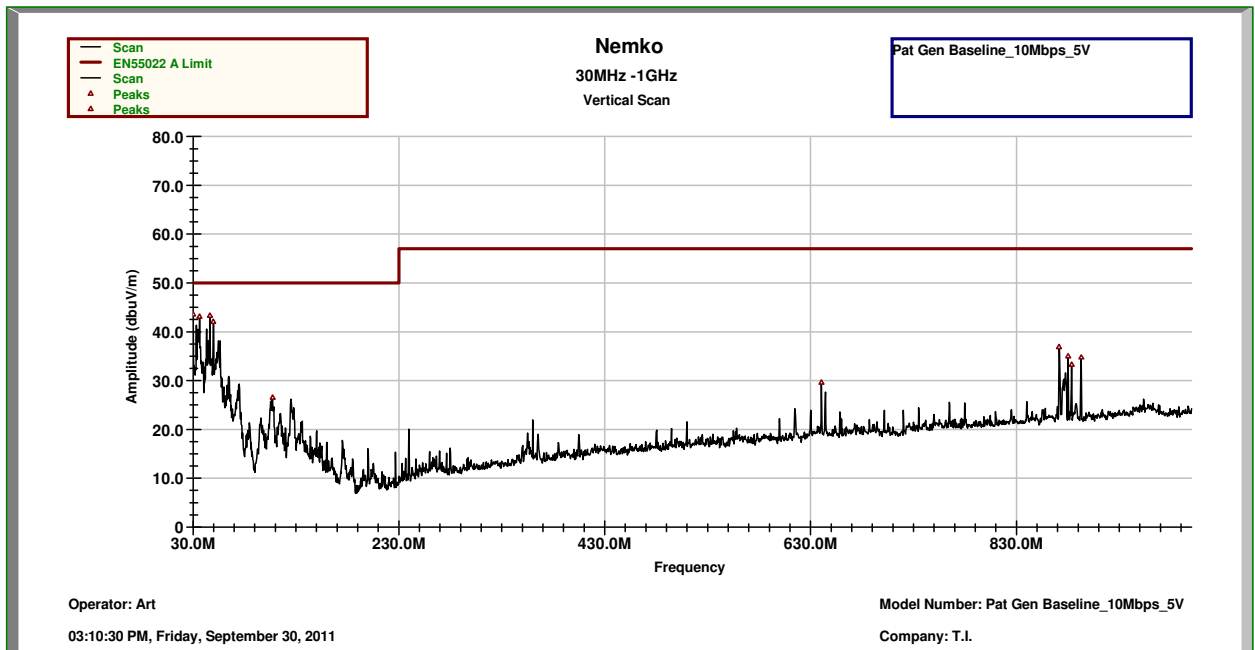
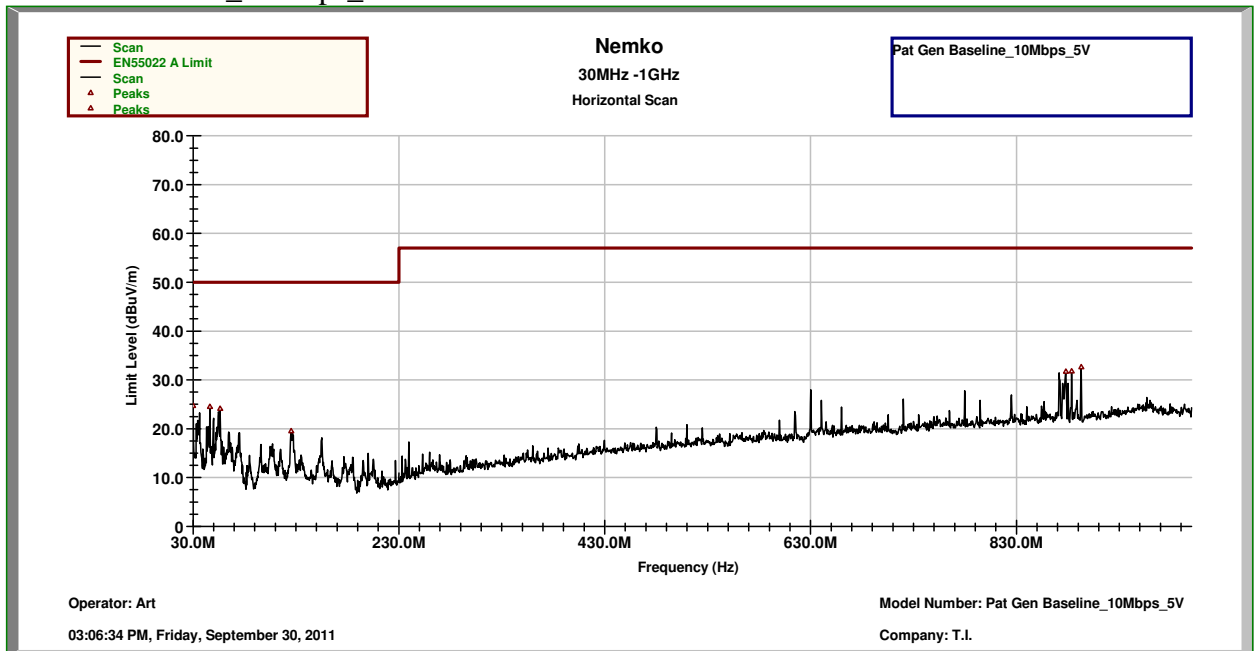


Pat Gen Baseline_12_5MHz_3V

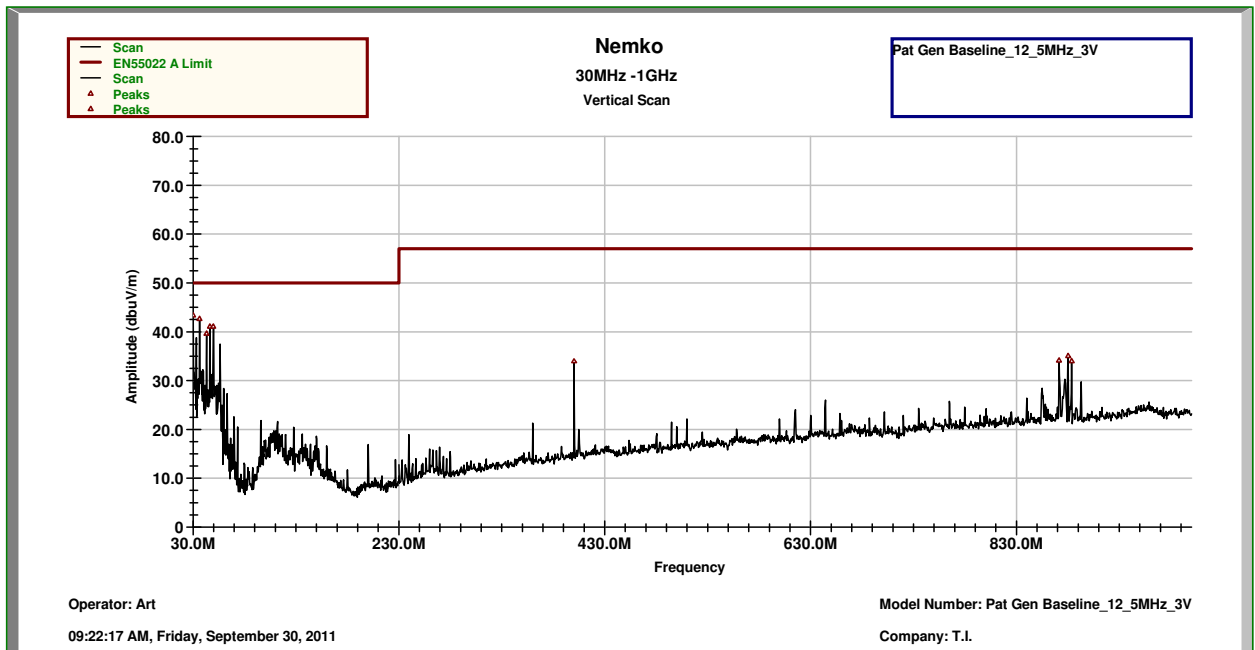
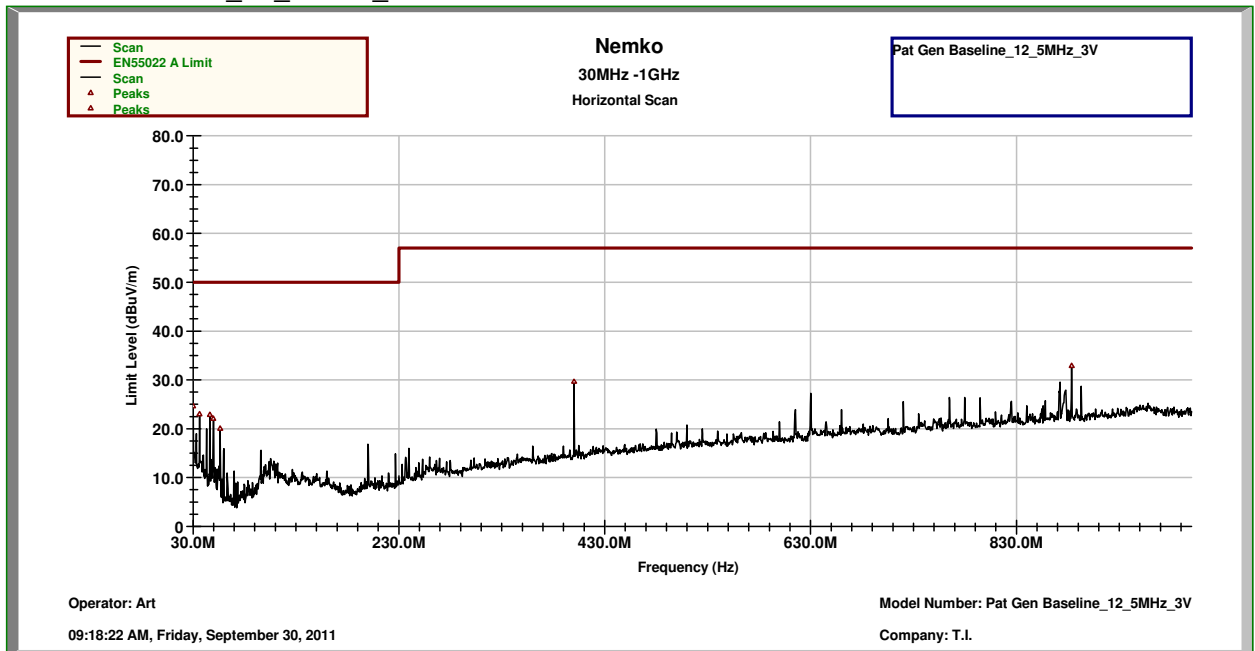


Frequency MHz	Limit Limit	Horizontal QP	QP Margin	Vertical QP	Vertical Margin
36.6328	50	20.124	-29.876	40.803	-9.197
43.3265	50			37.847	-12.153
46.6529	50	22.411	-27.589	41.434	-8.566
49.9793	50	22.783	-27.217	39.762	-10.238
56.6729	50	20.005	-29.995		
400.234	57	26.618	-30.382	32.64	-24.36
871.509	57			36.638	-20.362
880.014	57			29.293	-27.707
883.614	57			29.359	-27.641
883.674	57	27.277	-29.723		

Pat Gen Baseline_1MHz_3V

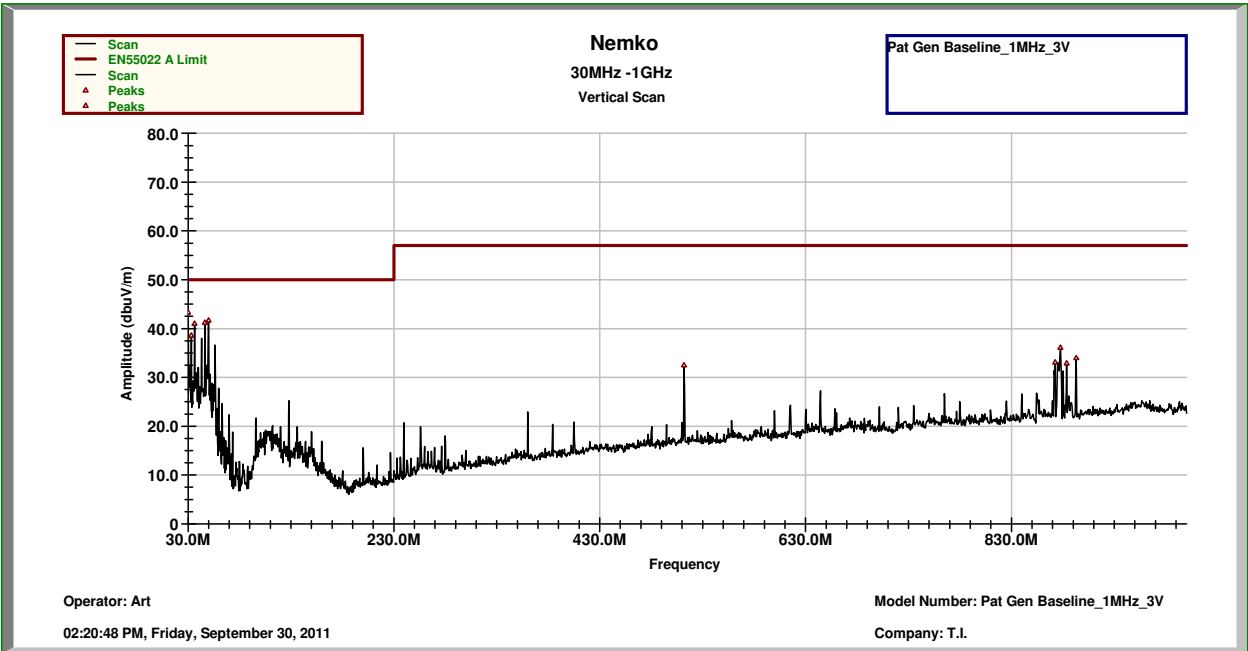
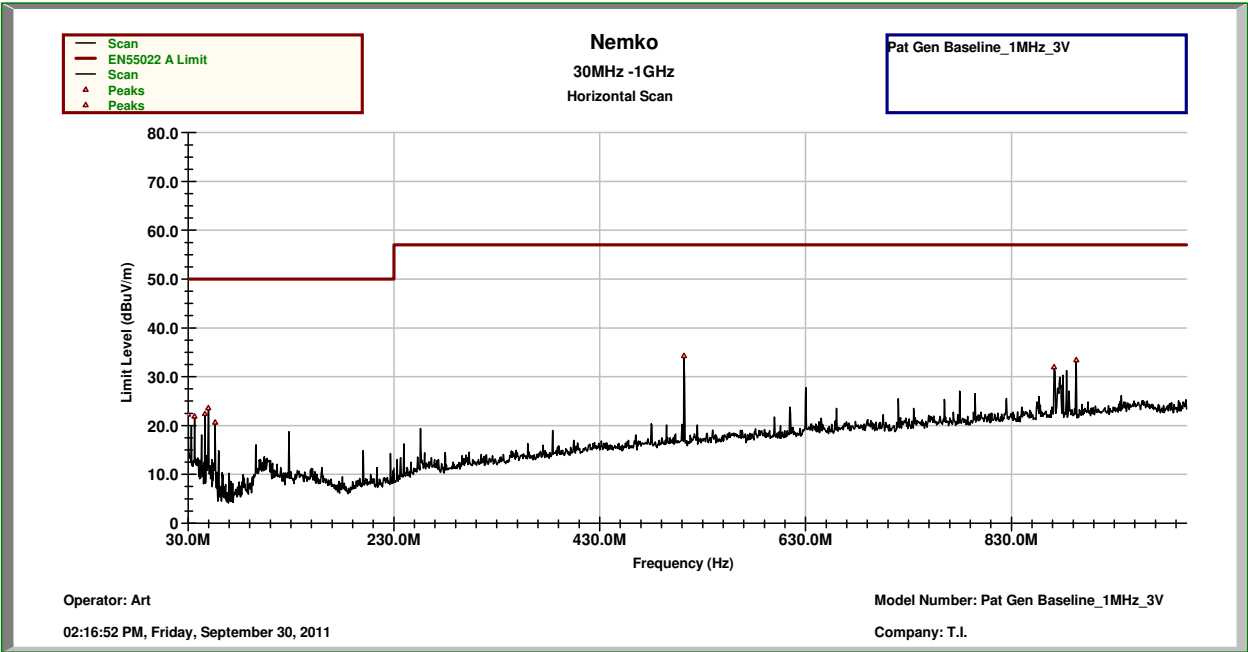


Pat Gen Baseline_25Mbps_3V

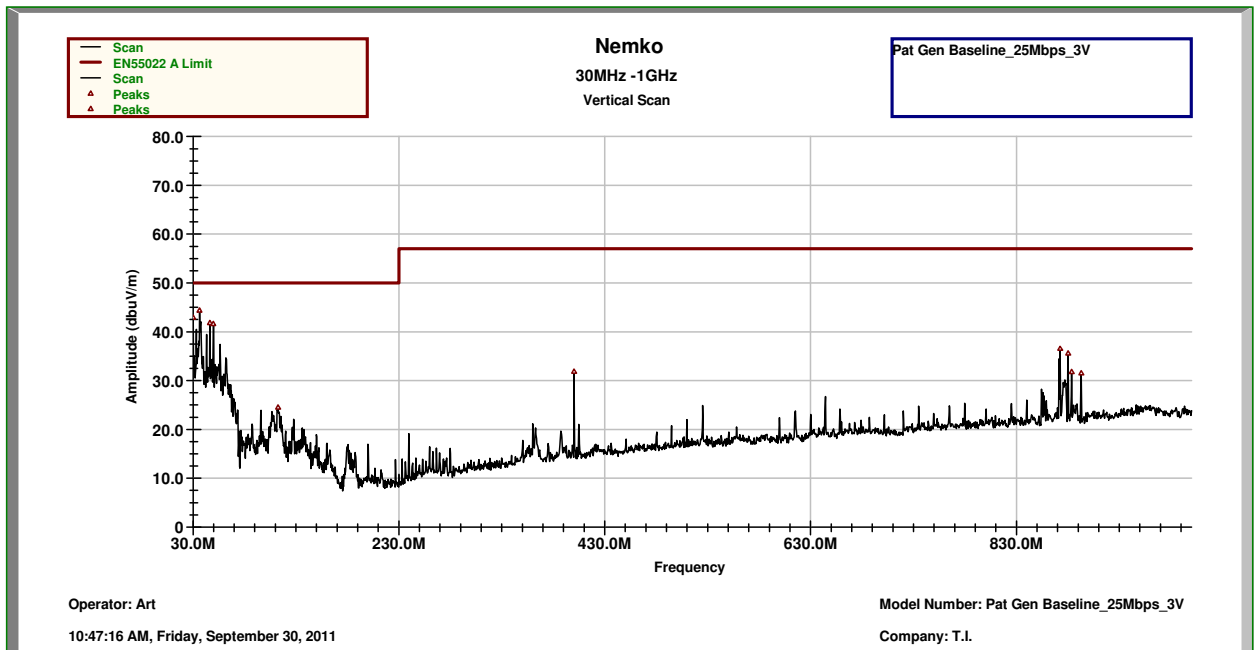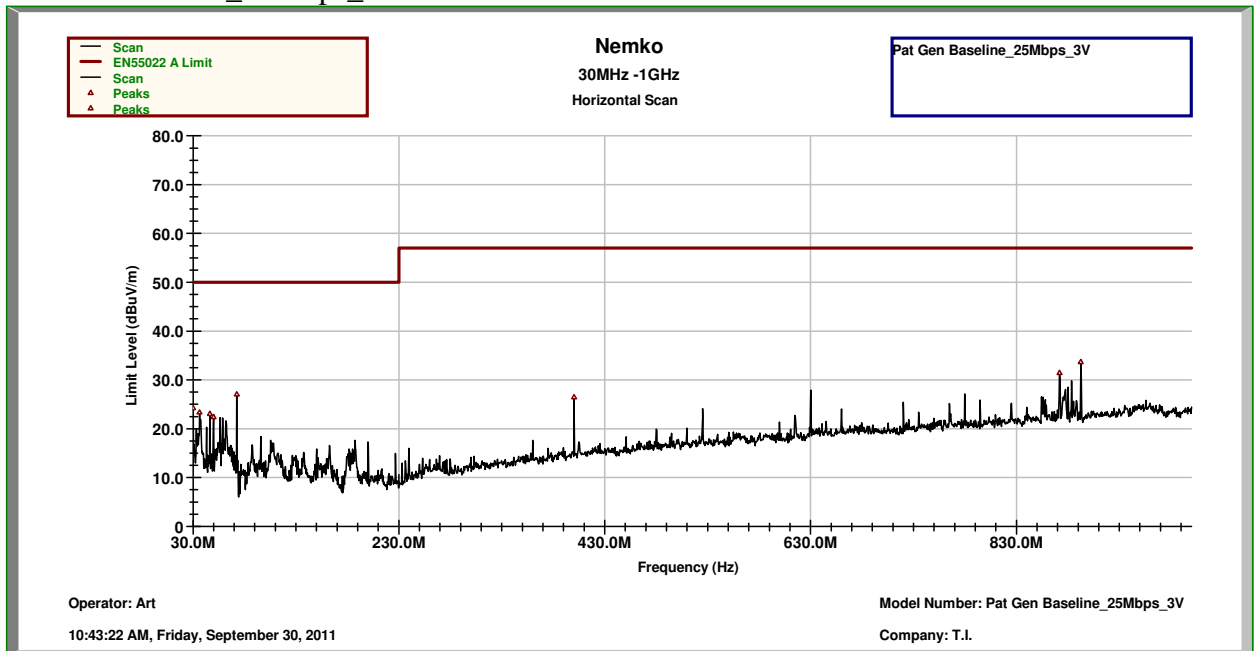

Frequency MHz	Limit Limit	Horizontal QP	QP Margin	Vertical QP	Vertical Margin
36.6928	50	20.358	-29.642	40.703	-9.297
46.6529	50	22.563	-27.437	42.231	-7.769
49.9793	50			39.879	-10.121
50.0201	50	22.075	-27.925		
71.985	50	7.494	-42.506		
112.725	50			24.05	-25.95
400.234	57			29.678	-27.322
400.294	57	21.321	-35.679		
871.664	57	29.586	-27.414		
872.178	57			39.18	-17.82
880.014	57			28.146	-28.854
883.614	57			31.626	-25.374
892.753	57			32.274	-24.726
892.838	57	33.722	-23.278		

Pat Gen Baseline_25Mbps_3V_ 1GHz-6GHz.

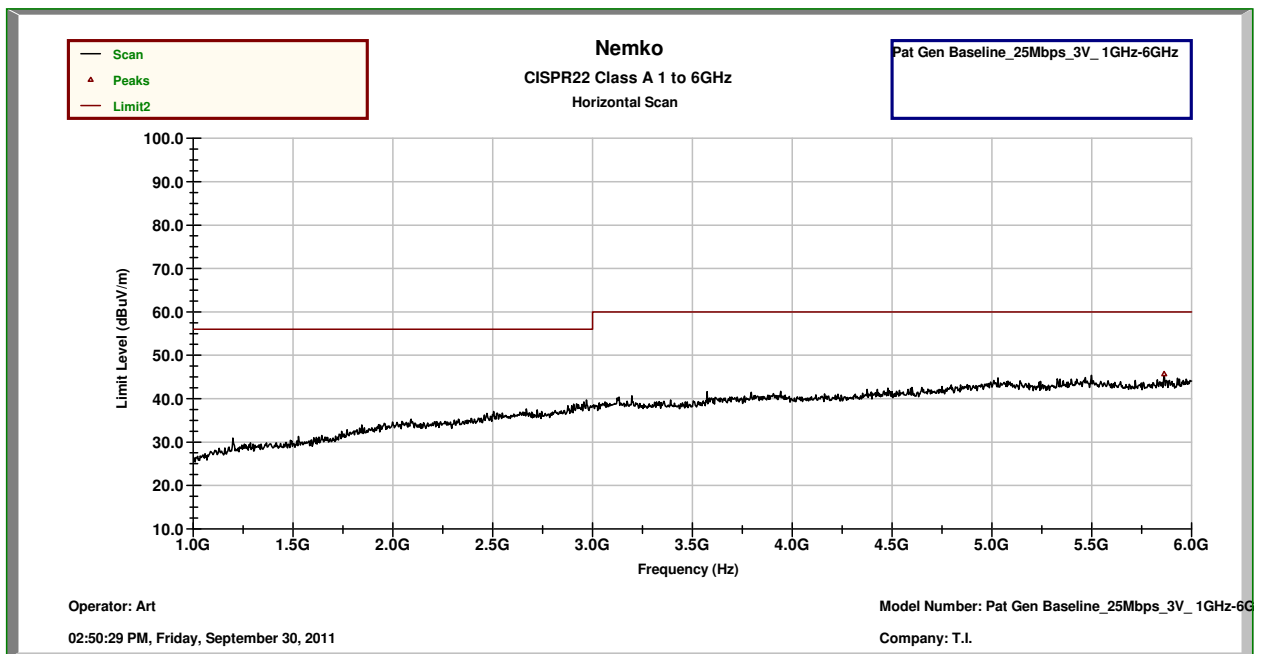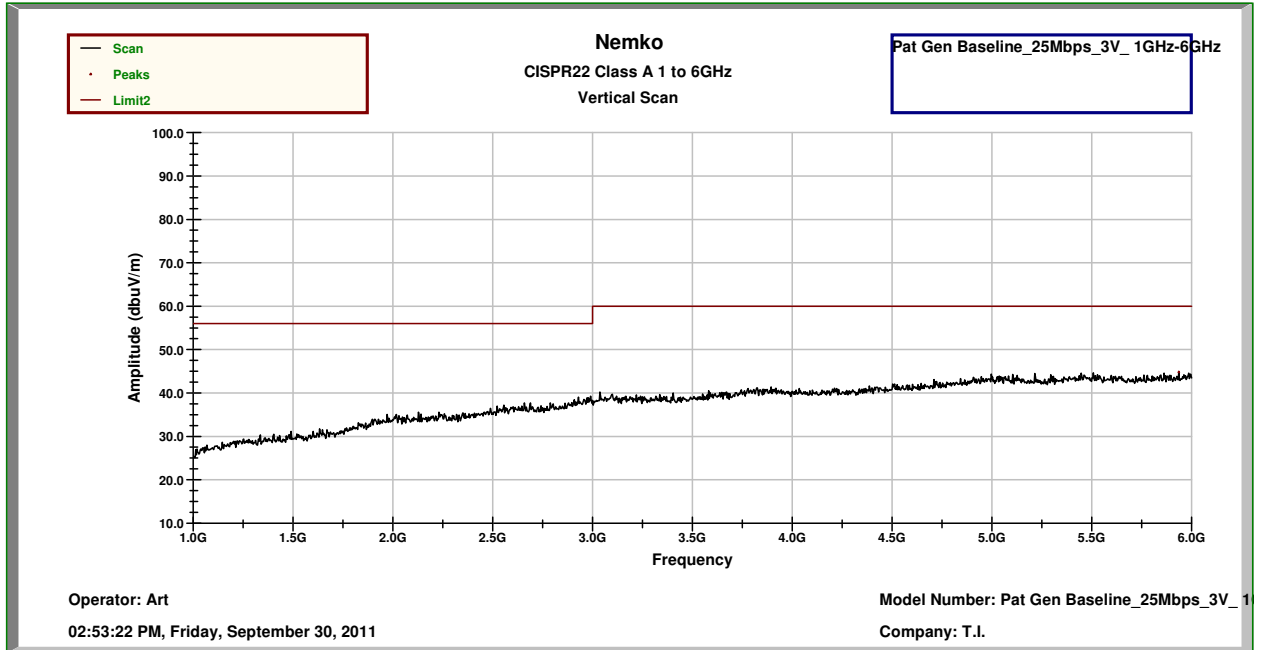

Pat Gen Baseline_5MHz_5V

