


1 5.00V/ 2 5.00V/ 3 4 5.00V/ 117.5µs 1.000ms/ f 2 1.63V

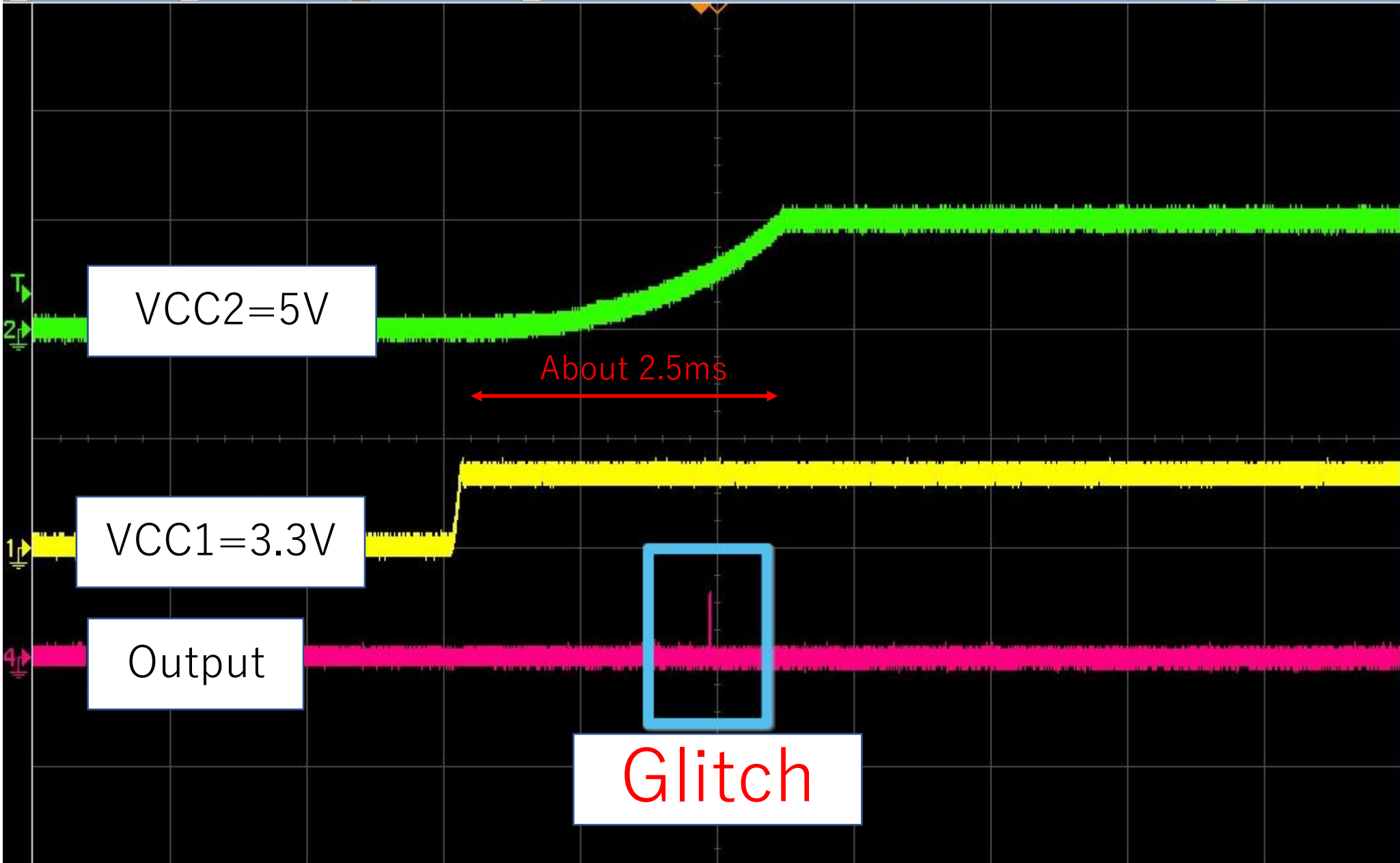

1 5.00V/ 2 5.00V/ 3 4 5.00V/ 85.00µs 20.00µs/ f 2 1.63V

