



■ Device
FDC2212

■ LC tank
 $L = 18\mu\text{H}$
 $C = 33\text{pF}$


■ Sensors
Capacitance of electrode: $200 \sim 300\text{pF}$

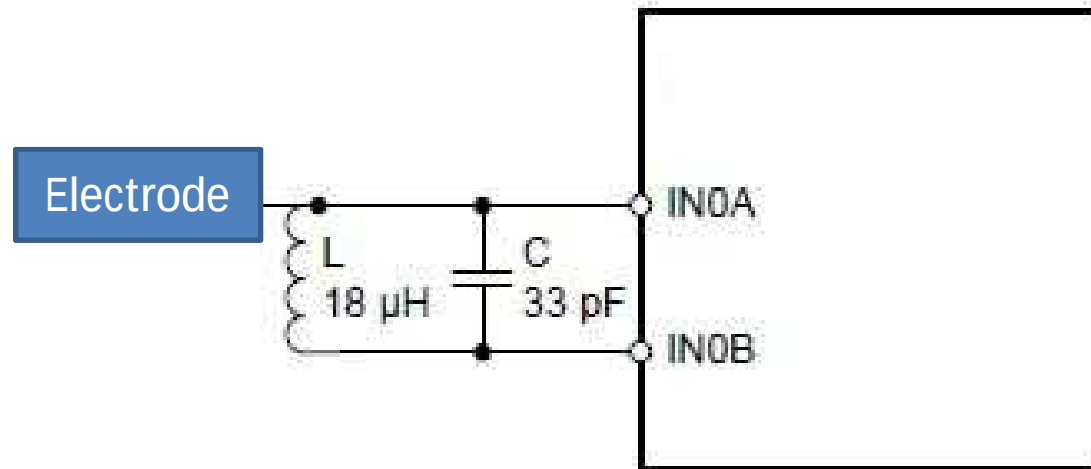

IDRIVE: 5

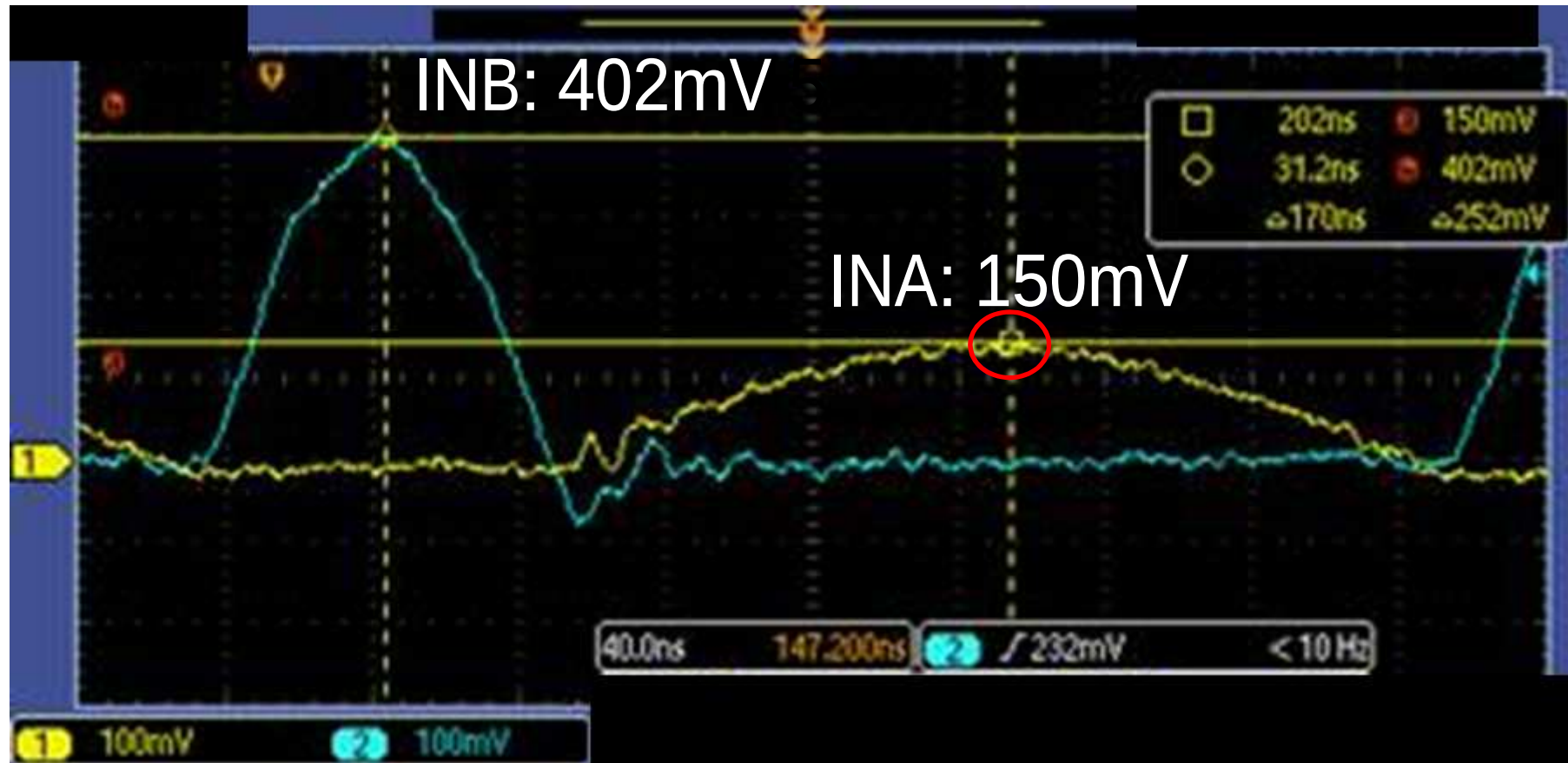

IDRIVE: 25

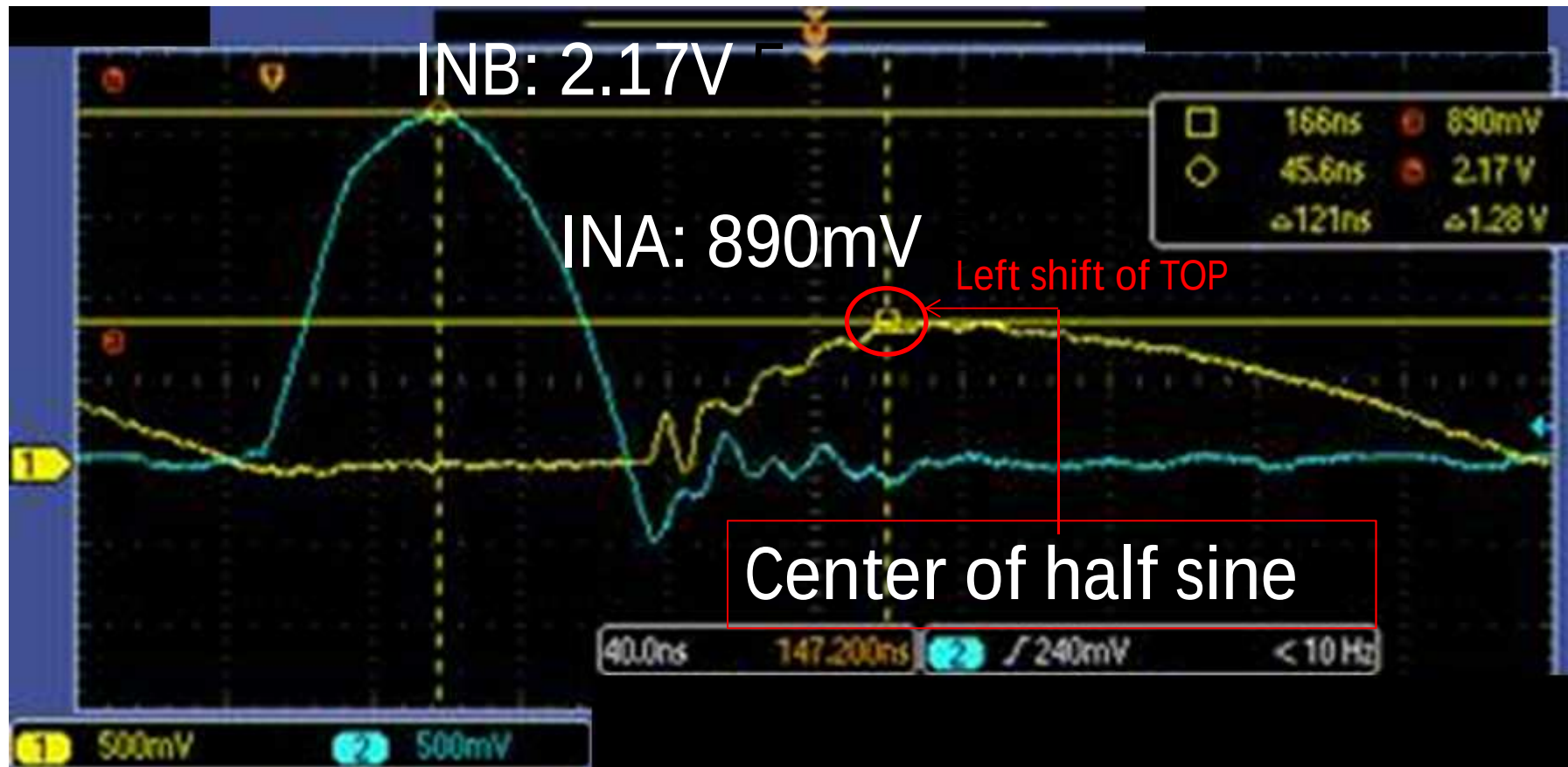

IDRIVE: 31

