


DRV425EVM Schematic

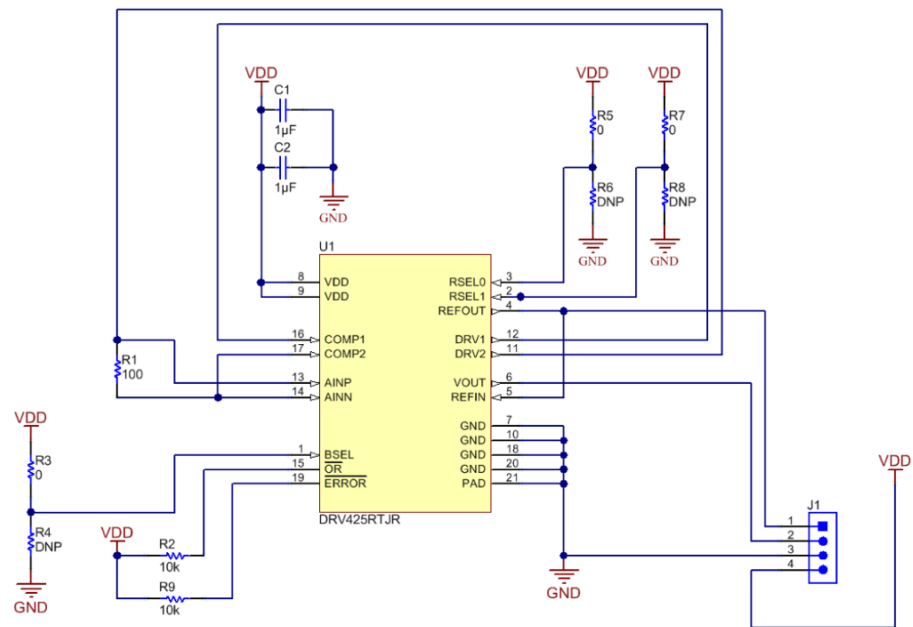

Pin Functions

Pin	Signal	Name	Description
1	V _{ref}	REFOUT	Output default connection Ref _{out} and Ref _{in} . Ref _{out} determined by R _{sel} pins and V _{DD} when ratio-metric selected. When used as input cut trace described in section 3.2 and pin only connected to Vref _{in} .
2	V _{out}	VOUT	Output Voltage referenced to RefIn
3	Gnd	GND	GND Pin
4	V _{DD}	VDD	Power Supply 3.0 V to 5.5 V

DRV425EVM Board

