

Details	Speed	Measured value	Test Result	Margin	Low Limit	High Limit	Comments
Max Consecutive Jitter	High Speed	48.184 ps	Informative	N.A	N.A	N.A	N.A
Min Consecutive Jitter	High Speed	-20.050 ps	Informative	N.A	N.A	N.A	N.A
RMS Consecutive Jitter	High Speed	11.839 ps	Informative	N.A	N.A	N.A	N.A
ERROR MESSAGE	N.A						


[Back to Summary Table](#)

Paired JK Jitter							
Measurement Details	Speed	Measured Value	Test Result	Margin	Low Limit	High Limit	Comments
Max JK Jitter	High Speed	17.525 ps	Informative	N.A	N.A	N.A	N.A
Min JK Jitter	High Speed	-16.849 ps	Informative	N.A	N.A	N.A	N.A
RMS JK Jitter	High Speed	11.145 ps	Informative	N.A	N.A	N.A	N.A
ERROR MESSAGE	N.A						


[Back to Summary Table](#)

Paired KJ Jitter							
Measurement Details	Speed	Measured Value	Test Result	Margin	Low Limit	High Limit	Comments
Max KJ Jitter	High Speed	24.050 ps	Informative	N.A	N.A	N.A	N.A
Min KJ Jitter	High Speed	-40.498 ps	Informative	N.A	N.A	N.A	N.A
RMS KJ Jitter	High Speed	13.250 ps	Informative	N.A	N.A	N.A	N.A
ERROR MESSAGE	N.A						

[Back to Summary Table](#)

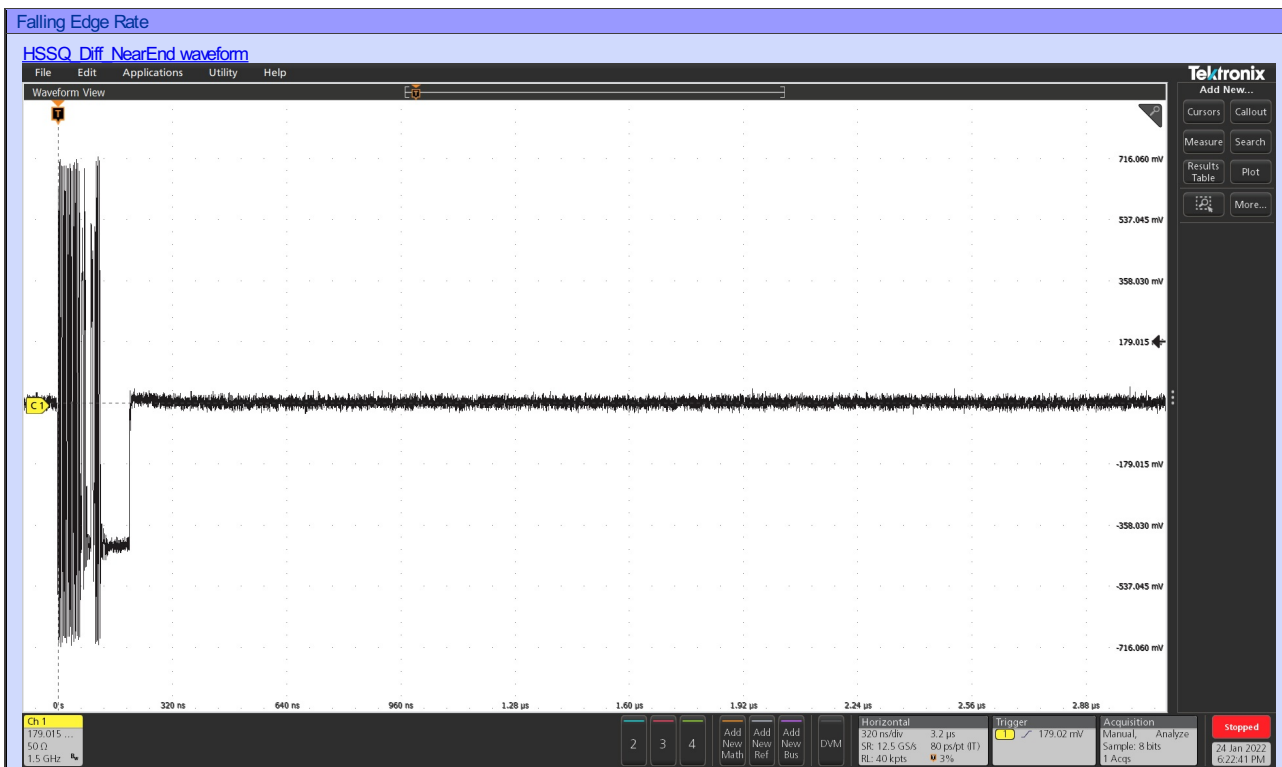

Eye Diagram for High Speed

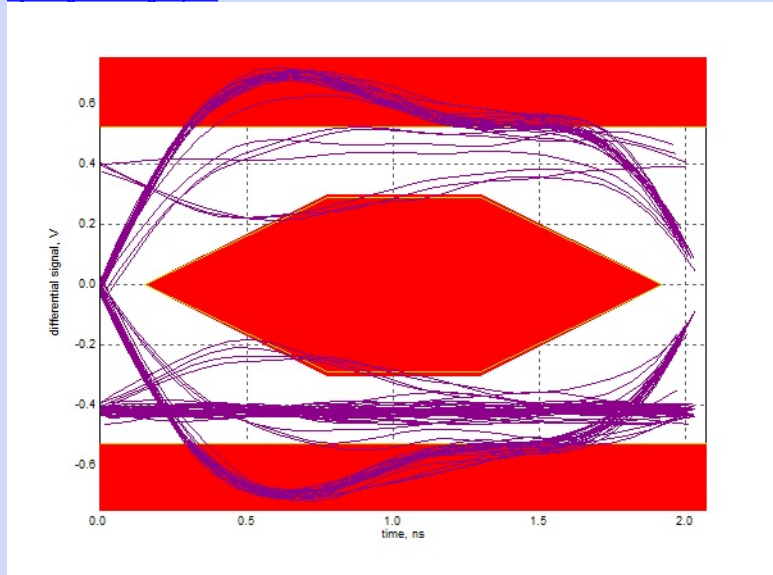

Waveform Plot for High Speed

