


Current RX Port Status

Port #	0	1
Linked:	33 MHz	No
Pass Sts:	Pass	No
Horizontal:	2948 bytes	
Vertical:	760 lines	
BC Rate:	2.50 Mbps	2.50 Mbps
EQ Hi/Lo:	0 / 2	6 / 7
S-Filter:	0 ddy	0 ddy
Lock Chg Cnt:	0	0
Parity Errs:	0	0
Encoder Errs:	0	0
Remote SER:	DS90UB953	DS90UB953
SER Revision:	0	0
SER I2C Address:	0xb4	0x00

$$= 33\text{MHz} / (2948/2) / 760$$

$$29.45797 \text{ Hz}$$

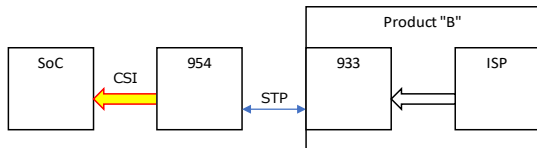

Current RX Port Status

Port #	0	1
Linked:	48 MHz	No
Pass Sts:	Pass	No
Horizontal:	2048 bytes	
Vertical:	720 lines	
BC Rate:	2.50 Mbps	2.50 Mbps
EQ Hi/Lo:	0 / 2	1 / 7
S-Filter:	0 ddy	0 ddy
Lock Chg Cnt:	0	0
Parity Errs:	0	0
Encoder Errs:	0	0
Remote SER:	DS90UB953	DS90UB953
SER Revision:	0	0
SER I2C Address:	0xb4	0x00

$$= 48\text{MHz} / (2048/2) / 720$$

$$65.10417 \text{ Hz}$$

