



Successful boot

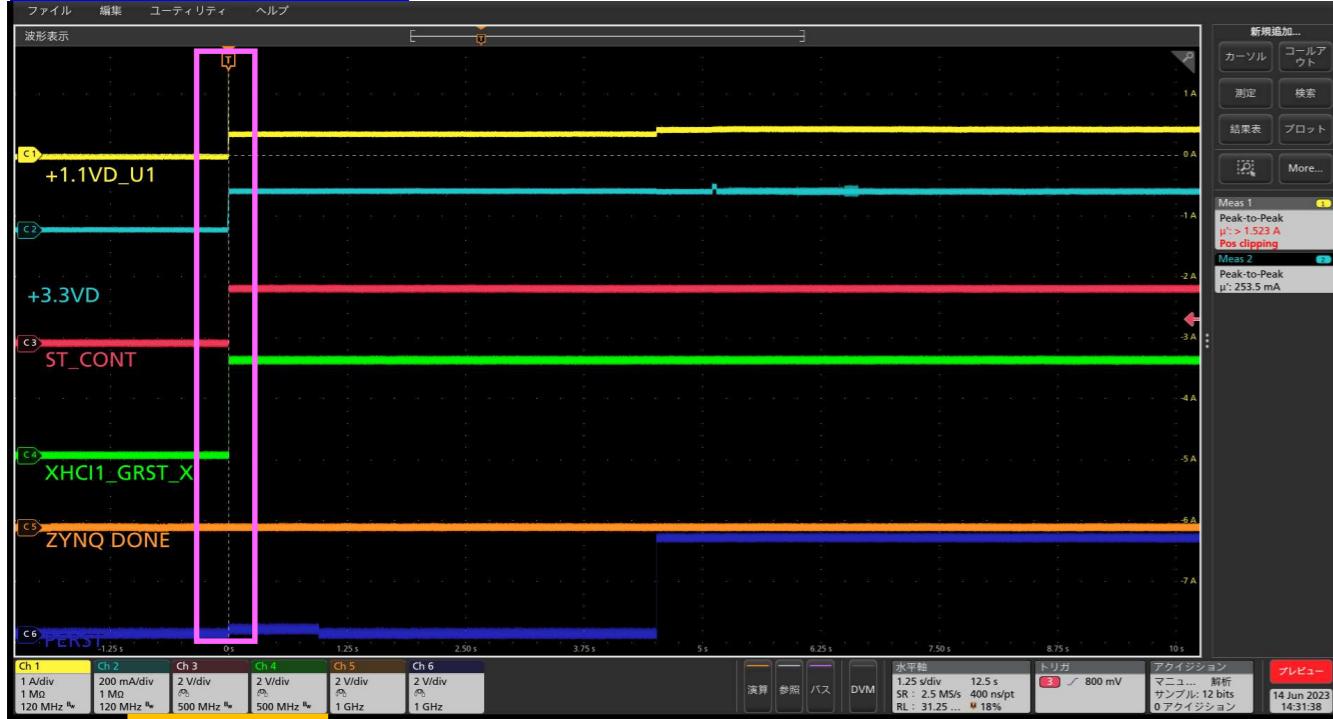

Enlarged waveform

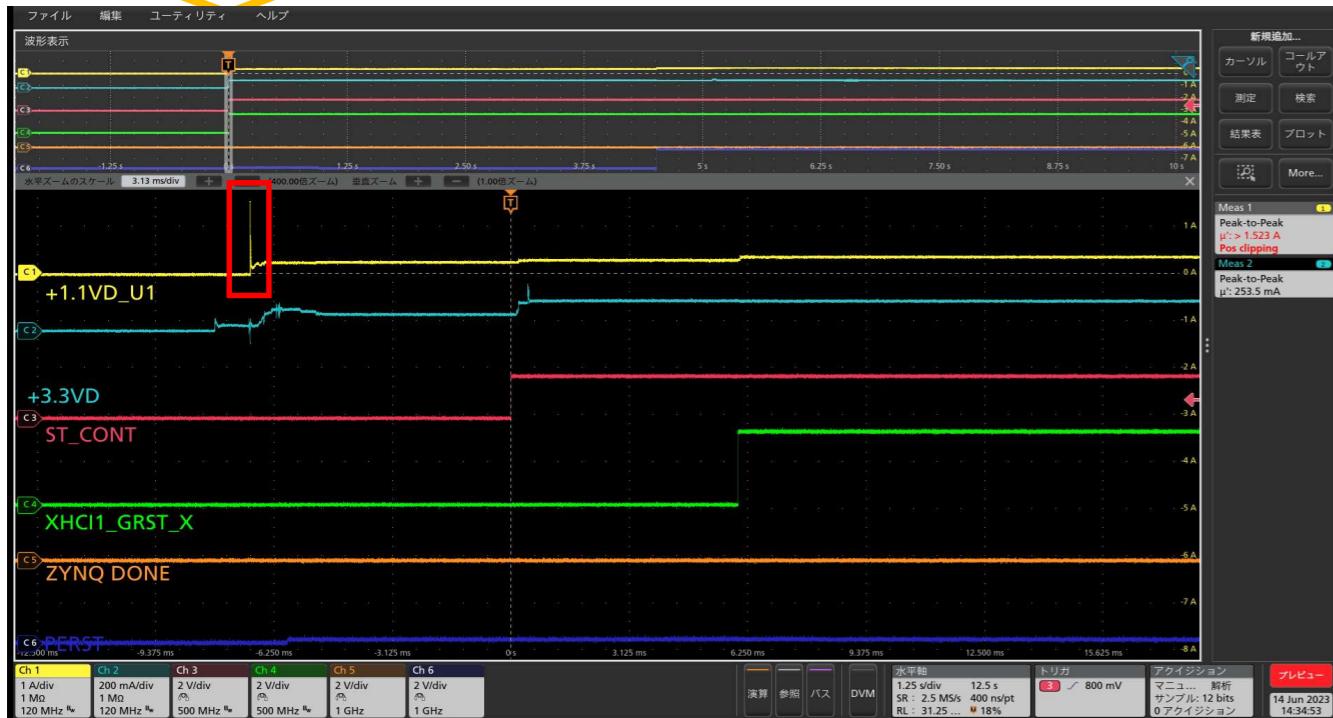

Signal description (measuring point)

CH1 : +1.1VD_U1

Power supply input to VDD11 pin of TUSB7320. (**Measure the Current value**)

CH2 : +3.3VD

Power supply input to VDD33 pin of TUSB7320. (**Measure the Current value**)


CH4 : XHCI1_GRST_X

Signal input to the GRST pin of the TUSB7320. (Measure the Voltage value)

CH6 : PERST

Signal input to the PERST pin of the TUSB7320. (Measure the Voltage value)

Failure boot

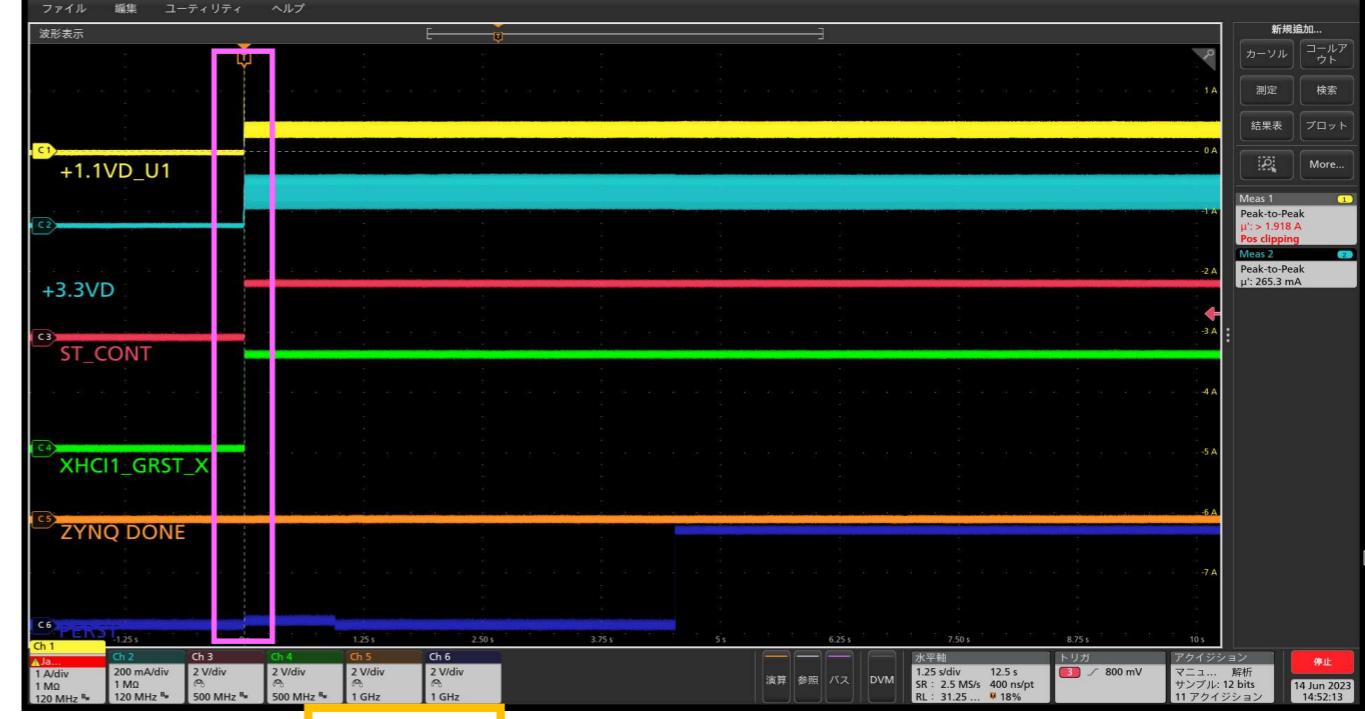

Enlarged waveform

