


GRST waveform

Signal description

Ch1 : 1.1V (Voltage)

CH2 : 3.3V (Voltage)

CH3 : XHCI1_GRST_X (Voltage)

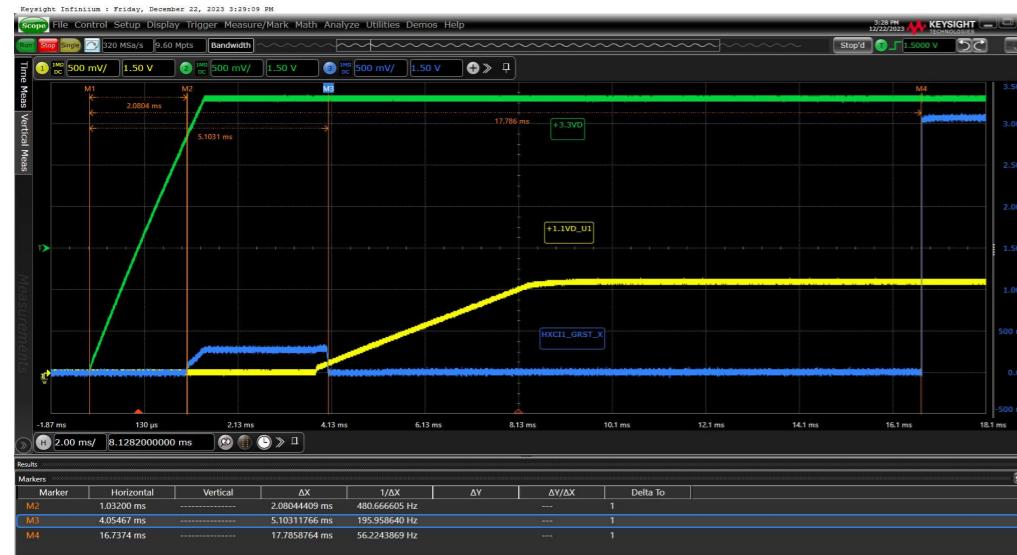


Current measurement (No failures in 200 attempts)

Signal description

Ch1 : 1.1V (Voltage)

CH2 : 3.3V (Voltage)

CH3 : 1.1V (Current)

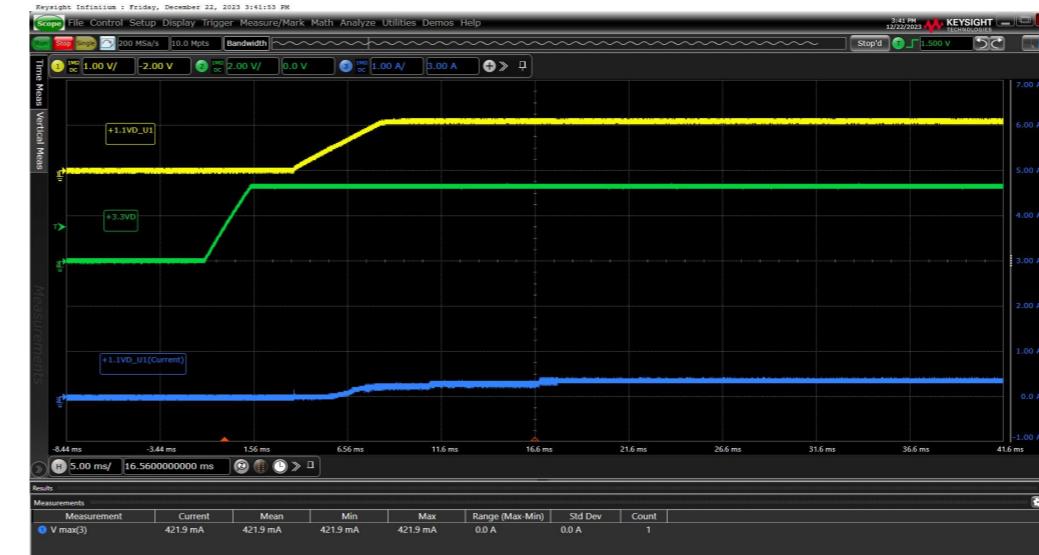

Current measurement (105 failures out of 200 attempts)

Signal description

Ch1 : 1.1V (Voltage)

CH2 : 3.3V (Voltage)

CH3 : 1.1V (Current)

When failure occurs, inrush current (about 2.5A) occurs.

