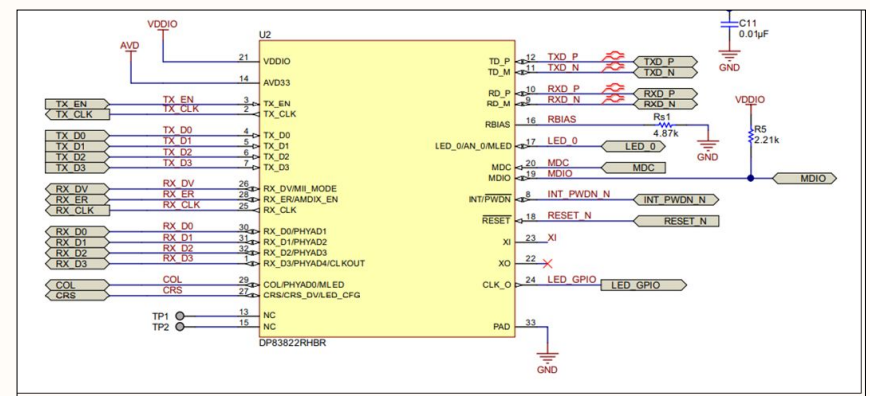
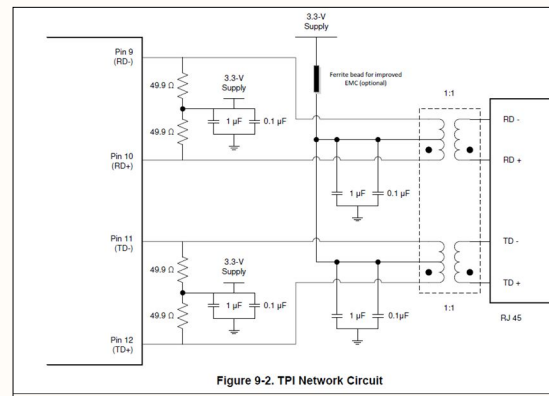
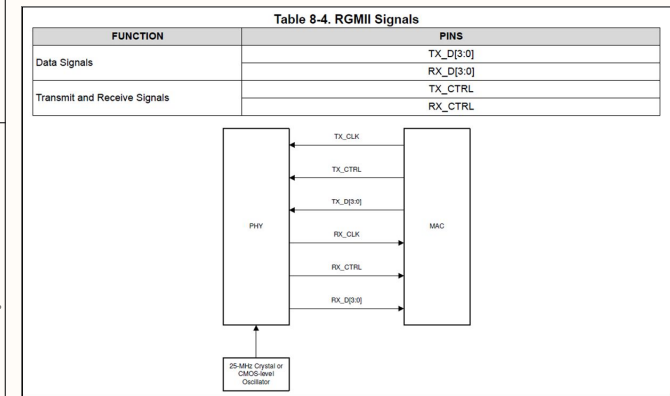


DP83822 EVM

Quantity	LibRef	Footprint	Designator	Description	Comment
2	C	cap196	C1, C6		10uF
4	C	cap196	C2, C7, C11, C13		1uF
4	C	cap196	C3, C8, C12, C14		0.1uF
3	C	cap196	C4, C5, C9		10nF
1	CAP NP	CAP_1210	C10		22uF
2	C	cap196	C15, C16		22pF
2	C_Dup1	cap196	C17, C18		1nF / 2KV
1	C	cap196	C19		4.7nF
4	LED	LED_0402	D1, D2, D3, D4		GREEN LED
1	TPD4E05U06DQAR	DQA_R-PUSON-N10_	D5	4-Channel Ultra-Low-Capacitance IEC ESD Protection Diode	TPD4E05U06DQAR
1	CMP-03371-000021-1	FP-1-406541-1-MFG	J1	CONN MOD JACK 8P8C R/A SHIELDED	1-406541-1
7	R_Dup1	AXRC05	R1, R2, R5, R6, R7, R10, R11		2.49K
4	R_Dup1	AXRC05	R3, R4, R8, R9		470
10	R_Dup1	AXRC05	R12, R17, R29, R30, R31, R32, R33, R34, R35, R36		0
4	R_Dup1	AXRC05	R13, R14, R15, R16		2.2K
4	R_Dup1	AXRC05	R18, R19, R20, R21		49.9
7	R_Dup1	AXRC05	R22, R23, R24, R25, R26, R27, R28		33
1	R_Dup1	AXRC05	R37		4.87K
4	R_Dup1	AXRC05	R38, R39, R40, R41		75
1	HVCB2010FKC1M00_0	RESC5125X76N	R42	RES, HV, 2010, 1 Mohm, 1%, 50 ppm, 1W	1M / 1W
1	HX1188FNLT_3	HX1188FNLT	T1	Audio Transformers / Signal Transformers 100BaseTX SMD NonPoE 350uH 1-Port	HX1188FNLT
1	94b435a900d85aeb e30a92c465df140	FP-RHB0032B-MFG	U1	IC INTERFACE SPECIALIZED 32VQFN	DP83822IRHBT
1	ABM8AIG-25_0.000MHZ-12-2Z-T3	ABM8AIG25000MH Z122ZT3	Y1	Crystals 25MHz AECQ200 12pF 20ppm -40C +125C	ECS-250-12-33Q-JES-TR