


Configuration - ISO3086

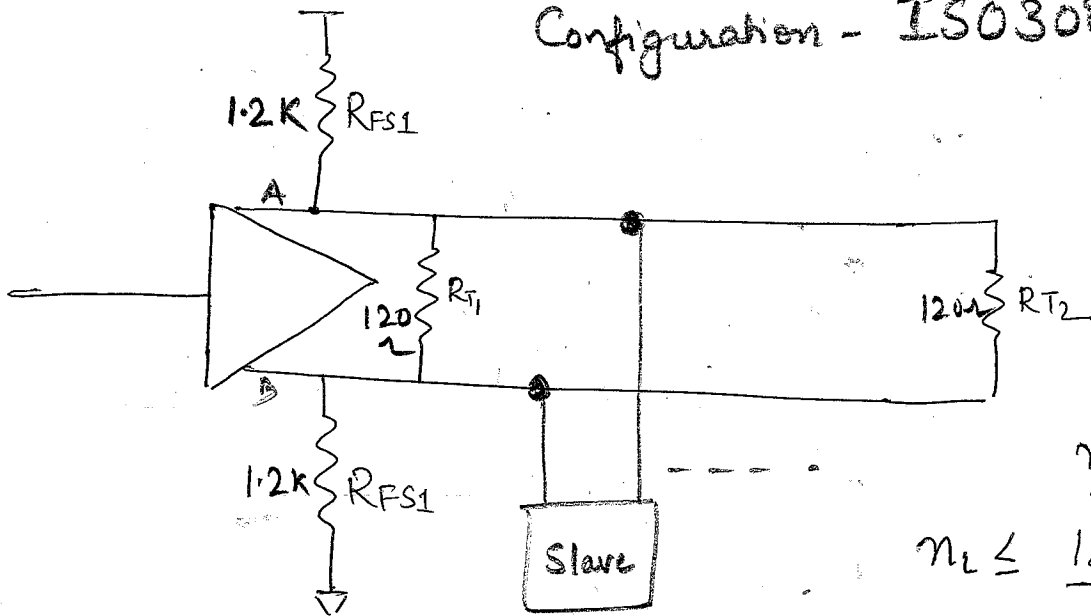

max Load units

$$n_L \leq \frac{12K\Omega}{U_L} \left[\frac{1}{375} - \frac{1}{R_{FS1}} \right]$$

for $U_L = 1/8$

$$n_L \approx 176$$

Fig 1

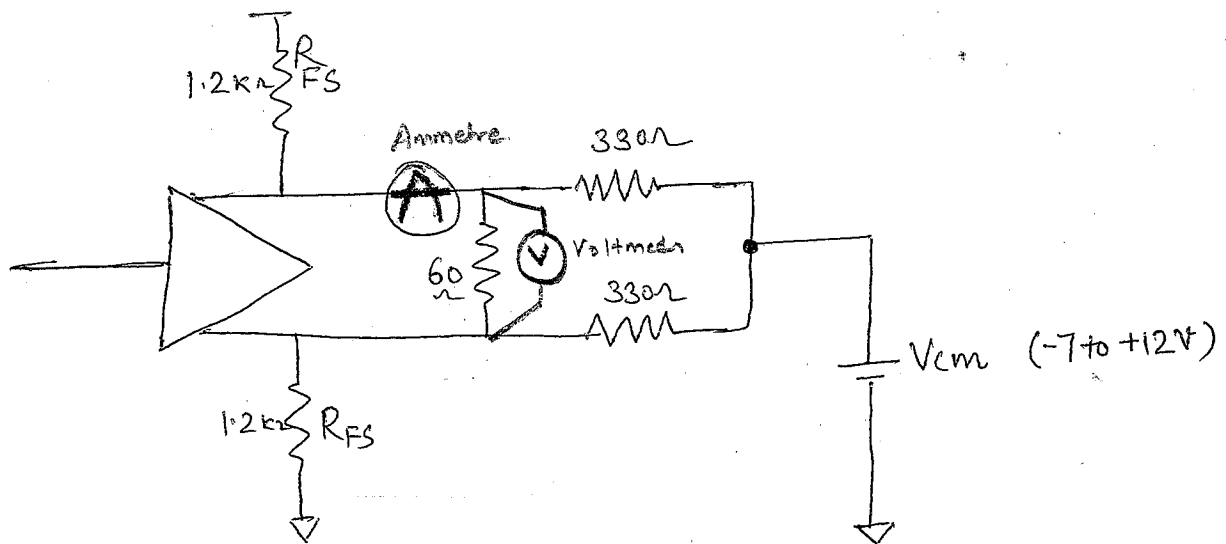


Fig 2

Q: How to verify max. Load (units) value?