
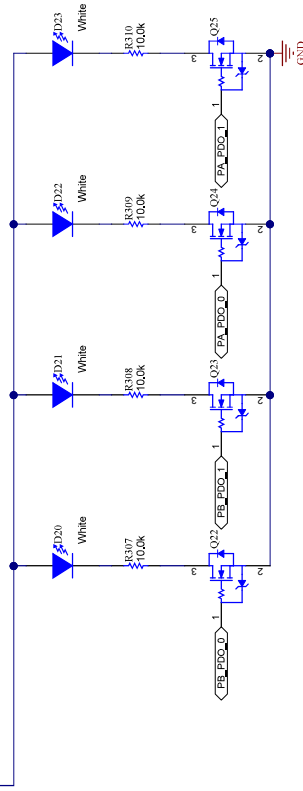
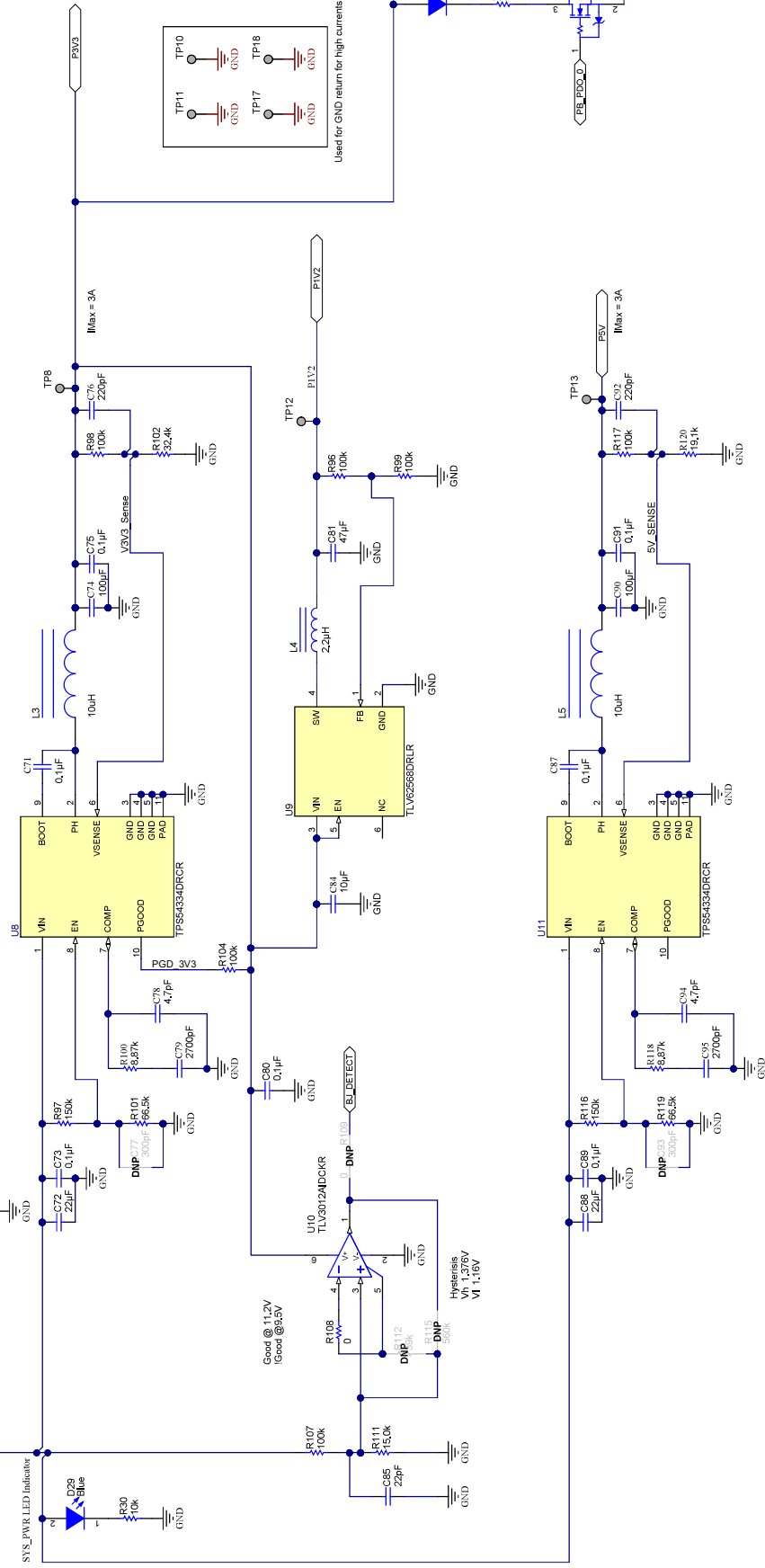


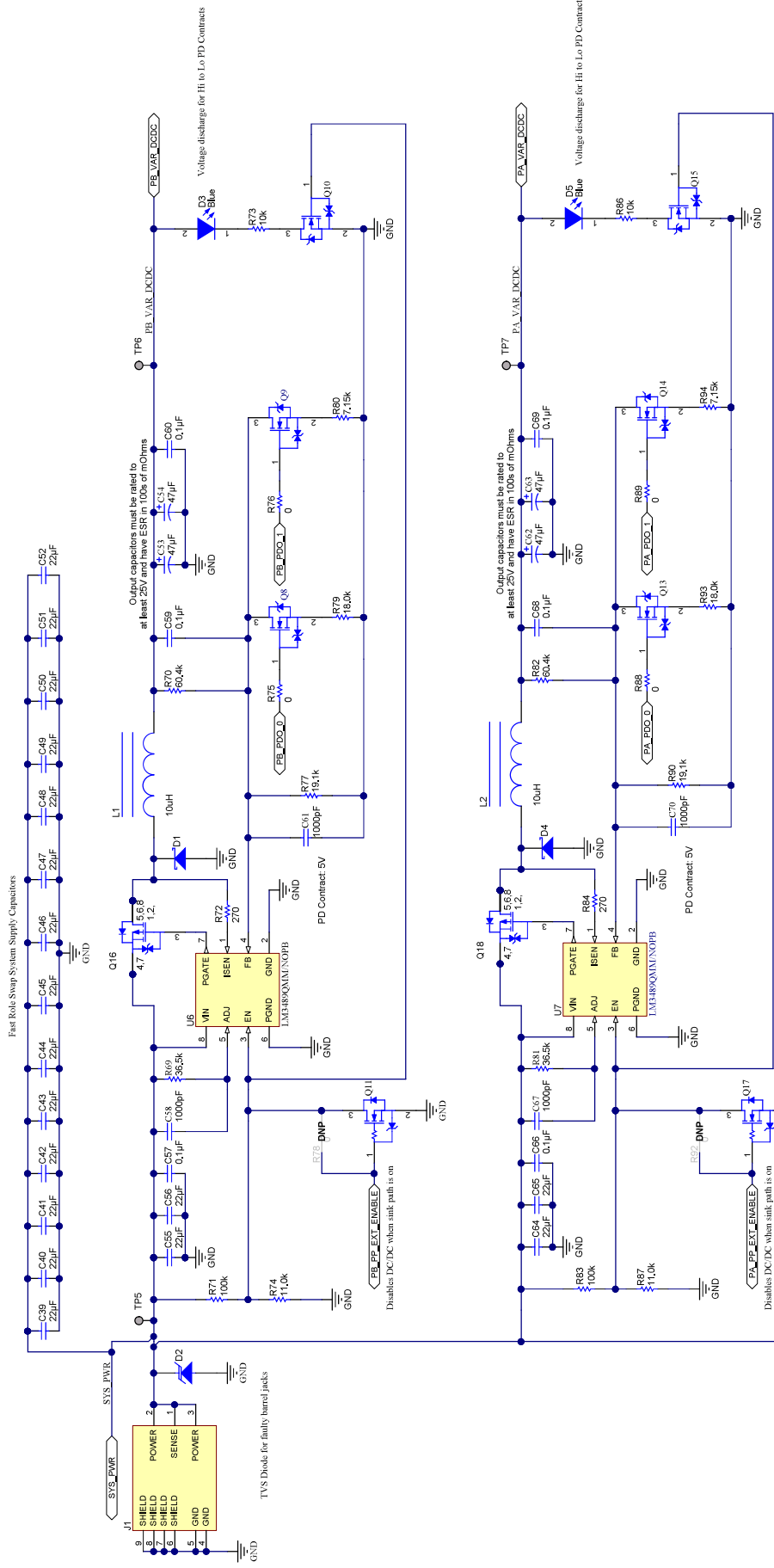

|   | PDO_0 | PDO_1 | Output Voltage | Feedback (R1) | Feedback (R2) | Output Voltage |
|---|-------|-------|----------------|---------------|---------------|----------------|
| 1 | 0     | 0     | 5V             | 60.4k         | 19.1k         | 5.15V          |
| 2 | 0     | 1     | 9V             | 60.4k         | 9.27k         | 9.26V          |
| 3 | 1     | 0     | 15V            | 60.4k         | 5.2k          | 15.62V         |
| 4 | 1     | 1     | 20V            | 60.4k         | 4.04k         | 19.78V         |