

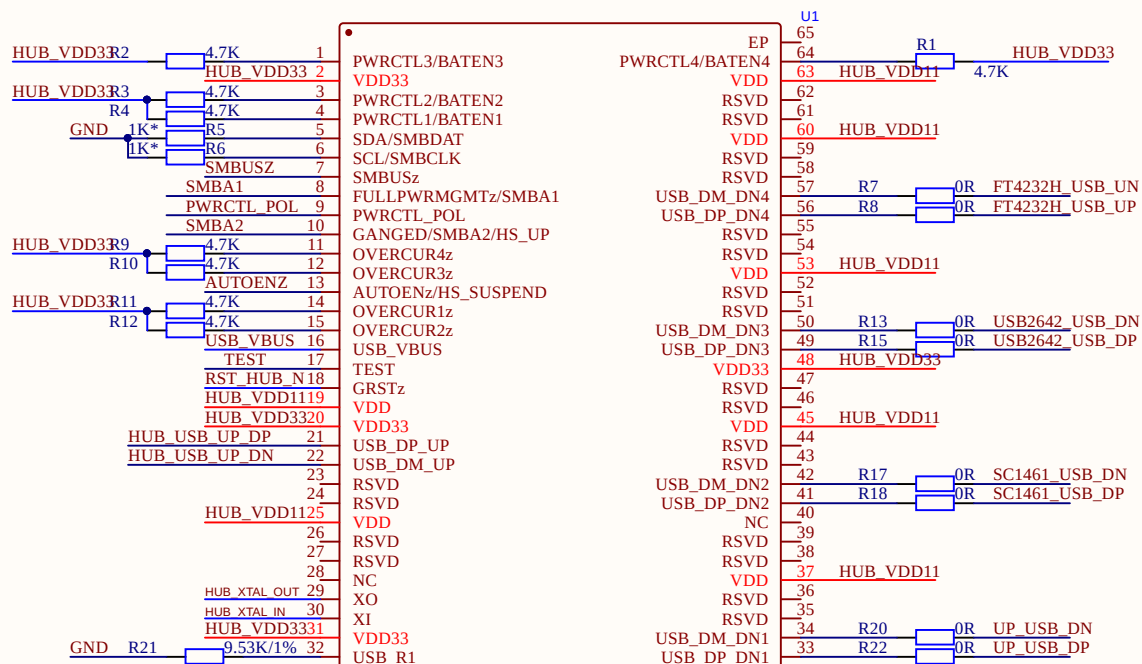
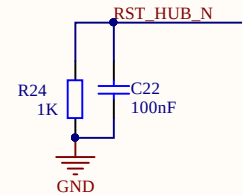
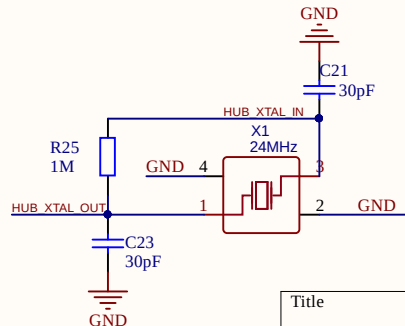
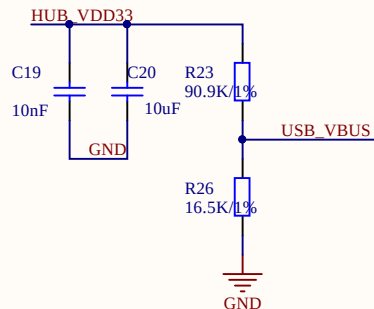
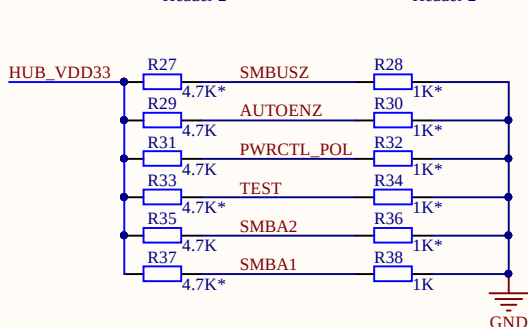
 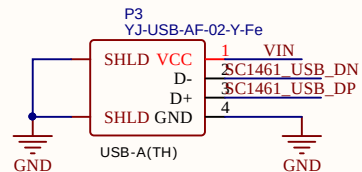
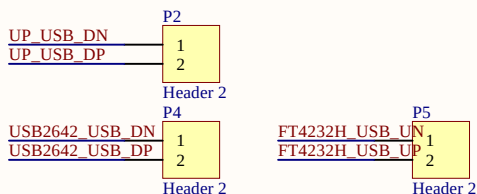

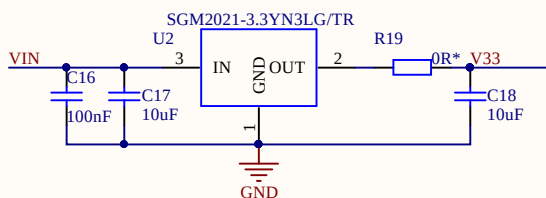
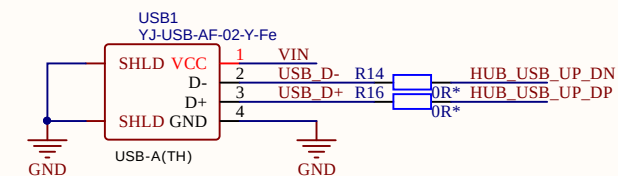
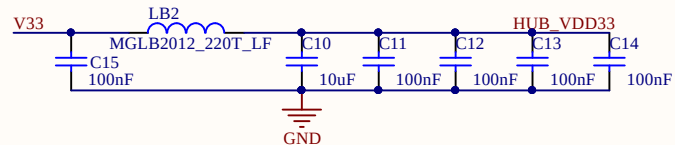


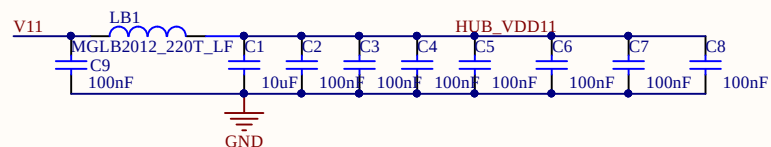


Title		
Size	Number	Revision
A4		
Date:	2021/3/5	Sheet of
File:	F:\SH\...\TUSB4041-TEST.SchDoc	Drawn By:

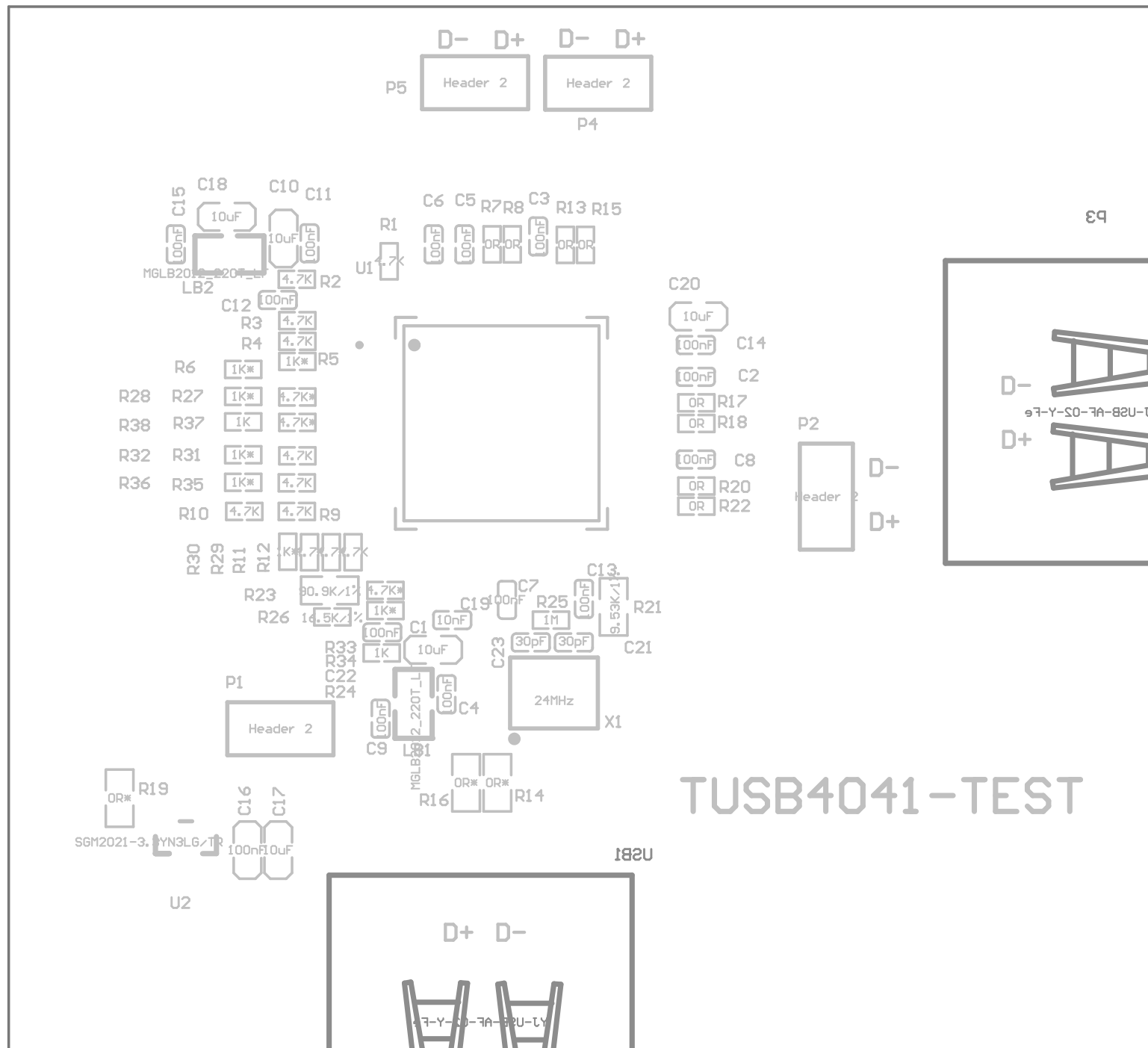


TUSB4041-TEST

89

D-
D+

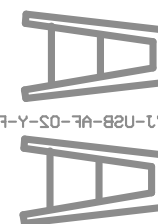

D+ D-

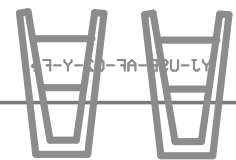

Comment	Description	Designator	Footprint	LibRef	Quantity
10uF	Capacitor	C1, C10, C17, C18, C20	0603C	Cap	5
100nF	Capacitor	C2, C3, C4, C5, C6, C7, C8, C9, C11, C12, C13, C14, C15, C22	0402C	Cap	14
100nF	Capacitor	C16	0603C	Cap	1
10nF	Capacitor	C19	0402C	Cap	1
30pF	Capacitor	C21, C23	0402C	Cap	2
MGLB2012_220T_LF	Inductor	LB1, LB2	0805	Inductor	2
Header 2	Header, 2-Pin	P1, P2, P4, P5	HDR1X2	Header 2	4
YJ-USB-AF-02-Y-Fe		P3, USB1	USB-A	YJ-USB-AF-02-Y-Fe	2
4.7K	Resistor	R1, R2, R3, R4, R9, R10, R11, R12, R29, R31, R35	0402	Res2	11
1K*	Resistor	R5, R6, R28, R30, R32, R34, R36	0402	Res2	7
0R	Resistor	R7, R8, R13, R15, R17, R18, R20, R22	0402	Res2	8
0R*	Resistor	R14, R16, R19	0603R	Res2	3
9.53K/1%	Resistor	R21	0603R	Res2	1
90.9K/1%	Resistor	R23	0603R	Res2	1
1K	Resistor	R24, R38	0402	Res2	2
1M	Resistor	R25	0402	Res2	1
16.5K/1%	Resistor	R26	0402	Res2	1
4.7K*	Resistor	R27, R33, R37	0402	Res2	3
		U1	TUSB4041IPAPR	TUSB4041IPAPR	1
SGM2021-		U2	SOT-23	SGM2021-1.8YN3G/TR	1
24MHz		X1	SMD2520-4P	24MHz	1