


RxCikIn vs DOUT

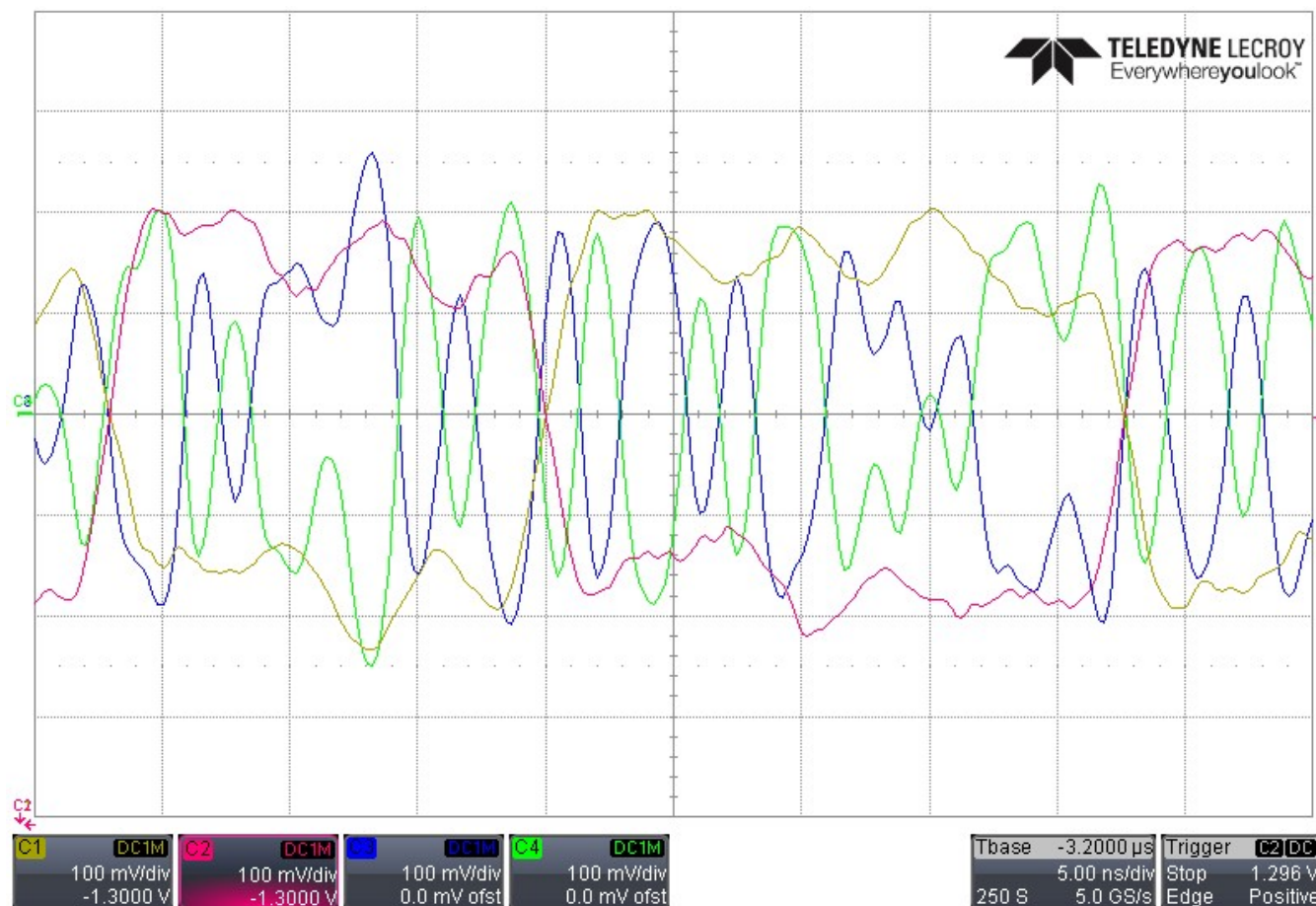

Channel Status

| | C1 | C2 | C3 | C4 |
|----------|---------------|---------------|---------------|---------------|
| V / Div | 100 mV | 100 mV | 100 mV | 100 mV |
| Offset | -1.3000 V | -1.3000 V | 0.0 mV | 0.0 mV |
| Coupling | DC1M Ω | DC1M Ω | DC1M Ω | DC1M Ω |
| BW-Limit | Full | Full | Full | Full |
| Probe | 10 | 10 | 10 | 10 |
| Sweeps | 1 # | 1 # | 1 # | 1 # |

Acquisition Status

| | | | |
|------------|---------|---------------|-----------------|
| Time / Div | 5.00 ns | Sampling Rate | 5.0 GS/s |
| Time / Pt | 200 ps | Sampling Mode | RealTime |
| Pts / Div | 25.0 S | Trigger Delay | -3.2000 μ s |
| Mode | Stop | Slope | Positive |
| Type | Edge | Level | 1.296 V |
| Source | C2 | Coupling | DC |

