


RxCikIn vs DOUT

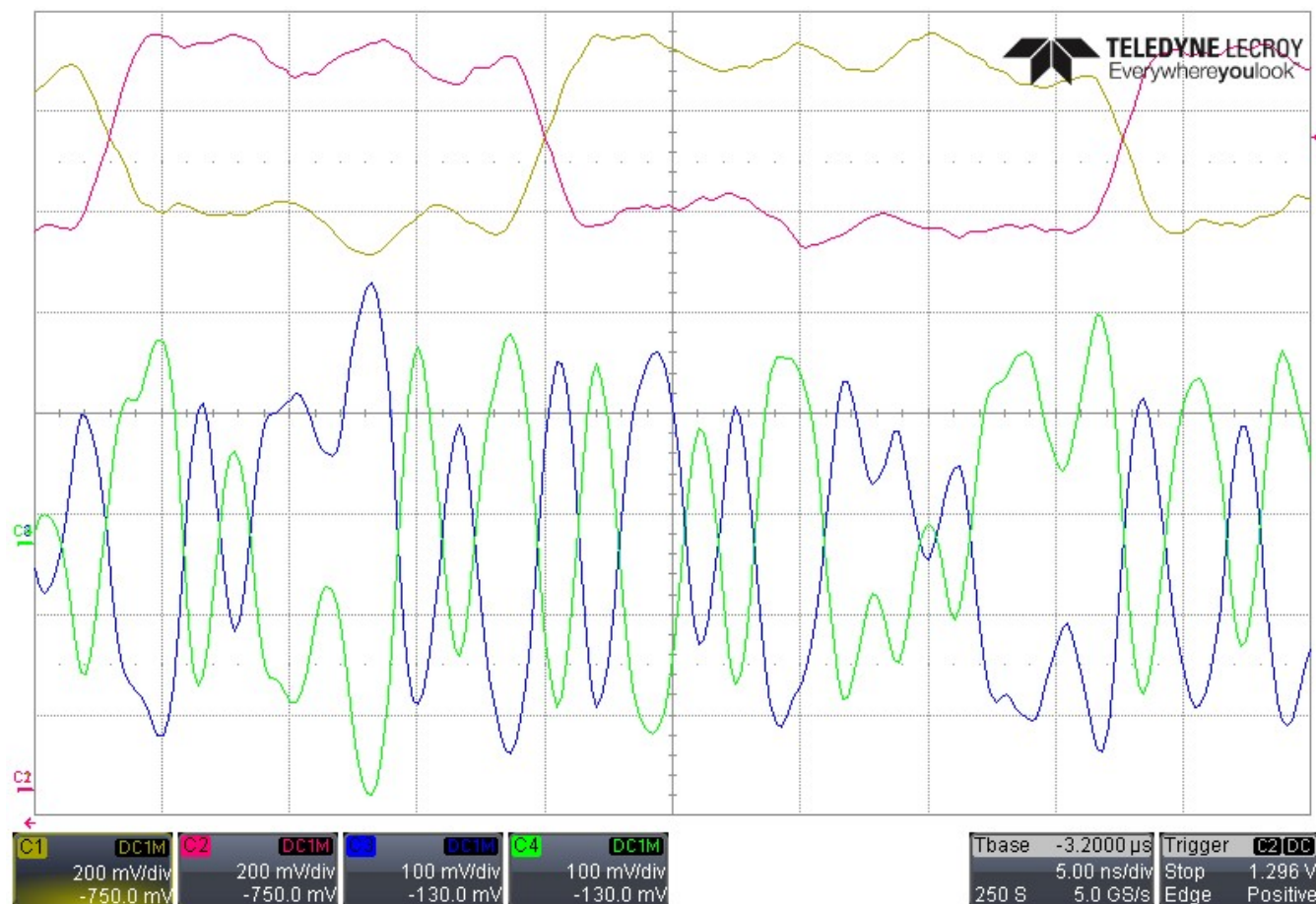

Channel Status

	C1	C2	C3	C4
V / Div	200 mV	200 mV	100 mV	100 mV
Offset	-750.0 mV	-750.0 mV	-130.0 mV	-130.0 mV
Coupling	DC1M Ω	DC1M Ω	DC1M Ω	DC1M Ω
BW-Limit	Full	Full	Full	Full
Probe	10	10	10	10
Sweeps	1 #	1 #	1 #	1 #

Acquisition Status

	Time / Div	5.00 ns	Sampling Rate	5.0 GS/s
Horizontal	Time / Pt	200 ps	Sampling Mode	RealTime
	Pts / Div	25.0 S	Trigger Delay	-3.2000 μ s
	Mode	Stop	Slope	Positive
Trigger	Type	Edge	Level	1.296 V
	Source	C2	Coupling	DC

