


TxCikOut

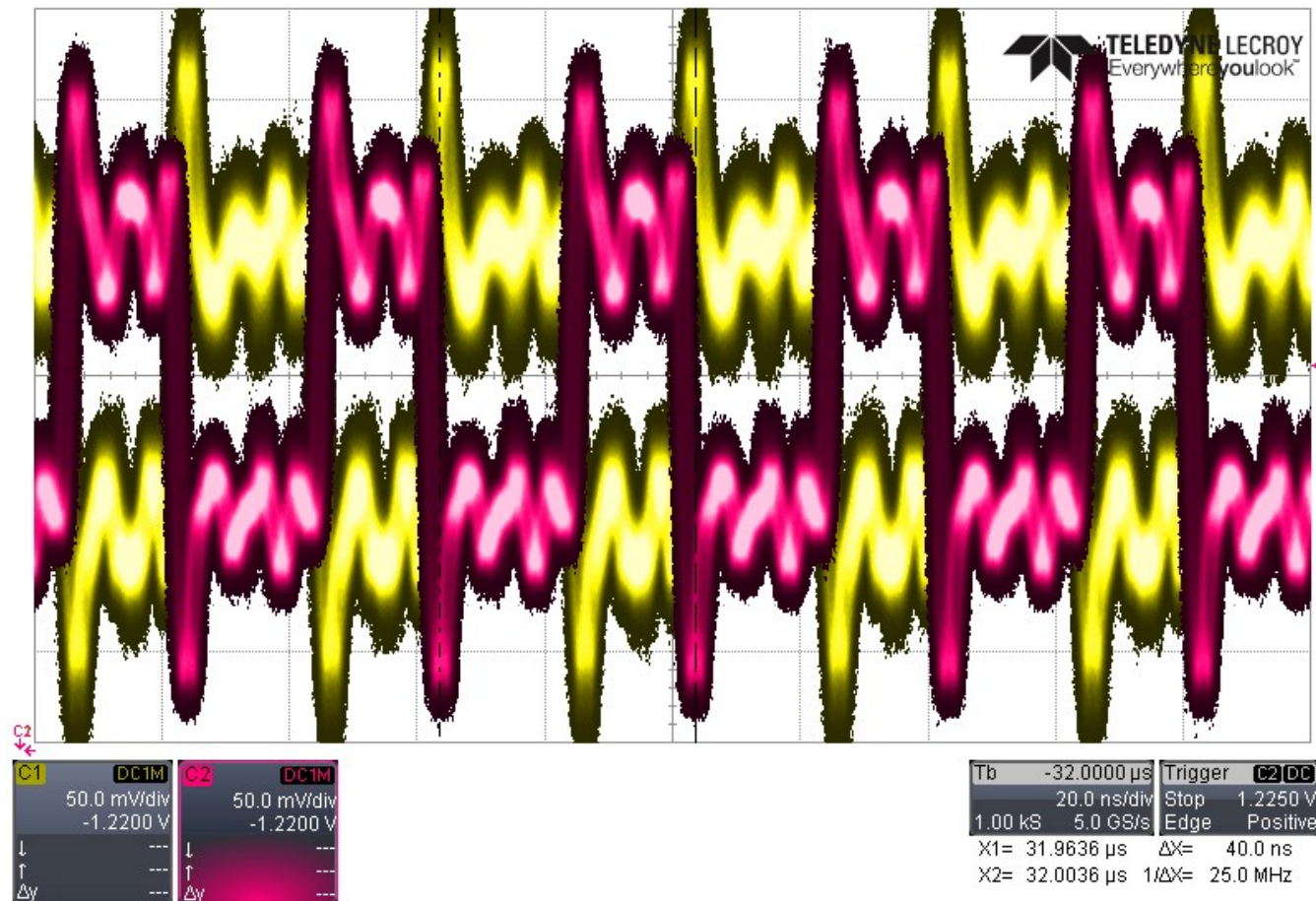

Channel Status

	C1	C2
V / Div	50.0 mV	50.0 mV
Offset	-1.2200 V	-1.2200 V
Coupling	DC1MΩ	DC1MΩ
BW-Limit	Full	Full
Probe	10	10
Sweeps	1 #	1 #

Acquisition Status

	Time / Div	20.0 ns	Sampling Rate	5.0 GS/s
Horizontal	Time / Pt	200 ps	Sampling Mode	RealTime
	Pts / Div	100.0 S	Trigger Delay	-32.0000 μs
	Mode	Stop	Slope	Positive
Trigger	Type	Edge	Level	1.2250 V
	Source	C2	Coupling	DC

