

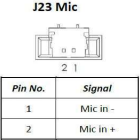


Audio DAC

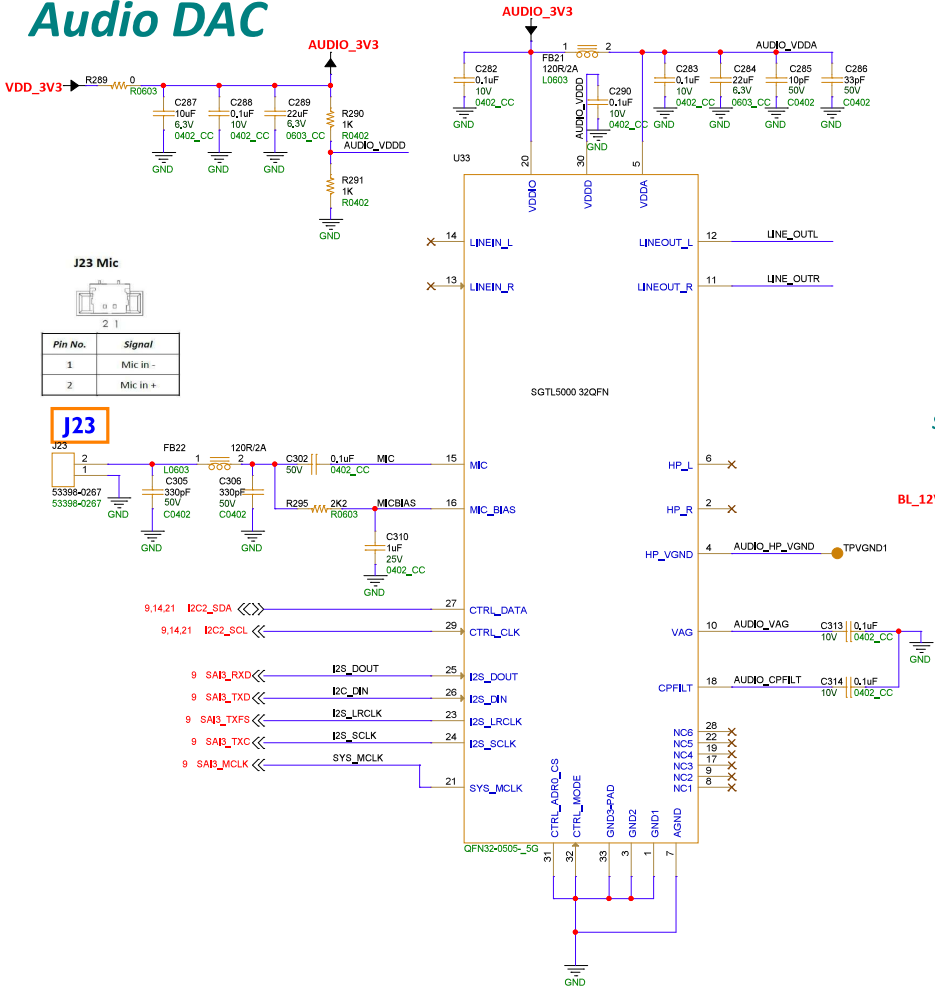


J23


STB/Mute

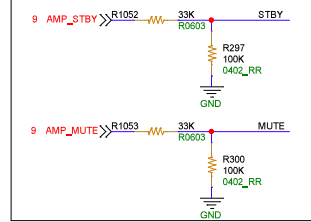

Gain

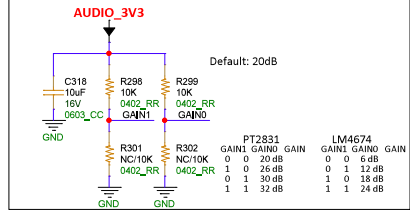




SPK Output

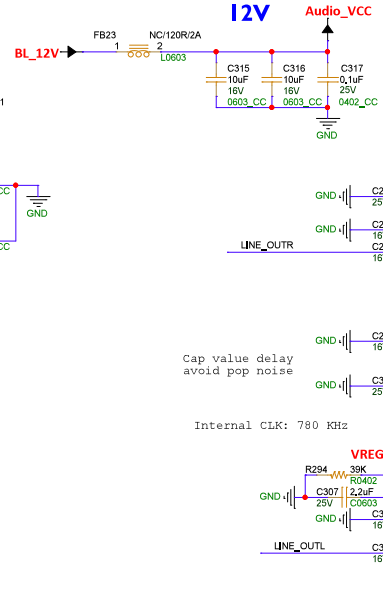


LC Filter components			
R _{load}	L1, L2, L3, L4	C15, C16	
4Ω	15uH	470nF	
6Ω	22uH	220nF	
8Ω	33uH	220nF	

Mode	STBY	Mute	OE
Standby	L	X	X
Mute 1	H	L	X
Mute 2	X	X	L
Normal	H	H	H*

*Drive level defined in Electrical specifications

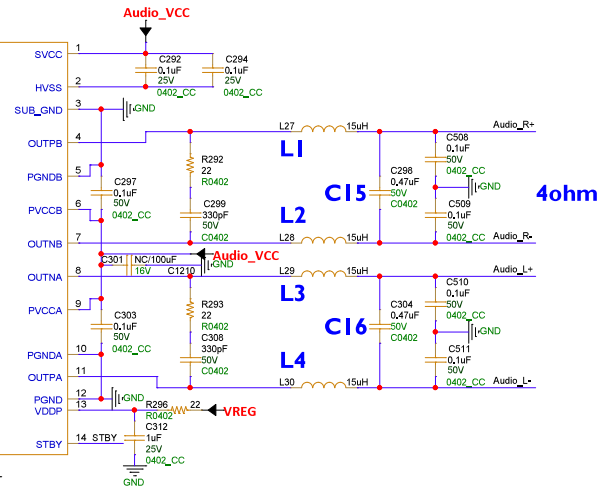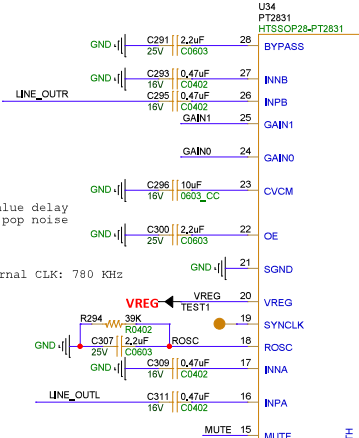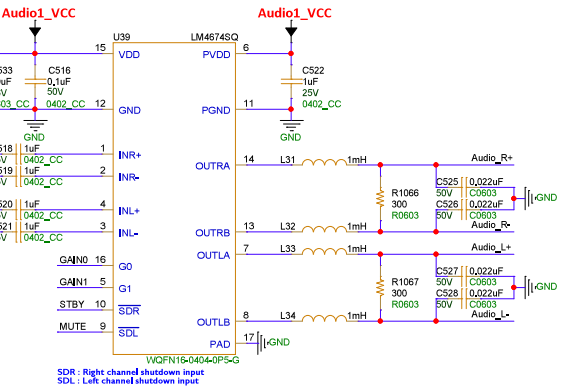

J4

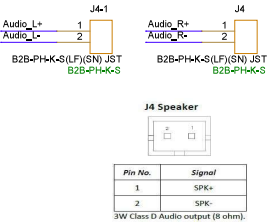

Pin No.	Signal
1	SPK+
2	SPK-

3W Class D Audio output (8 ohm).