



LMH730216 Rev. D

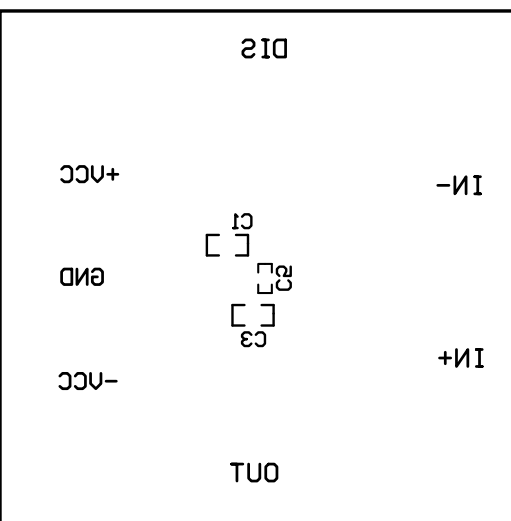

LMH730216 Rev. D

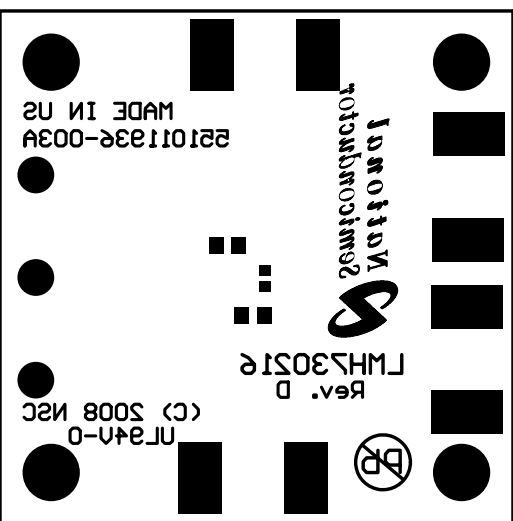


MADE IN US
22101133E-003A


Rev. D
LMH730216
NSC 5008 (C)
0-0




LMH730216 Rev. D

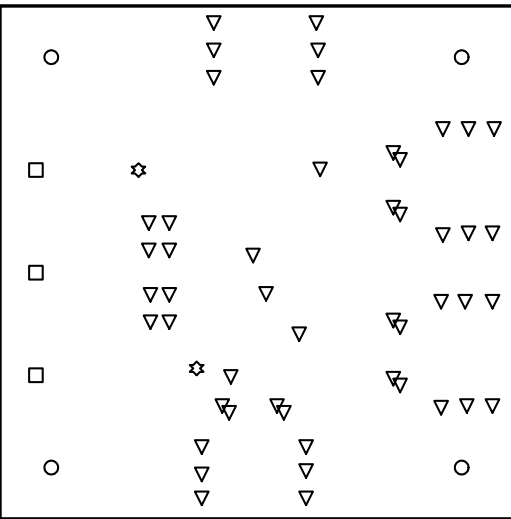


Symbol	Hit Count	Tool Size	Plated	Hole Type
▽	49	10m1 (0.254mm)	PTH	Round
☆	2	15m1 (0.381mm)	PTH	Round
□	3	60m1 (1.524mm)	PTH	Round
○	4	120m1 (3.048mm)	PTH	Round
	58 Total			

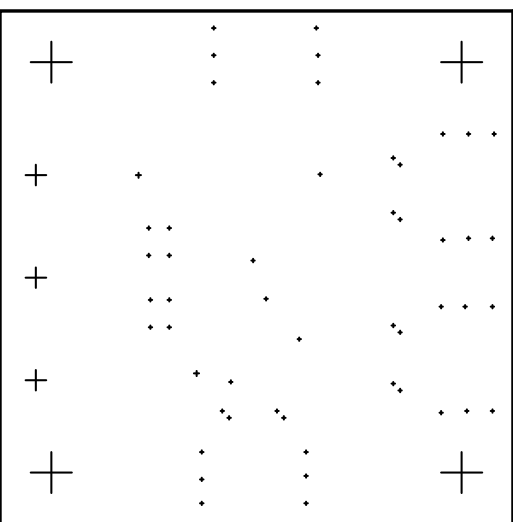


LMH730216 Rev. D

 


LMH730216 Rev. D

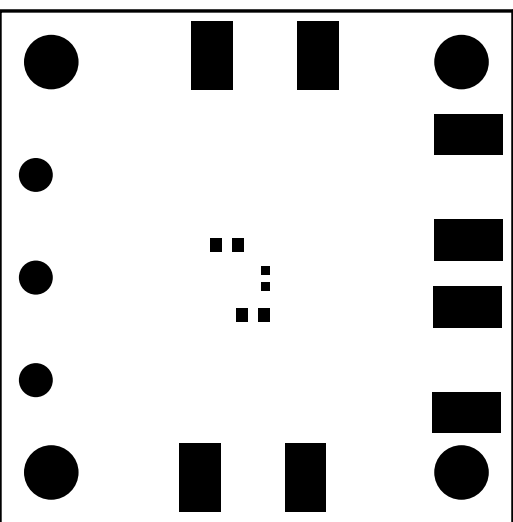


LMH730216 Rev. D

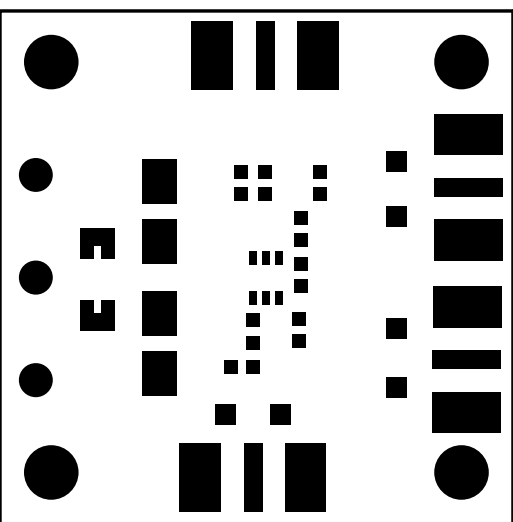


LMH730216 Rev. D

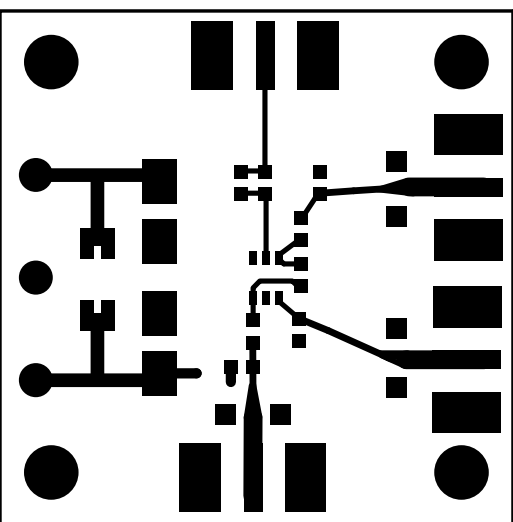

LMH730216 Rev. D

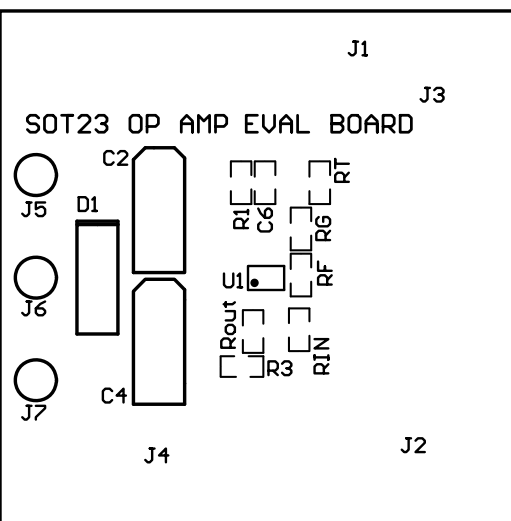

LMH730216 Rev. D

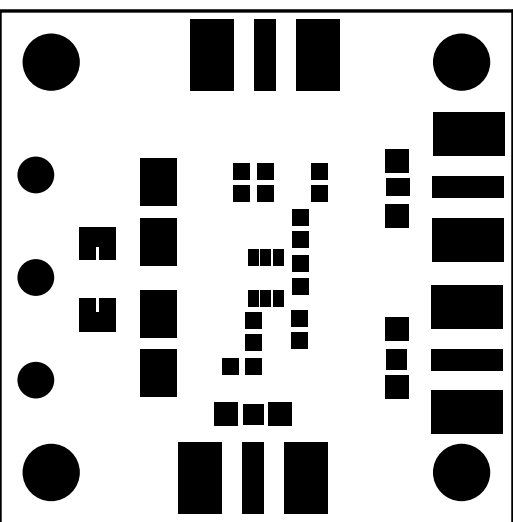

LMH730216 Rev. D

