


Trc2 — S11 Smith 200 mV/Ref 1 U Cal

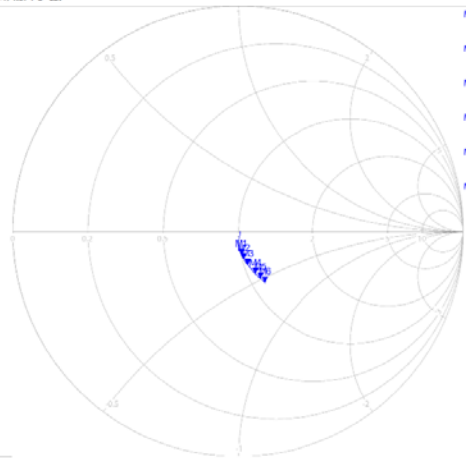


Ch2 Start 1 MHz

Pwr -20 dBm Bw 5 kHz

Stop 1 GHz

Trc3 — S22 Smith 200 mV/Ref 1 U Cal

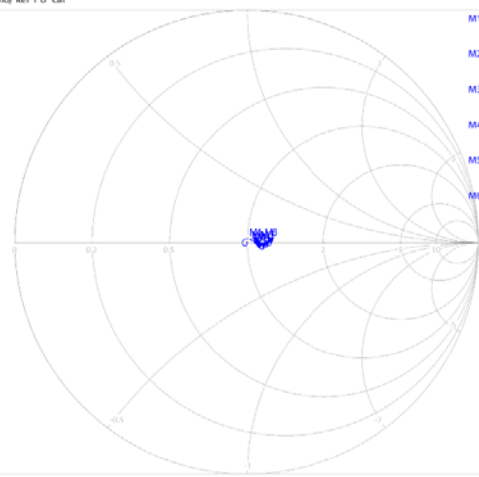


Ch3 Start 1 MHz

Pwr -20 dBm Bw 5 kHz

Stop 1 GHz

Trc1 — S21 dB Mag 1 dB/Ref 16 dB Cal

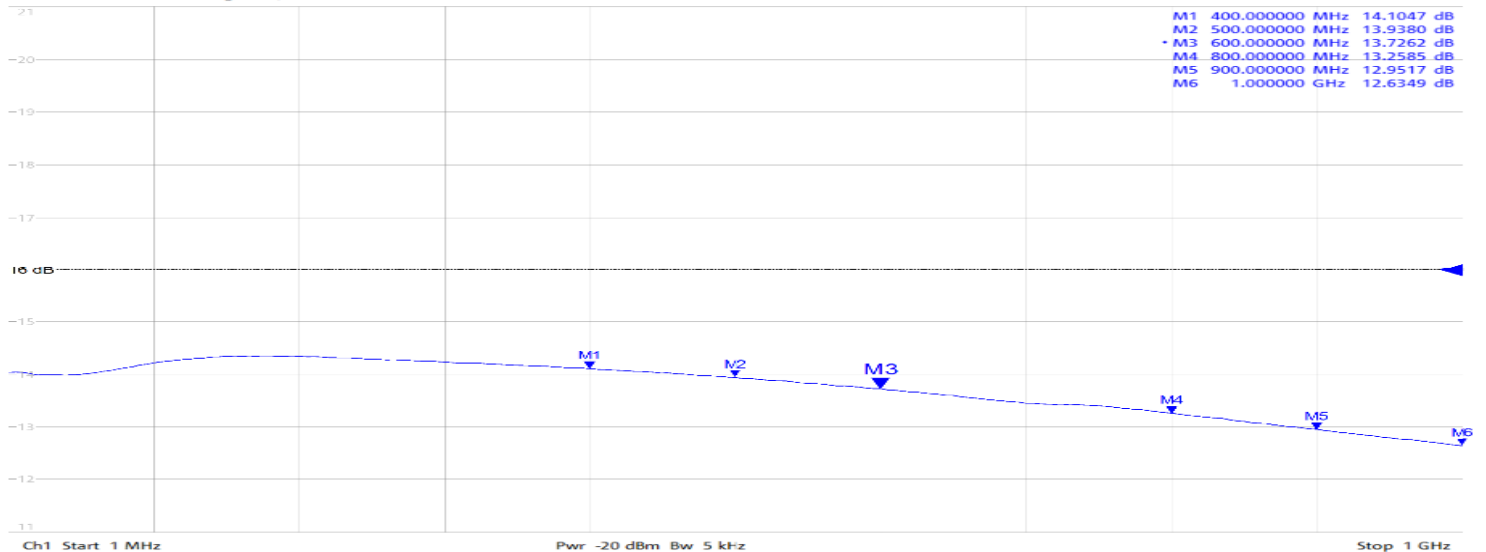

Ch1 Start 1 MHz

Pwr -20 dBm Bw 5 kHz

Stop 1 GHz

