

VINA:
Min: 0.8VDC
Max: 4.5VDC


VINB:
Min: 1.8VDC
Max: 5.5VDC

Propagation Delay = 1.5nS
Operating Temperature = -40C to +125C


VINB > VINA + 0.8V

**Applications: GPIO, MDIO, PMBus,
SMBus, SDIO, UART, I2C**


Input

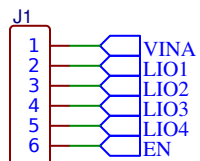

Circuit

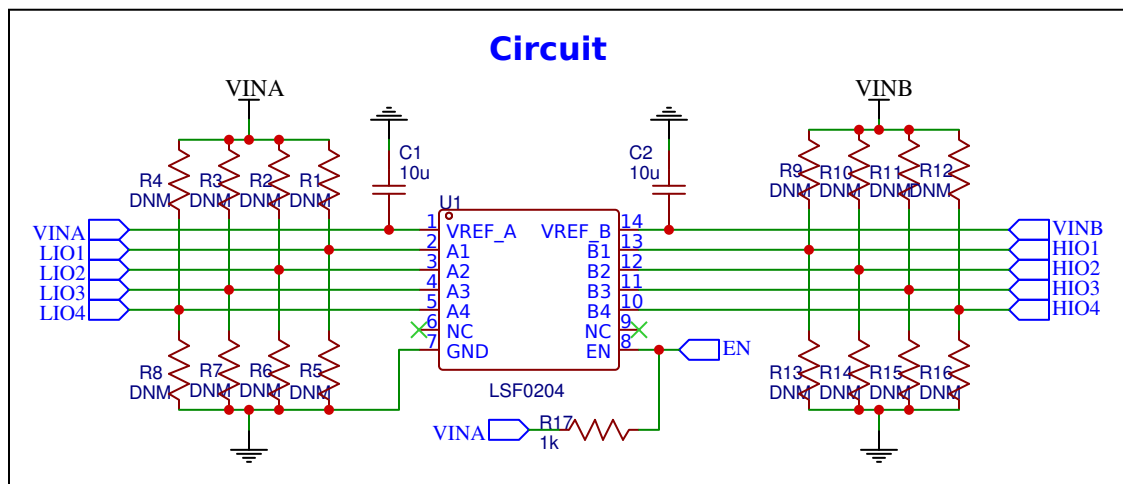

Output

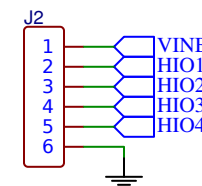

TITLE:
Level Shifter - 4 Channel

REV: 1.0

Date: 2018-08-05

Sheet: 1/1

EasyEDA V5.6.15

Drawn By: Teja Chintalapati