


LVC1G14 D-DIE ICCI (5.50,-40 C)

Pin: 2 Comment: ICC VS VIN A


Material: 01

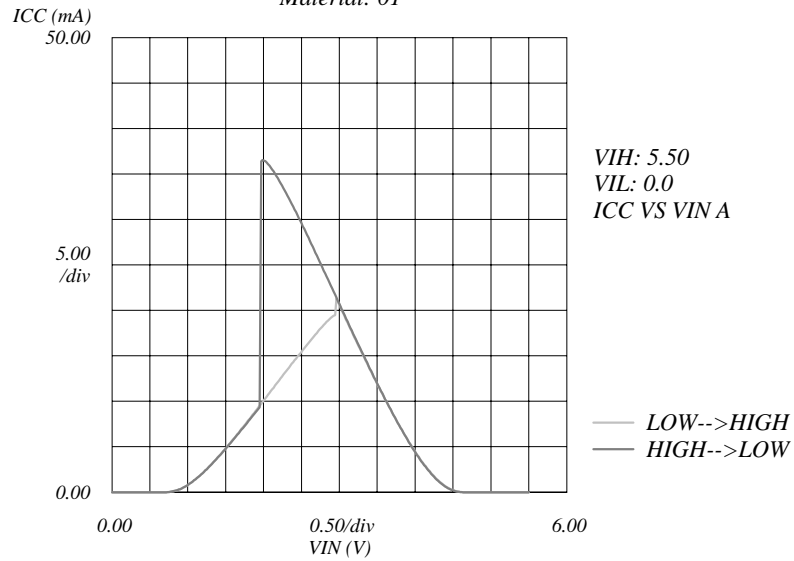

LVC1G14 D-DIE ICCI (5.50,-40 C)

Pin: 2 Comment: ICC VS VIN A


Material: 02

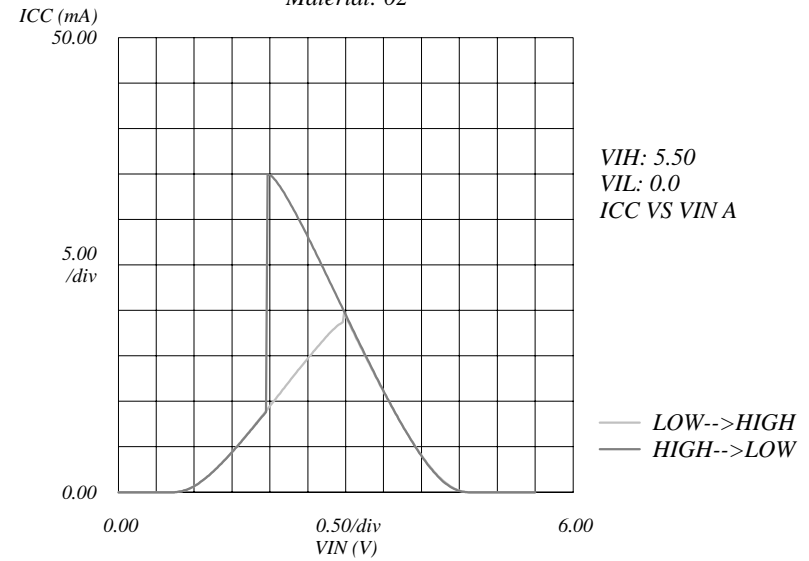

LVC1G14 D-DIE ICCI (5.50,-40 C)

Pin: 2 Comment: ICC VS VIN A


Material: 03

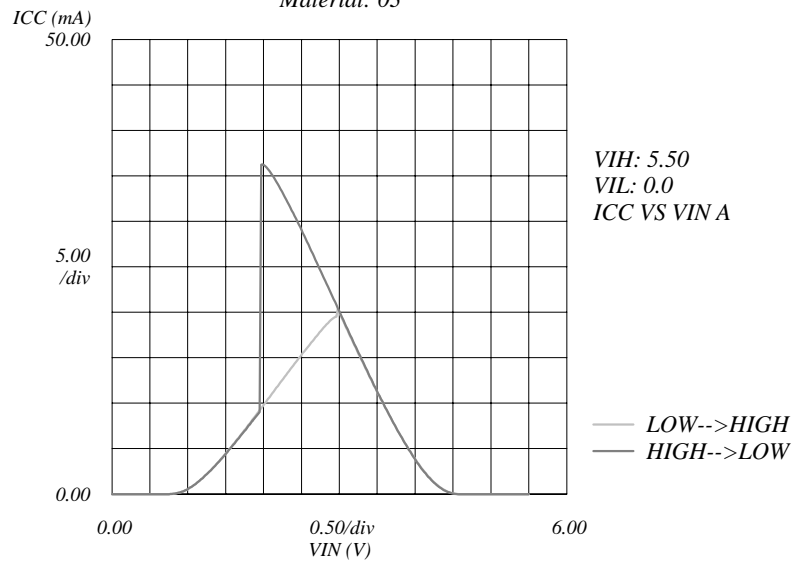

LVC1G14 D-DIE ICCI (5.50,25 C)

Pin: 2 Comment: ICC VS VIN A


Material: 01

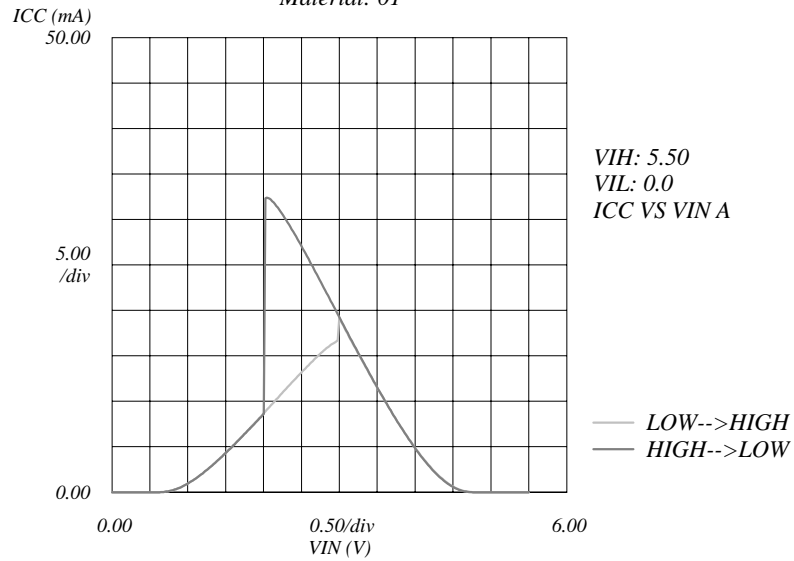

LVC1G14 D-DIE ICCI (5.50,25 C)

Pin: 2 Comment: ICC VS VIN A


Material: 02

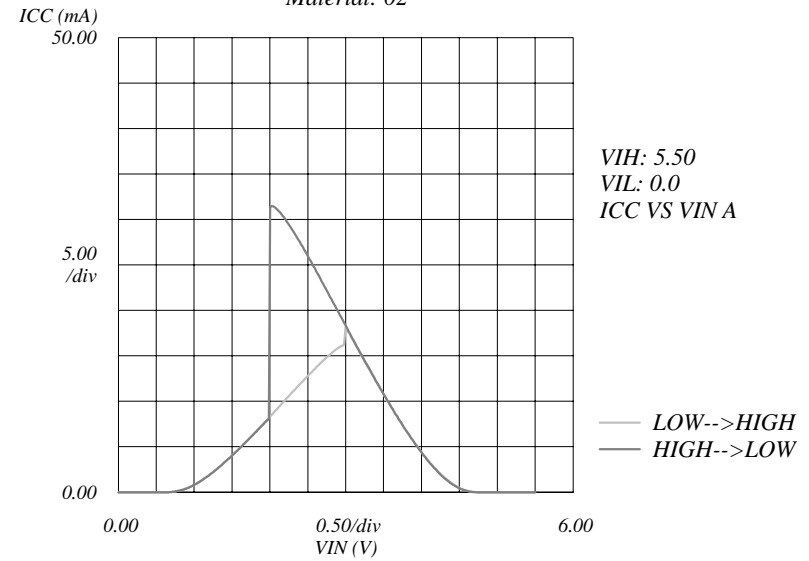

LVC1G14 D-DIE ICCI (5.50,25 C)

Pin: 2 Comment: ICC VS VIN A


Material: 03

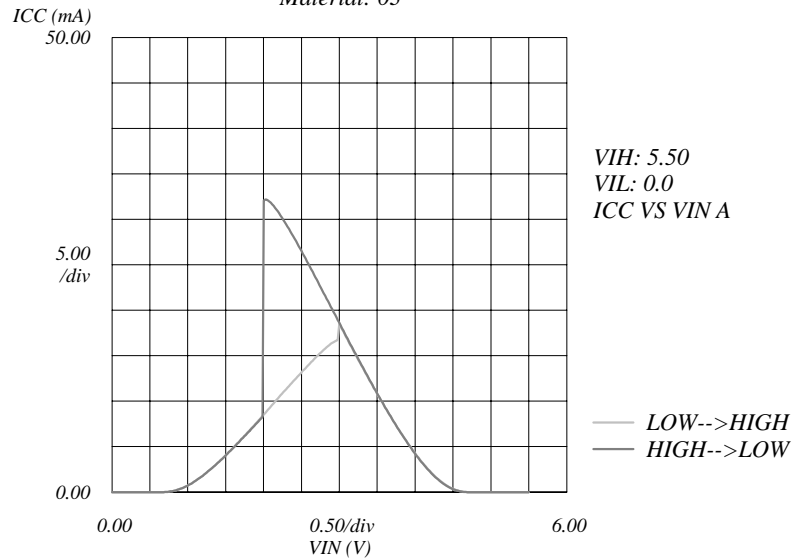

LVC1G14 D-DIE ICCI (5.50,85 C)

Pin: 2 Comment: ICC VS VIN A


Material: 01

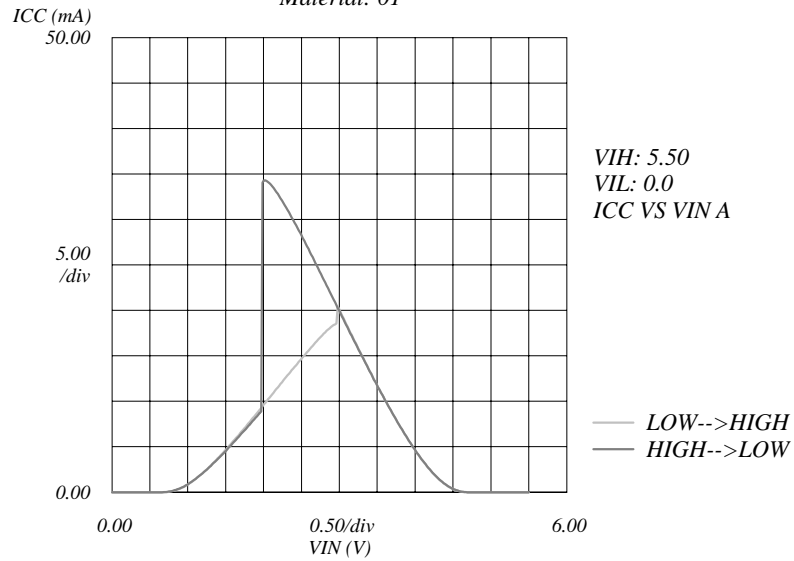

LVC1G14 D-DIE ICCI (5.50,85 C)

Pin: 2 Comment: ICC VS VIN A

Material: 02

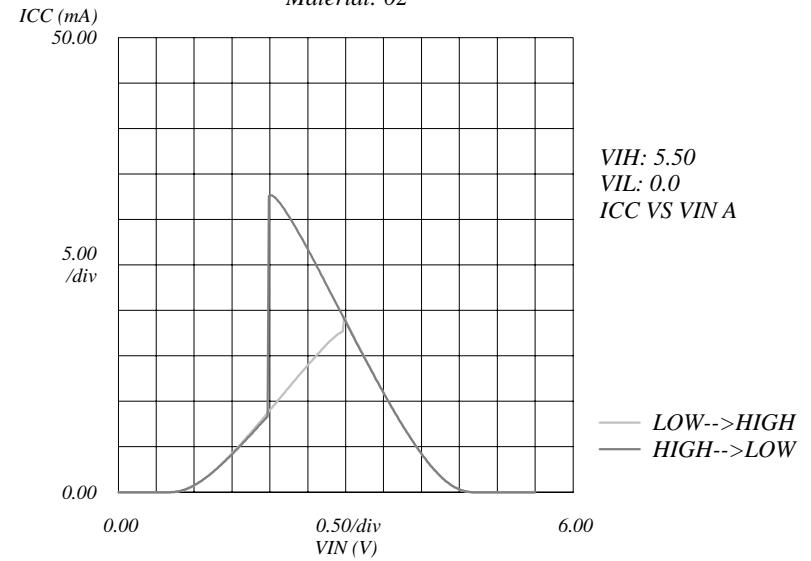

LVC1G14 D-DIE ICCI (5.50,85 C)

Pin: 2 Comment: ICC VS VIN A

Material: 03

