

IQ Demod Time Plot




Div 10.000

Ref -30.000

Triggered

30.000000 ms per div

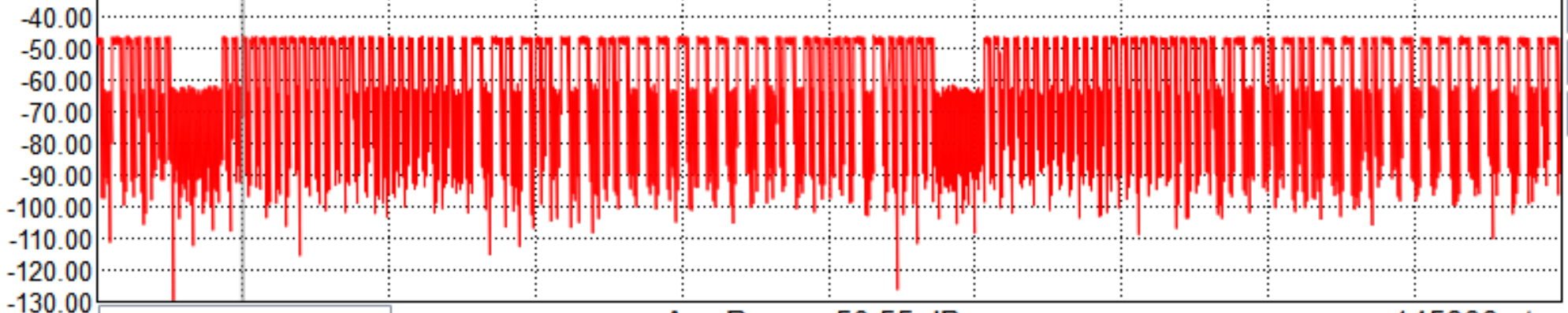

Pk  
Δ  
Off

AM Demod

Avg Power -50.55 dBm


145833 pts

IQ Spectrum Plot



Ref 0.000

FFT Size 183

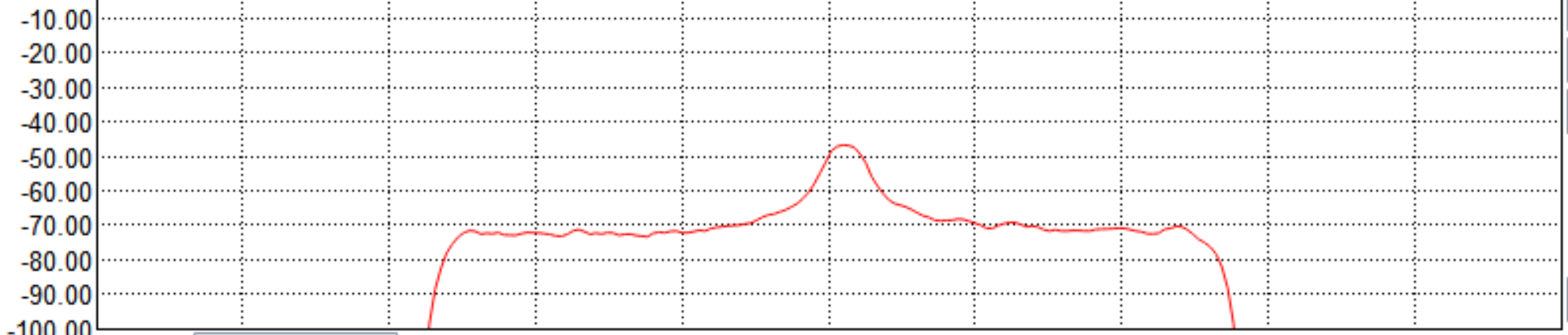

Pk  
Δ  
Off

Max

RBW 10.000000 kHz

Span 486.111 kHz