


Ref -20.000 dBm
Div 10.0

RBW 100.000000 Hz
Atten Auto

VBW 100.000000 Hz
100% POI 37.917 ms

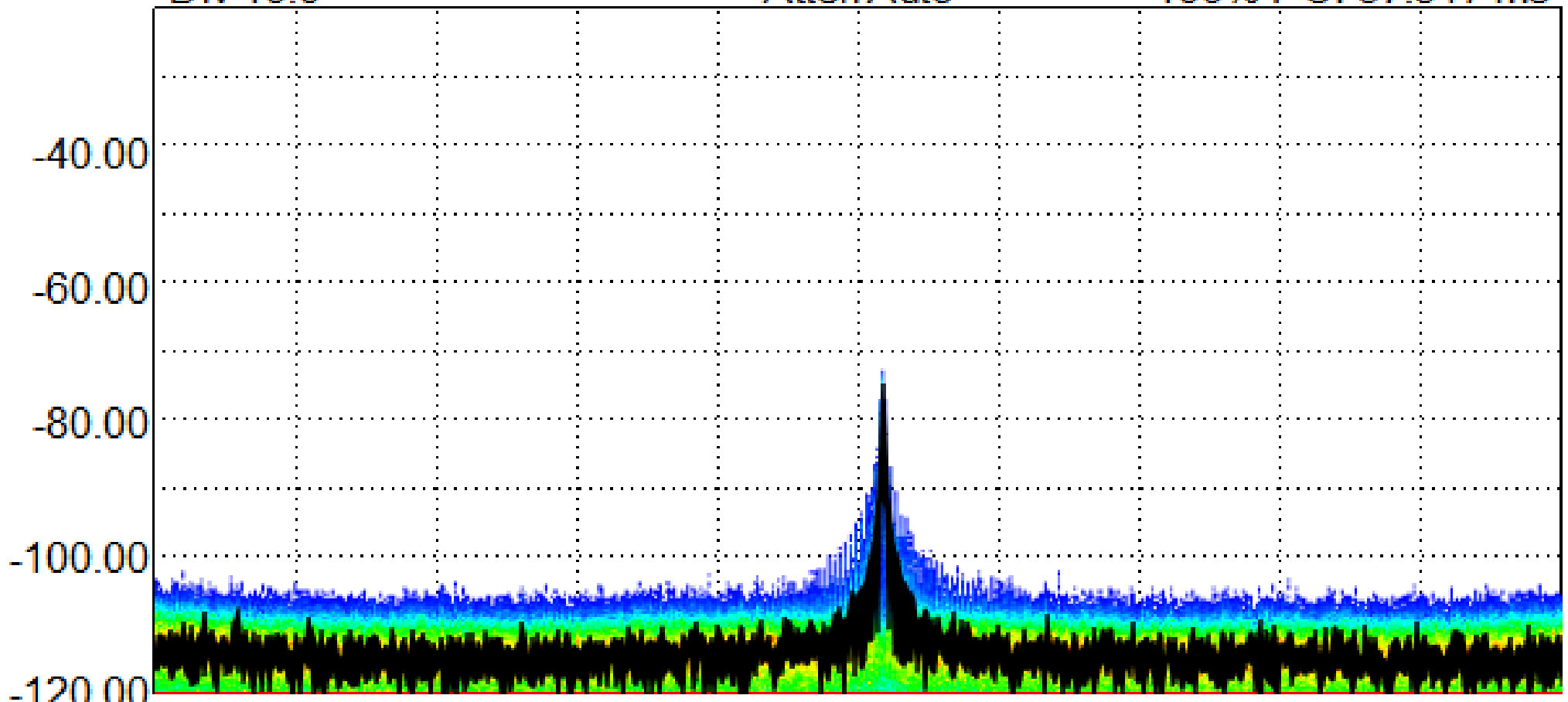

Start 417.875000 MHz

Center 418.000000 MHz
Span 250.000000 kHz

Stop 418.125000 MHz
8432 pts in 40651 ms