


Receiver spurious emissions
Operating mode: 2475 Rx mode

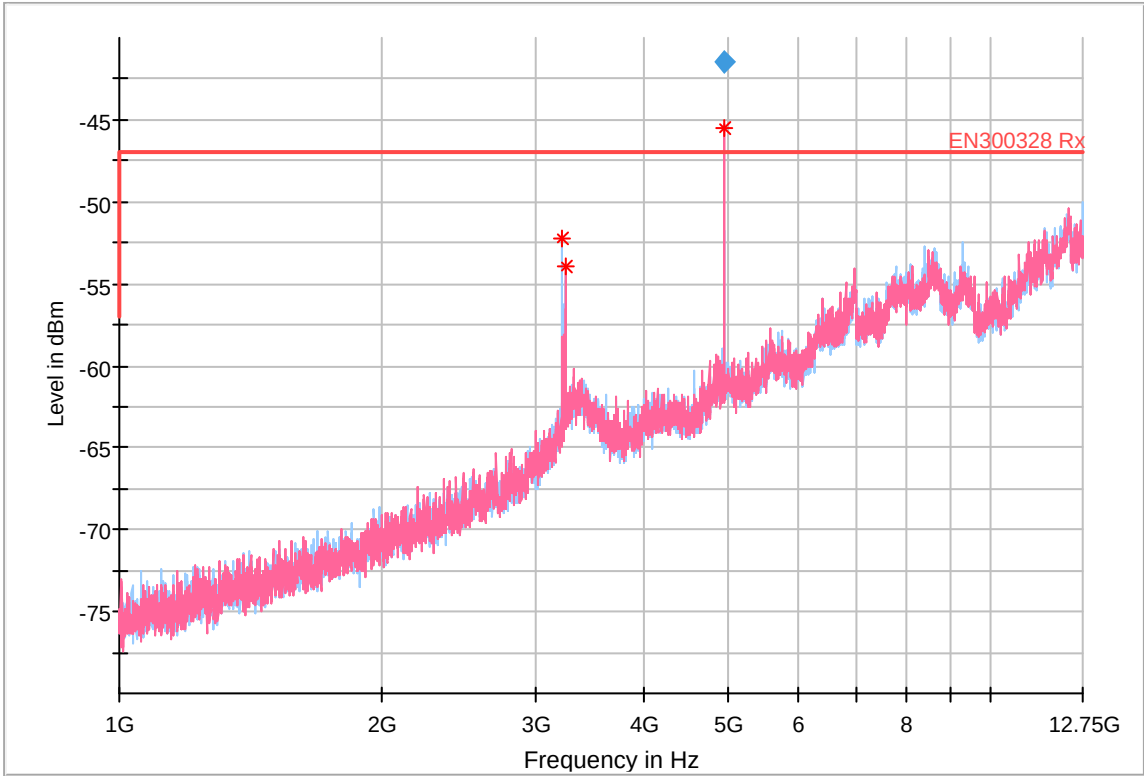

Final_Result

Frequency (MHz)	RMS (dBm)	Limit (dBm)	Margin (dB)	Height (cm)	Pol	Azimuth (deg)	Corr. (dB)
4949.909375	-41.50	-47.00	5.50	200.0	V	92.0	-83.5

Critical_Freqs

Frequency (MHz)	MaxPeak (dBm)	Limit (dBm)	Margin (dB)	Height (cm)	Pol	Azimuth (deg)	Corr. (dB)
3222.659375	-52.27	-47.00	-5.27	100.0	H	41.0	-88.6
3256.000000	-53.94	-47.00	-6.94	100.0	V	88.0	-88.0
4949.909375	-45.56	-47.00	1.44	200.0	V	92.0	-83.5