
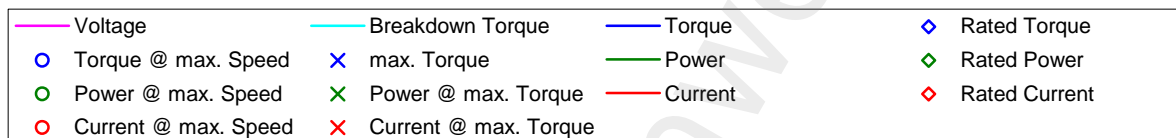


### 3-phase motor @ variable frequency

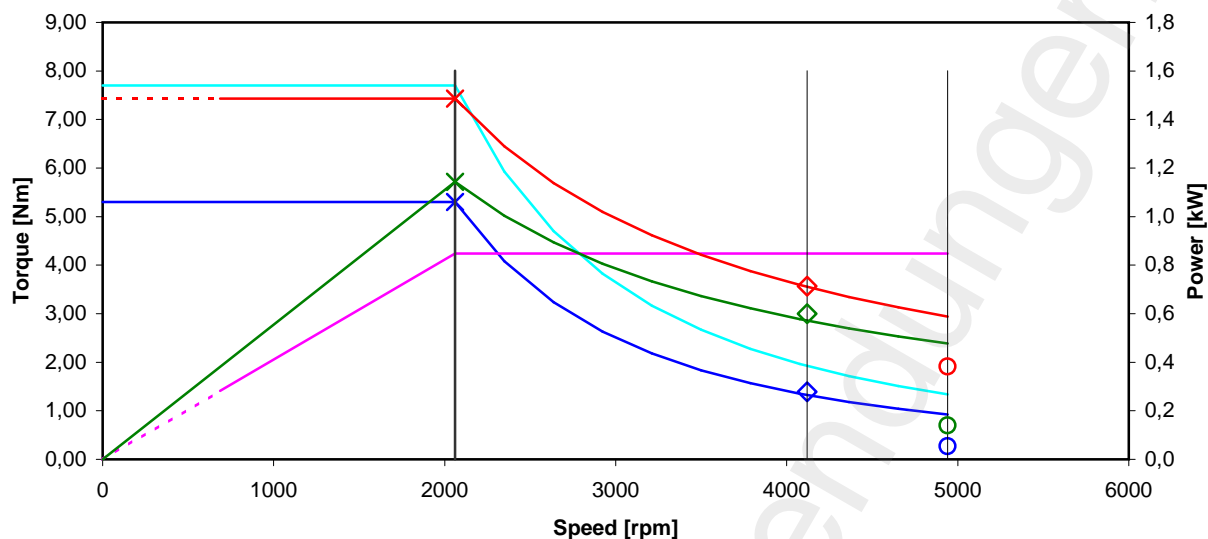

Type: DG63d-4  
 E No.: E18124  
 Winding No.: 590127484

Number of Poles: 4  
 Voltage [V]: 15  
 Base Freq. [Hz]: 76

Notes:

#### Max. Torque

Speed [rpm]:	2060	Power factor:	0,81	Frequency [Hz]:	76
Torque [Nm]:	5,30	Efficiency [%]:	75,0	Slip [Hz]:	7,3
Power [kW]:	1,14	Duty Cycle:	S2-5 min		
Current [A]:	72,5	Voltage [V]:	15		

#### Rated Power

Speed [rpm]:	4120	Power factor:	0,81	Frequency [Hz]:	144
Torque [Nm]:	1,39	Efficiency [%]:	82,0	Slip [Hz]:	6,7
Power [kW]:	0,60	Duty Cycle:	S2-60 min		
Current [A]:	34,8	Voltage [V]:	15		

#### Max. Speed

Speed [rpm]:	4940	Power factor:	0,49	Frequency [Hz]:	166
Torque [Nm]:	0,27	Efficiency [%]:	59,0	Slip [Hz]:	1,3
Power [kW]:	0,14	Duty Cycle:	S2--30 min		
Current [A]:	18,7	Voltage [V]:	15		

Note: Current, slip, power factor and efficiency are estimated values