


Mag [B/A] (dB)

Phase [B-A] (deg)

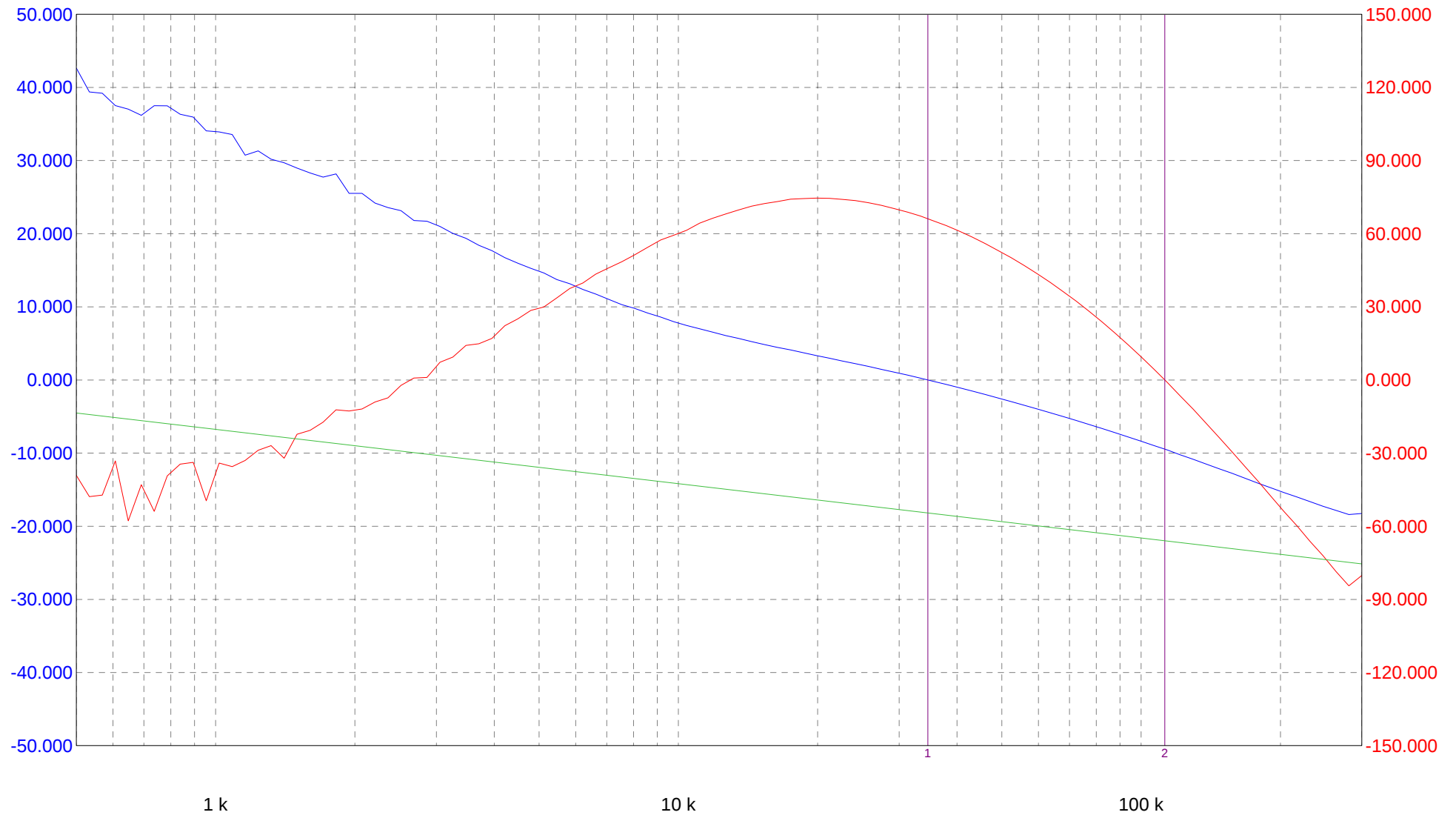

Frequency	M1	M2	M2 - M1
	34.60 kHz	112.52 kHz	77.92 kHz
Magnitude	-0.003 dB	-9.461 dB	-9.457 dB
Phase	66.116 deg	-0.025 deg	-66.141 deg
Var. Source	9.04 mV	6.40 mV	-2.64 mV