


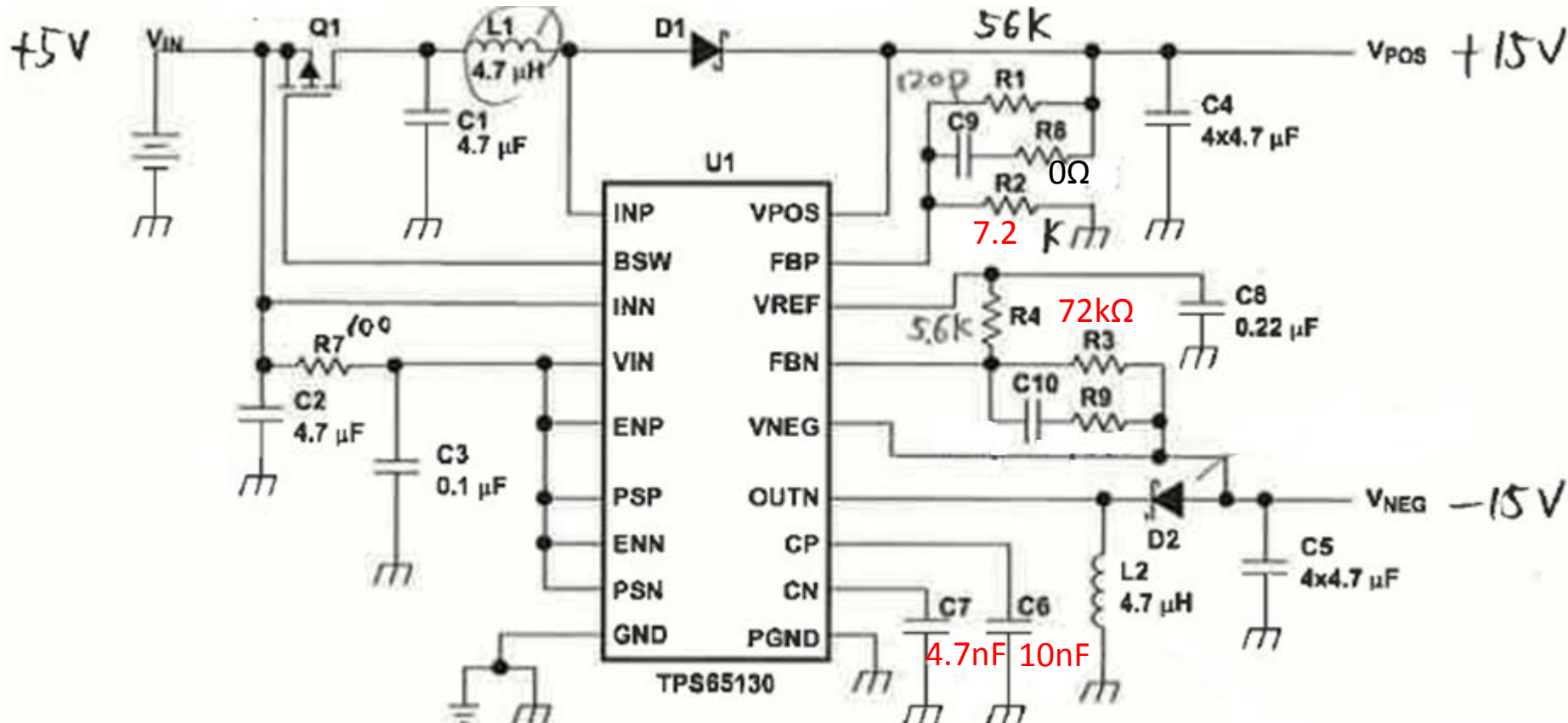

No Load SW

Δ : 16.5 V
@: 16.6 V

Ch2 5.00 V M 10.0 μ s A Ch2 3.10 V

30.20 %

swaying between 16V and 15V.

Δ : 14.0ms
@: 16.6ms
 Δ : 100mV
@: 15.0 V

Ch2 5.00 V M 4.00ms A Ch2 3.10 V

30.20 %

Normal operation

It is different SW period

Ch2 5.00 V M 10.0 μ s A Ch2 3.10 V

29.60 %