


1 2 3 50 1.00V/ 20.00ms/ 110mV
0 0.0V H 4.240s T 1 Auto?

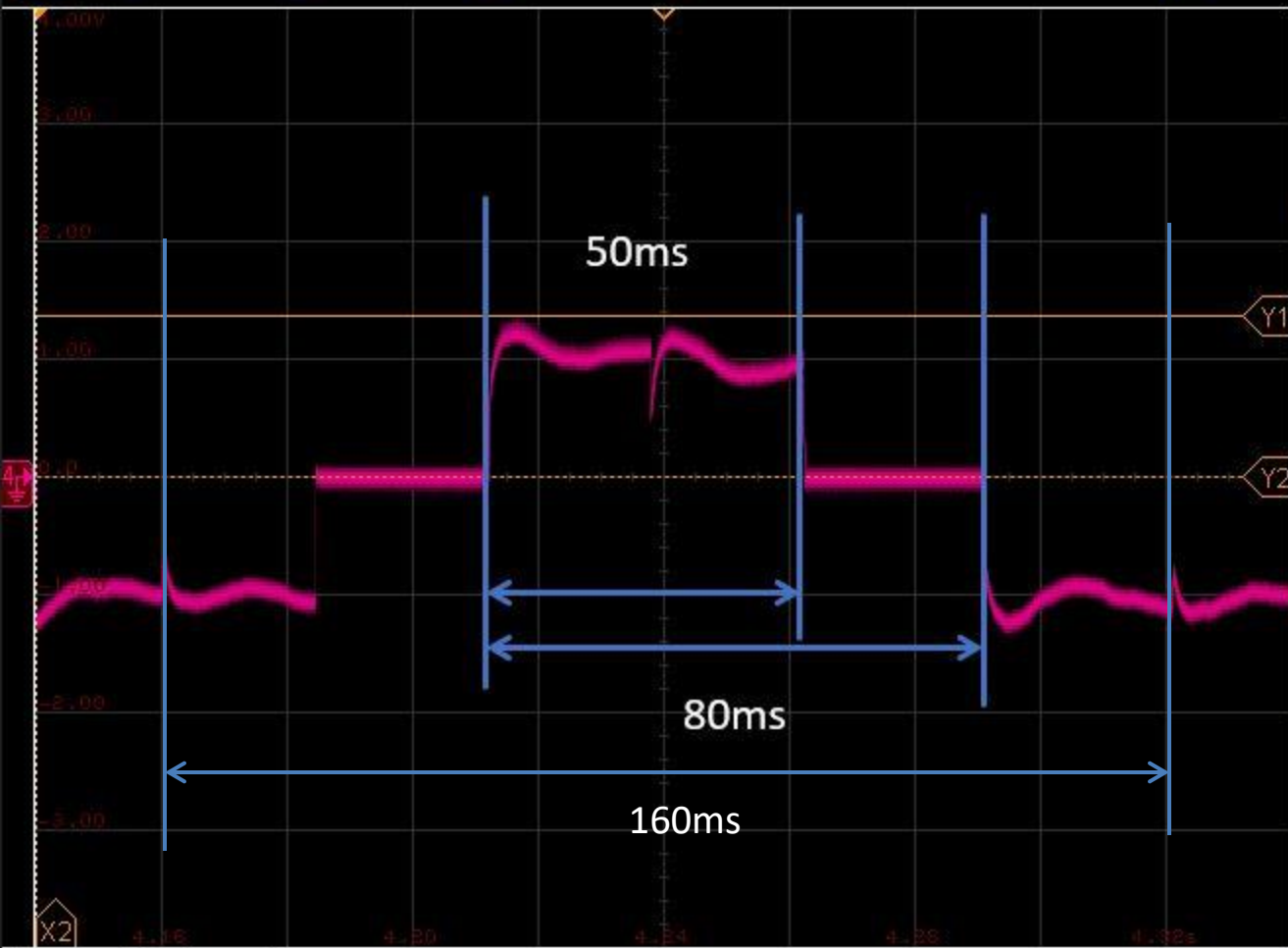

Cursor Manual

X1(4): -2.000000000ms
X2(4): 57.000000000ms
ΔX: 59.000000000ms
1/ΔX: 16.949Hz

Y1(4): 1.37500V
Y2(4): 0.0V
ΔY: -1.37500V
ΔY/ΔX: -23.3051V/s

Waveform Persistence Menu

Persistence Off Capture Waveforms Clear Persistence Clear Display