


PC44磁芯PQ3220 6+6骨架

4、6脚：电感 $L_p = 420\mu\text{H} \pm 10\%$  @65kHz  
 4、6脚：漏感 $L_k < 20\mu\text{H}$ ，短接其他脚

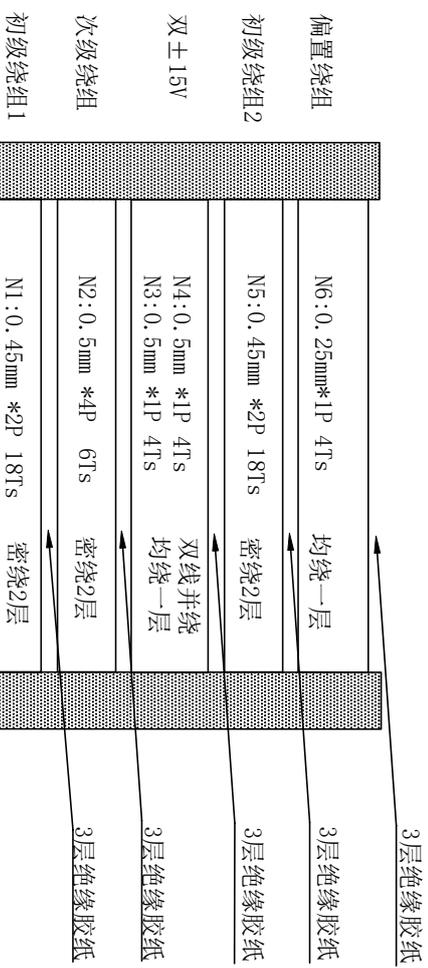

PQ3220 6+6骨架

4、6脚初级电感 $L_p = 420\mu\text{H} \pm 10\%$   $L_k < 20\mu\text{H}$