


The Lumitape® Static white high efficacy LED strip features even lighting, longer lifespan, High efficacy and high CRI, it is designed to provide consistent linear lighting for limited spaces in wide variety of applications for cove lighting and indirect lighting in hotels, restaurants, shops, offices and homes.


- High efficacy up to 130Lm/w
- 2835, 210LED/m, 24V
- 3-5 years warranty
- 0-10V, DALI, PWM Dimmable

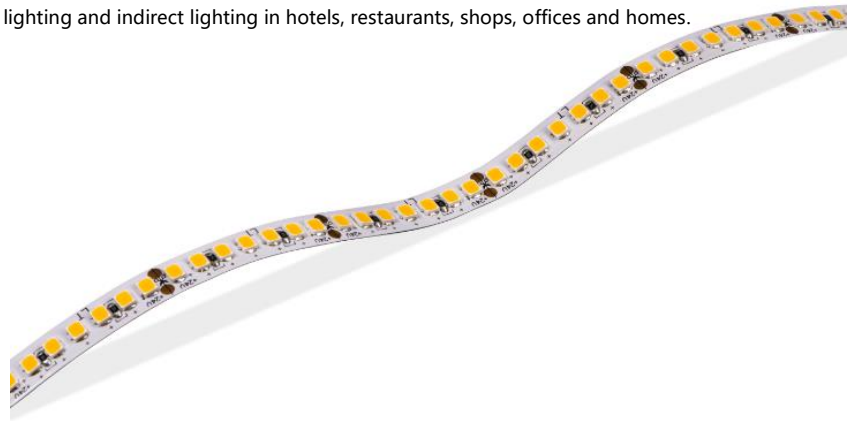

Cut points



Temperature Data¹ (15W/m)

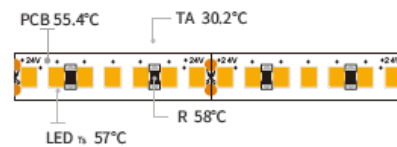

Electrical technical data

Nominal input voltage	24V DC	Voltage range	23-25V DC
LED types	2835 SMD	Product dimension	L5000*W8*H1.4mm
LED QTY/m	210pcs	PCB dimension	8mm x 3oz (1/2oz)
IP rating (optional)	IP20 (IP65,IP67,IP68)	Cut points	33.33mm
Beam angle	120°	Material of coating	N/A
Bend radius	R<50mm	Customized length/reel	0.1 to 30meters
Dimming function	PWM/ 0-10V/ DALI	Standard length/reel	5meters
Connection	2 x 0.5MM ² / 20AWG wire / DC connector	Installation.	3M 300LSE adhesive tape

Light technical data


Part number	LT-SW28N210-XX80-24-YYY		
	XX: 24=2400K/ 27=2700K/ 30=3000K/ 40=4000K/ 50=5000K/ 57=5700K/ 65=6500K YYY: 240=24W/200=20W/150=15W		
Power consumption/m	24W	20W	15W
CCT	2400~6500K		
Lumen output/m	2256~2688Lm	1980~2600Lm	1560~1860Lm
Efficacy	94~112Lm/w	99~130Lm/w	104~130Lm/w
MAXRUN® in series	3m (3A)	5m (4.2A)	8m (5A)
Binning tolerance & code	SDCM<3	SDCM<3	SDCM<3
CRI (White)	Ra+80;R9+3		
TM30	Rf=80 Rg=85		
TLCI(Qa)	80		
Warranty	3 years		

Temperature data²

Operating temp. (Tc)	-25 - 70°C	Storage temp. (Ts)	-30 - 80°C
Ambient temp. (Ta)	-25 - 45°C	Lifespan	30,000Hrs

Packaging information

QTY per Carton	60pcs	Carton size	40*40*23cm
G.W. per reel (5m)	0.15Kg	G.W per Carton	9.50Kg

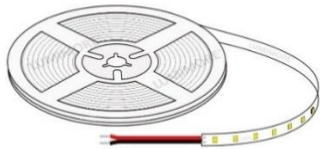

Warranty

Should this product fail during the 5 years warranty period it will be replaced free of charge, subject to the correct installation of the original product in accordance with applicable and appropriate electrical codes and instructions provided by LUMIMORE, as well as subsequent return of the faulty unit. LUMIMORE does not accept responsibility for any installation costs associated with the replacement of this product and LUMIMORE reserves the right to alter specifications without prior notice. LUMIMORE can offer 7 years warranty upon request.