




Waveform of SW1, SW2, Vout, Inductor Current

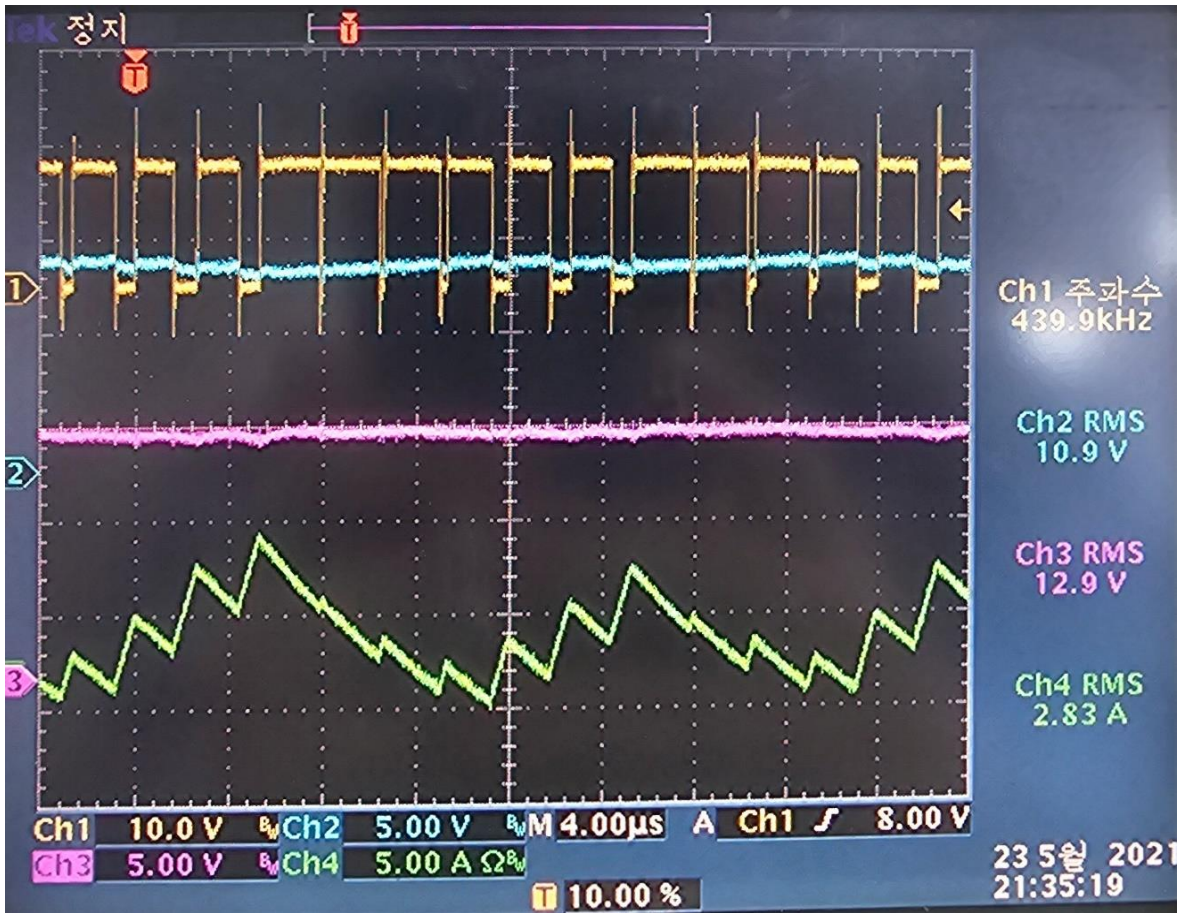

- CH1 SW1
- CH2 SW2
- CH3 Vout
- CH4 Inductor Current

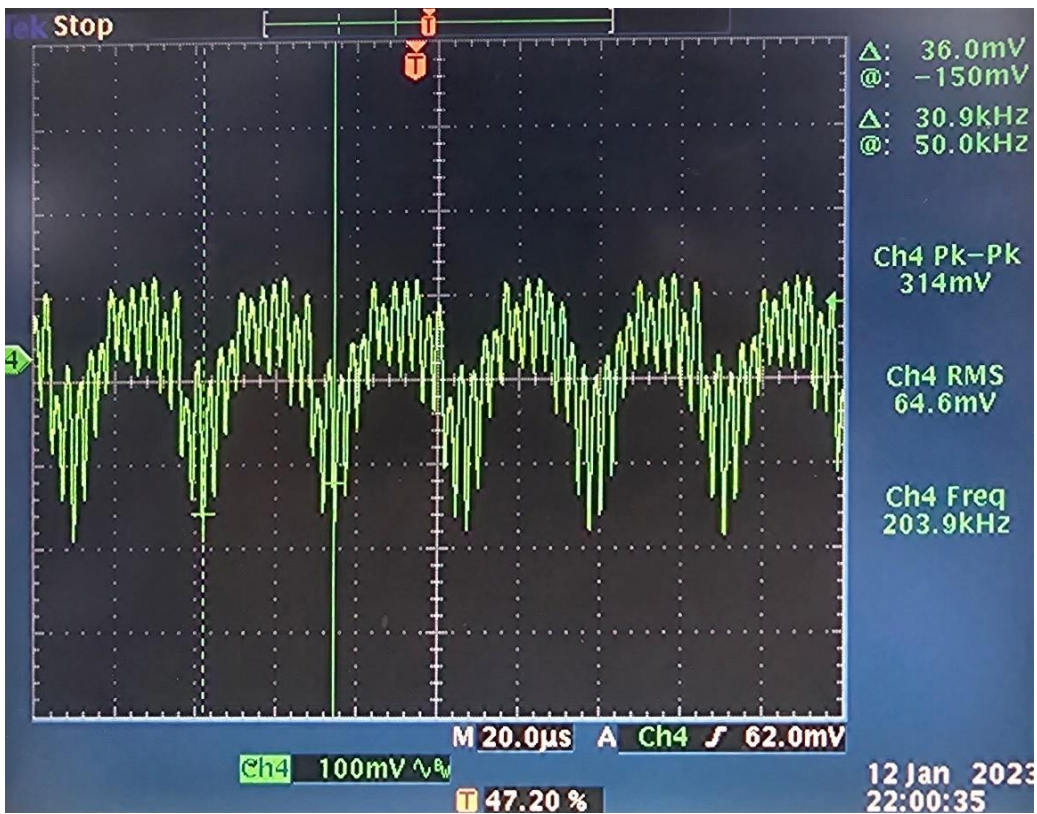

R17=4.99kohm, C25=10nF, L=2.2uH, Fsw=400kHz

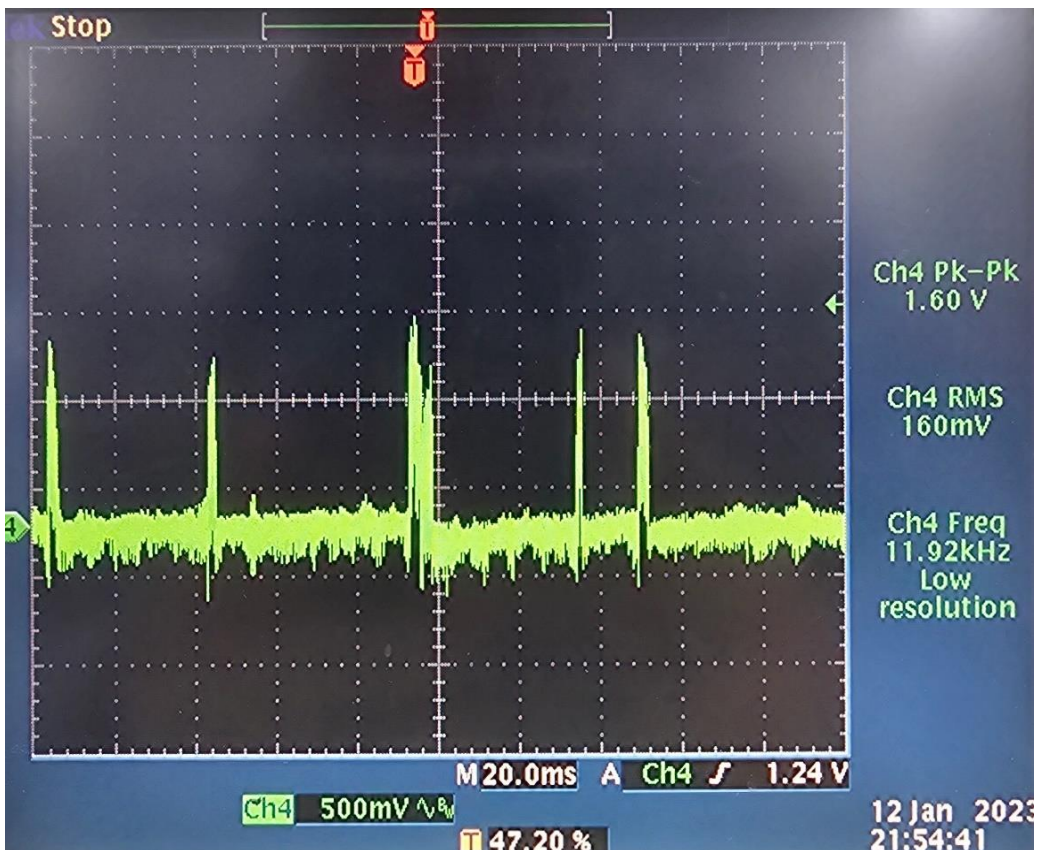

R17=4.99kohm, C25=10nF, L=4.7uH, Fsw=400kHz