


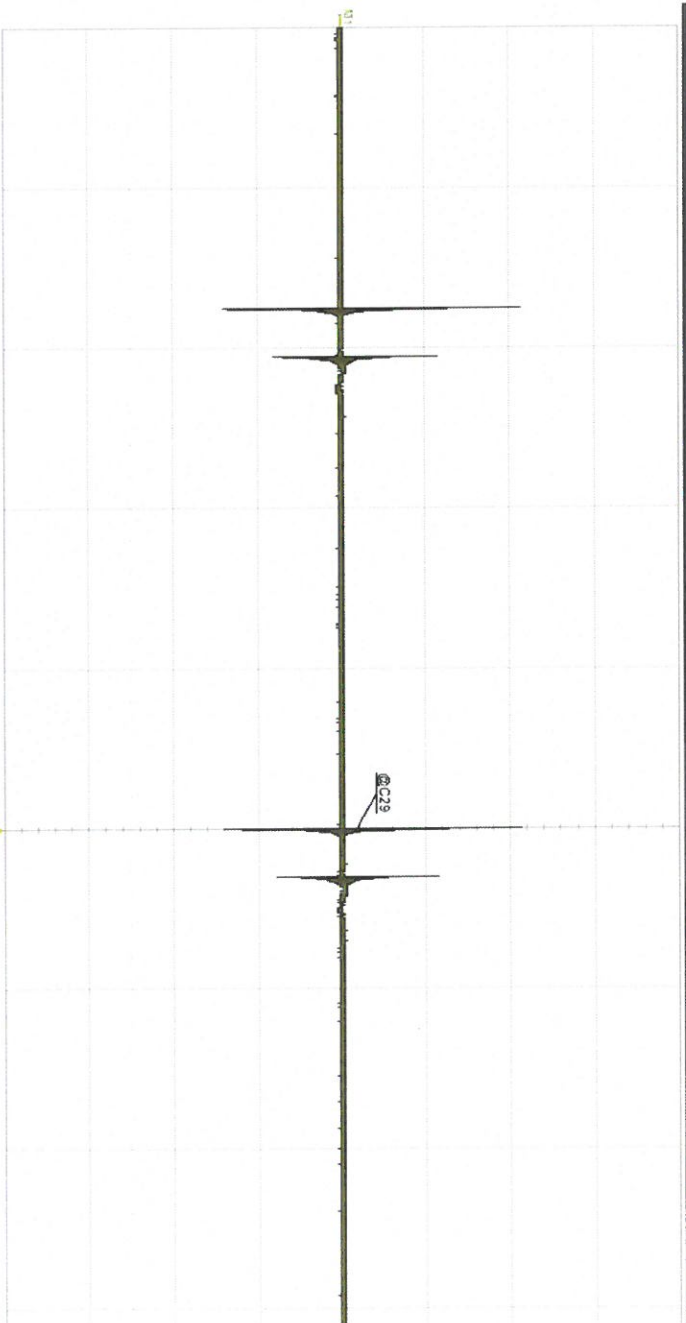

Sidehor	P1rise(C1)	P2fall(C1)	P3period(C1)	P4freq(C1)	P5width(C1)	P6duty(C1)	P7delay(C1)	P8npoints(C1)	P9---	P10---	P11
value	3.216716us	1.305ns	3.772ns	265.1021MHz	1.219ns	44.03%	-3.246868us	400.0000e+3			
mean	2.1320864us	47.20304ns	617.30005ns	122.6843MHz	7.96302ns	23.4860%	-3.2199586us	400.0000e+3			
min	250ps	271ps	3.667ns	303.1997MHz	1.145ns	38m%	-3.619539us	400.000e+3			
max	6.763234us	3.298728us	3.298156us	272.6976MHz	3.297178us	99.97%	3.797885us	400.000e+3			
sdev	1.5524291us	370.40827ns	1.0986965us	114.1660MHz	135.67743ns	21.2642%	438.87233ns	0.00			
num	1.740e+3	1.741e+3	5.852e+3	5.852e+3	6.382e+3	5.852e+3	537	594			
status	OK	OK	OK	OK	OK	OK	OK	OK			

LeCroy