


Enlarged view

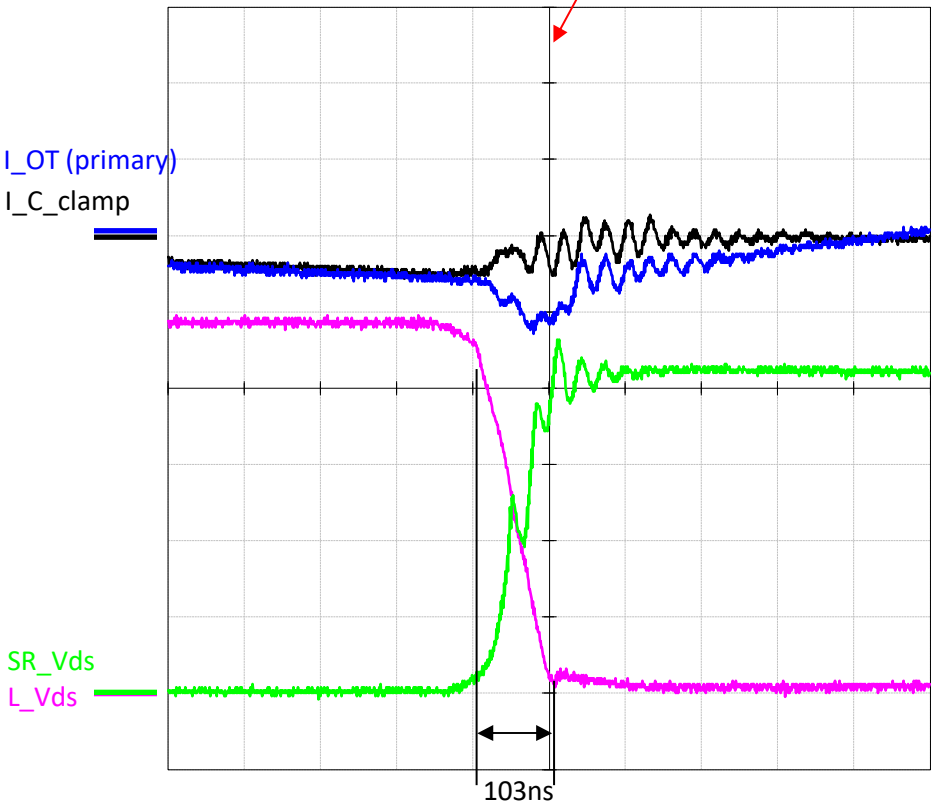

input : 264 VAC  
 output : 24 V  
 3.75 A

	Scale	Bw
CH1	2 A/div	500MHz
CH2	2 A/div	500MHz
CH3	100 V/div	500MHz
CH4	25 V/div	500MHz
REF1	-	-
REF2	-	-
REF3	-	-
REF4	-	-
MATH	-	-

TIME	1 us/div
MODE	Peakdetect

input : 264 V  
 output : 24 V  
 3.75 A

	Scale	Bw
CH1	2 A/div	500MHz
CH2	2 A/div	500MHz
CH3	100 V/div	500MHz
CH4	25 V/div	500MHz
REF1	-	-
REF2	-	-
REF3	-	-
REF4	-	-
MATH	-	-

TIME	100 ns/div
MODE	Peakdetect