



5~12V输入

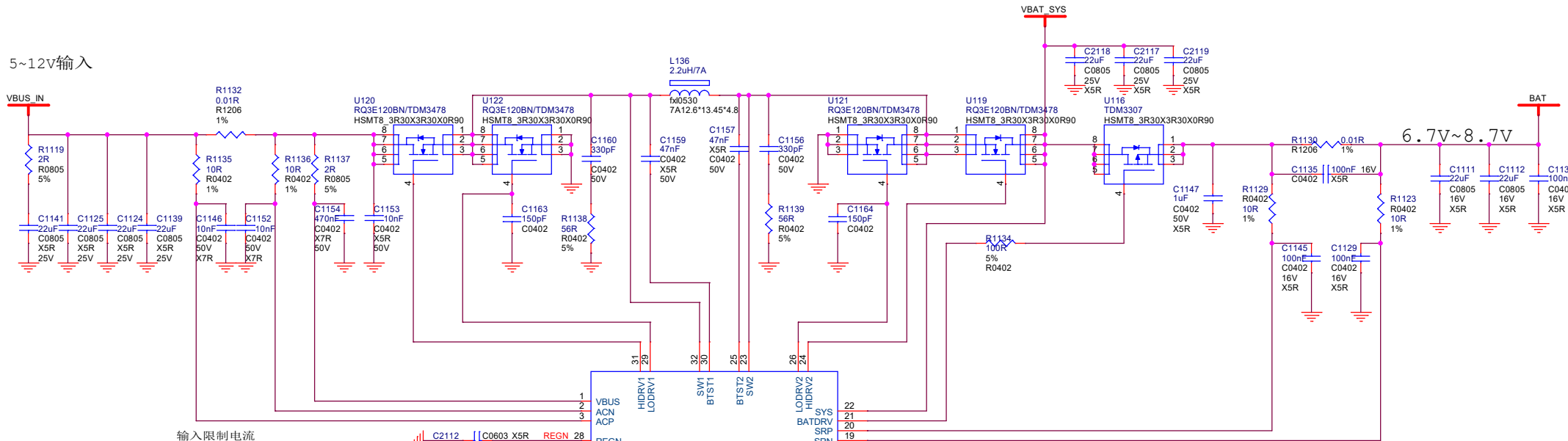

输入限制电流


VILIM_HIZ	IDPM
2.6 V	4000mA
2.2 V	3000mA
1.6 V	1500mA
1.2 V	500mA

$VILIM_HIZ = VDDA * R1125 / (R1125 + R1124)$

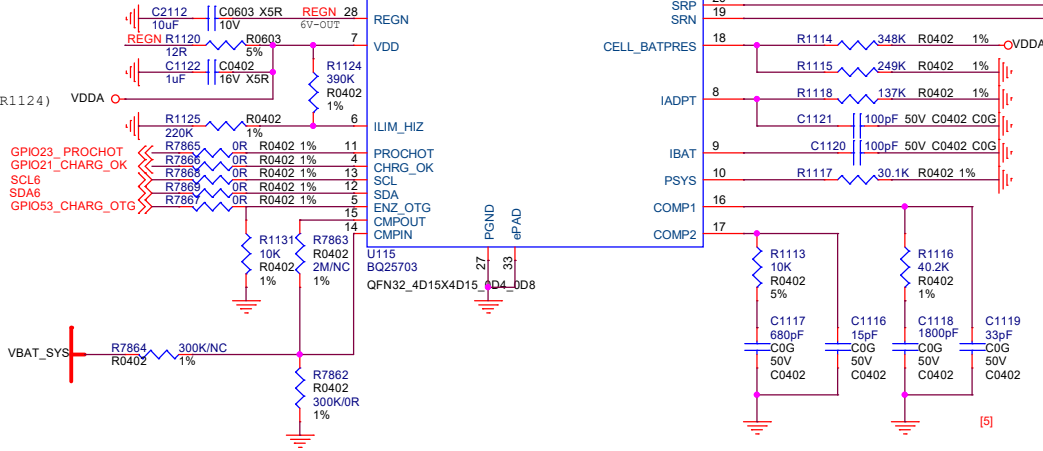

CELL_BATPRES
1S CELL 25%
2S CELL 40%
3S CELL 55%
4S CELL 75%
 $CELL_BATPRES = R1115 / (R1114 + R1115)$

电池接口

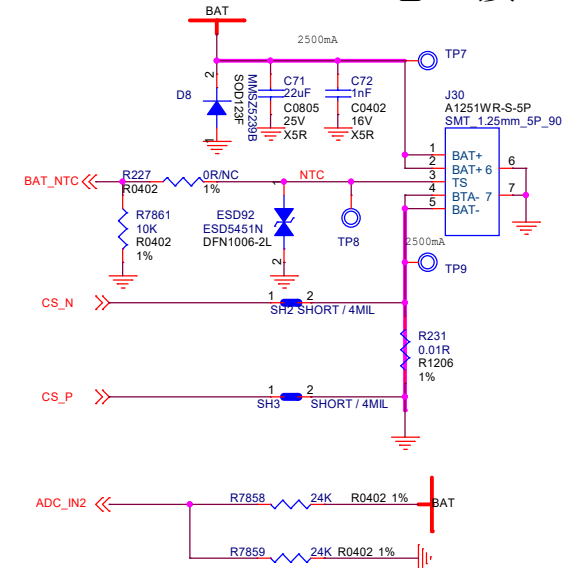

BAT, GND
一定要从电池连接器端引线,
才能保证测试精度。

