


Charging: 3A  
Discharging: 8A  
EG could setting.

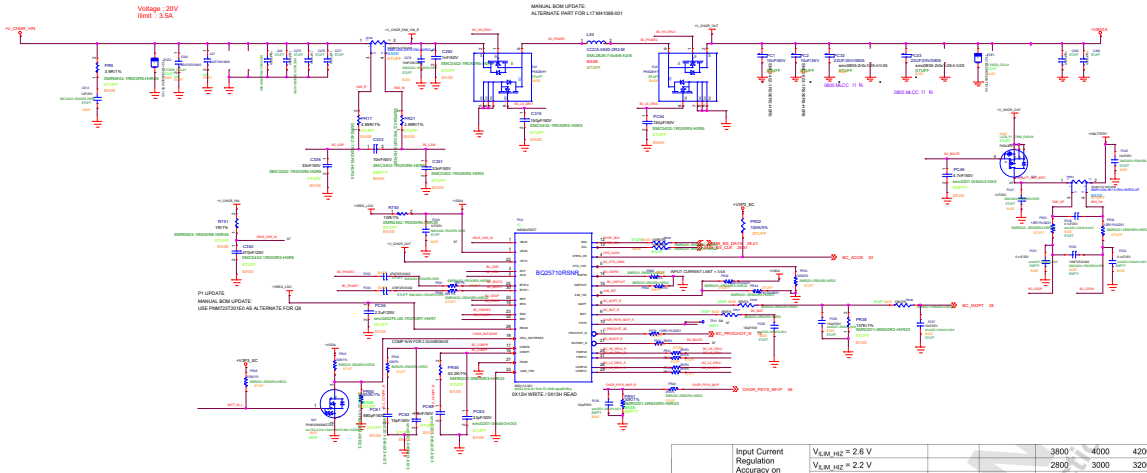

Input Current Regulation Accuracy on 0.1m, 1Hz pin C <sub>LM</sub>	V <sub>IN</sub> = 2.6 V	3800	4000	4200
	V <sub>IN</sub> = 2.2 V	2800	3000	3200
	V <sub>IN</sub> = 1.6 V	1300	1500	1700
	V <sub>IN</sub> = 1.2 V	300	500	700

