
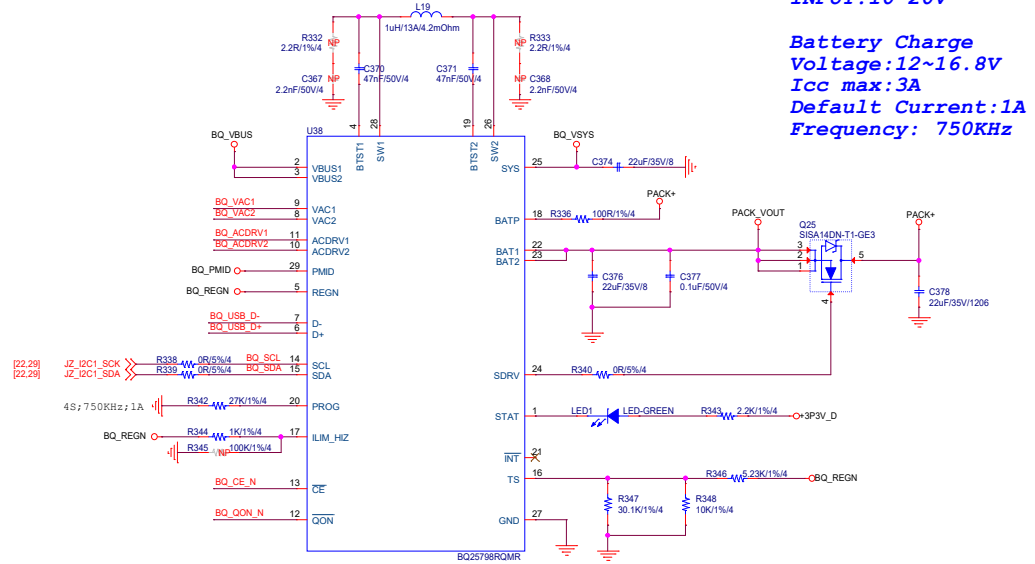
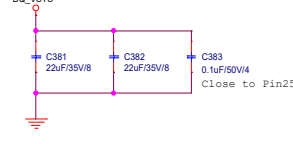
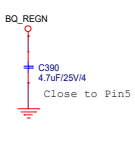
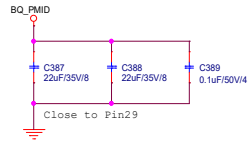
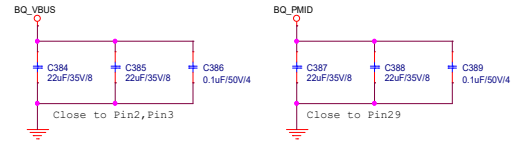
 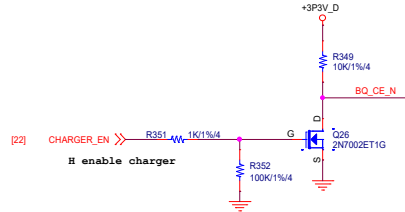

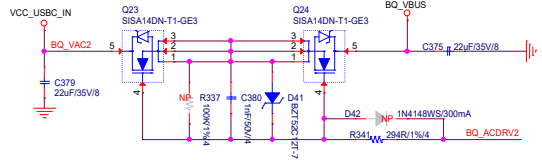


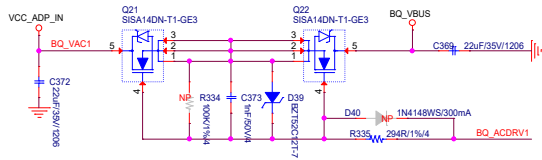

INPUT:10~20V
Battery Charge
Voltage:12~16.8V
Icc max:3A
Default Current:1A
Frequency: 750KHz

PIN	
PMID	Same as VIN
REGN	4.8V
SYS	12~16.8V
ILIM_HIZ	Ivin_lim=5A
TS	NA