
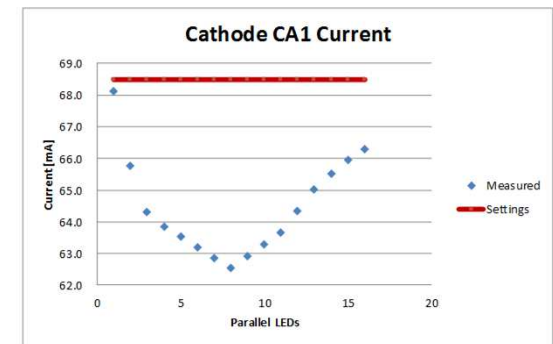
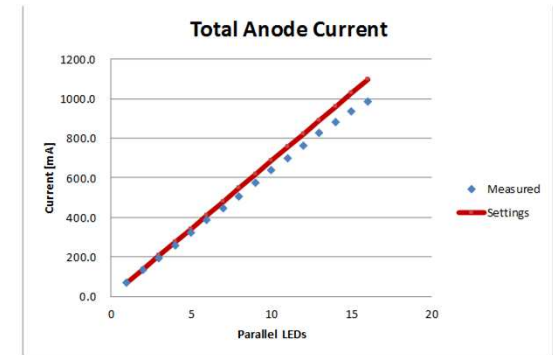


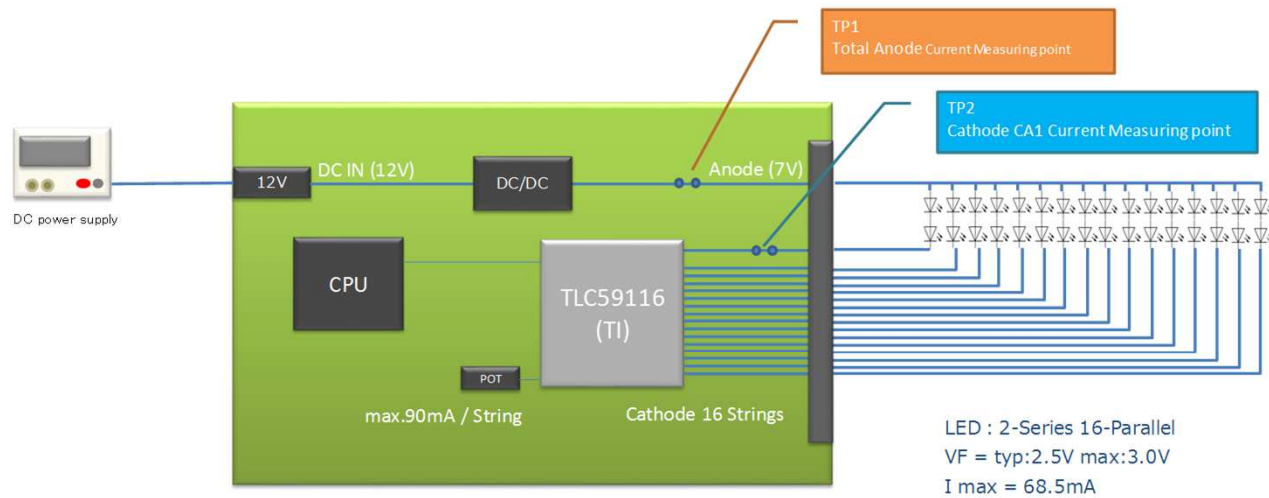

	Output Strings	Anode V[V]	OUT1 V[V]	OUT2 V[V]	OUT3 V[V]	OUT4 V[V]	OUT5 V[V]	OUT6 V[V]	OUT7 V[V]	OUT8 V[V]	OUT9 V[V]	OUT10 V[V]	OUT11 V[V]	OUT12 V[V]	OUT13 V[V]	OUT14 V[V]	OUT15 V[V]	OUT16 V[V]
1	1	7.07V	1.42V	3.045V	3.02V	3.211V	3.49V	3.56V	3.501V	3.53V	3.432V	3.598V	3.504V	3.289V	3.265V	3.404V	3.405V	3.376V
2	1-2	7.06V	1.429V	1.421V	3.007V	3.212V	3.492V	3.56V	3.495V	3.527V	3.427V	3.573V	3.503V	3.29V	3.271V	3.399V	3.441V	3.372V
3	1-3	7.06V	1.434V	1.427V	1.419V	3.21V	3.489V	3.557V	3.492V	3.527V	3.428V	3.568V	3.473V	3.283V	3.264V	3.395V	3.436V	3.37V
4	1-4	7.06V	1.432V	1.427V	1.421V	1.394V	3.484V	3.554V	3.49V	3.526V	3.422V	3.564V	3.473V	3.252V	3.254V	3.396V	3.422V	3.367V
5	1-5	7.06V	1.429V	1.426V	1.419V	1.397V	1.394V	3.549V	3.487V	3.522V	3.426V	3.566V	3.469V	3.248V	3.229V	3.392V	3.42V	3.364V
6	1-6	7.06V	1.428V	1.424V	1.417V	1.396V	1.395V	1.364V	3.483V	3.517V	3.422V	3.565V	3.466V	3.248V	3.223V	3.365V	3.414V	3.365V
7	1-7	7.06V	1.426V	1.423V	1.415V	1.395V	1.394V	1.369V	1.357V	3.524V	3.427V	3.57V	3.469V	3.245V	3.203V	3.366V	3.41V	3.362V
8	1-8	7.06V	1.423V	1.421V	1.413V	1.394V	1.394V	1.373V	1.367V	1.341V	3.434V	3.571V	3.473V	3.248V	3.2V	3.368V	3.403V	3.345V
9	1-9	7.06V	1.416V	1.413V	1.405V	1.386V	1.386V	1.364V	1.36V	1.335V	1.356V	3.593V	3.491V	3.253V	3.198V	3.37V	3.414V	3.356V
10	1-10	7.06V	1.411V	1.406V	1.398V	1.38V	1.379V	1.358V	1.352V	1.328V	1.358V	1.342V	3.514V	3.265V	3.201V	3.39V	3.427V	3.375V
11	1-11	7.06V	1.406V	1.401V	1.391V	1.372V	1.371V	1.349V	1.344V	1.32V	1.353V	1.339V	1.321V	3.283V	3.212V	3.421V	3.456V	3.409V
12	1-12	7.06V	1.399V	1.393V	1.381V	1.362V	1.361V	1.338V	1.332V	1.308V	1.342V	1.329V	1.313V	1.32V	3.205V	3.43V	3.43V	3.416V
13	1-13	7.06V	1.392V	1.385V	1.371V	1.352V	1.35V	1.327V	1.322V	1.298V	1.331V	1.318V	1.304V	1.315V	1.509V	3.434V	3.465V	3.438V
14	1-14	7.06V	1.385V	1.379V	1.363V	1.344V	1.341V	1.317V	1.313V	1.287V	1.322V	1.311V	1.297V	1.311V	1.503V	1.272V	3.437V	3.525V
15	1-15	7.07V	1.379V	1.372V	1.356V	1.336V	1.333V	1.309V	1.304V	1.277V	1.315V	1.305V	1.291V	1.307V	1.272V	1.277V	1.466V	3.623V
16	1-16	7.08V	1.373V	1.367V	1.349V	1.33V	1.326V	1.301V	1.296V	1.269V	1.31V	1.301V	1.287V	1.305V	1.277V	1.283V	1.485V	1.261V