

RIGOL

STOP



f

1

15.0V

① Vin

1



5.00V

Time 200.0ns

→ 768.0ns

RIGOL

T'D



f

1

15.0V

② V_{out}



1



5.00V

Time 200.0ns

768.0ns

RIGOL

T'D



f

1

15.0V

③ SN

T

T

1



5.00V

Time 200.0ns

768.0ns



RIGOL

STOP




f

1

688mV

④ COMP

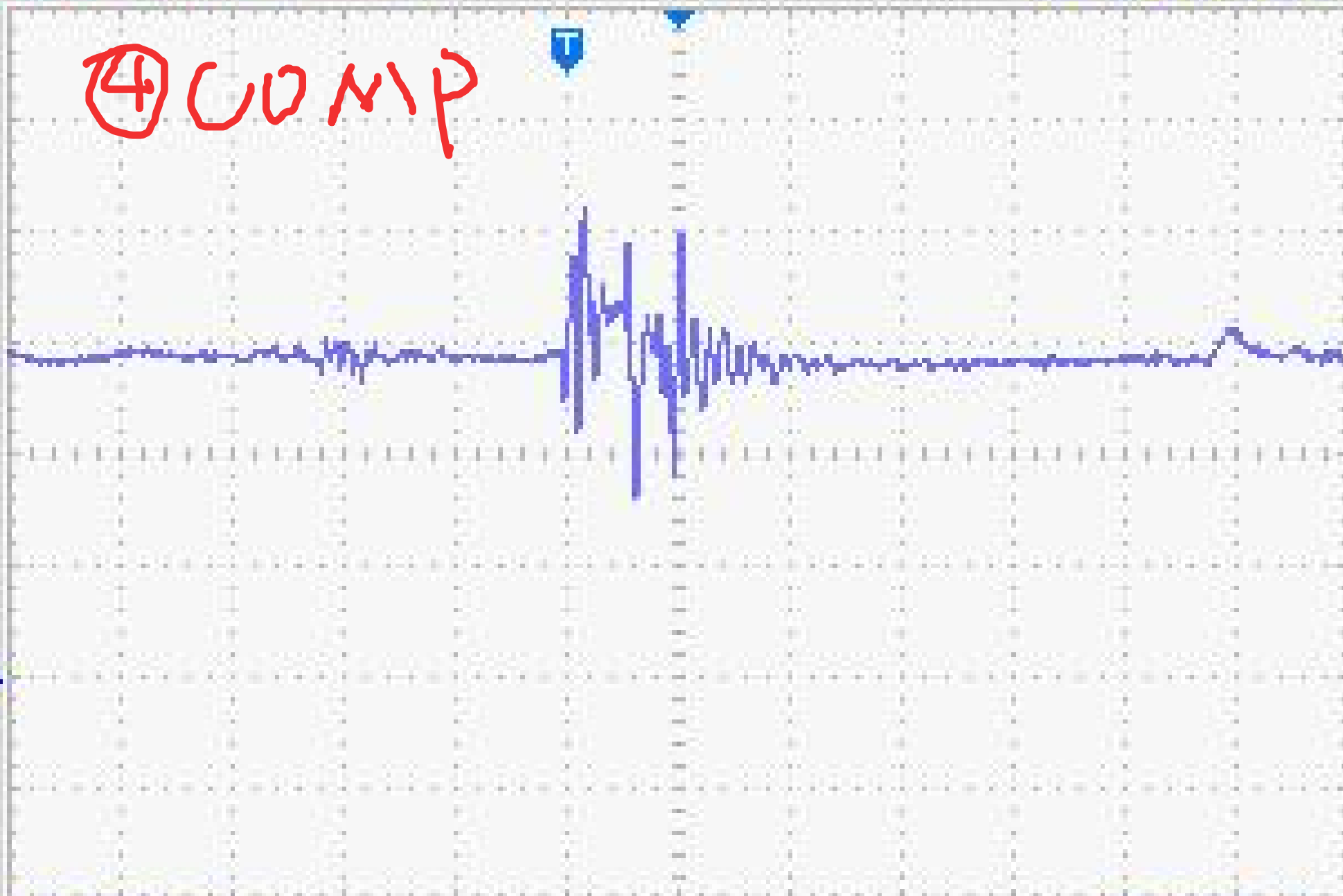

1



200mV

Time 200.0ns

→ 200.0ns