



Actual test circuit with C18, C9 in series with 51K resistor; C18 to 100pF.

Test 1:

+ Ripple of +15V:

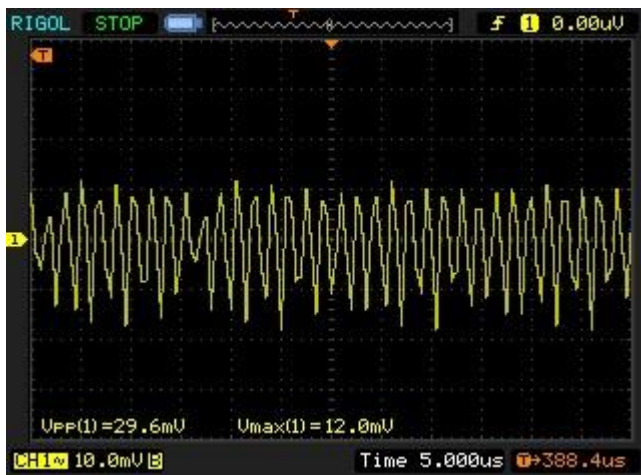


+15V dynamic response (25%~75% load (15V/200mA), 100Hz frequency):

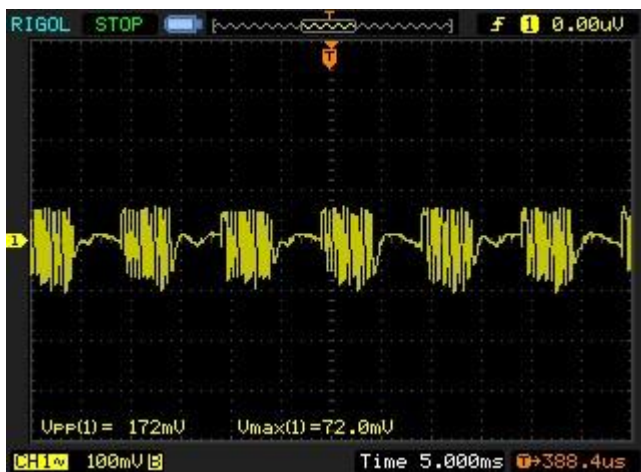

Test 2:

-15V ripple:

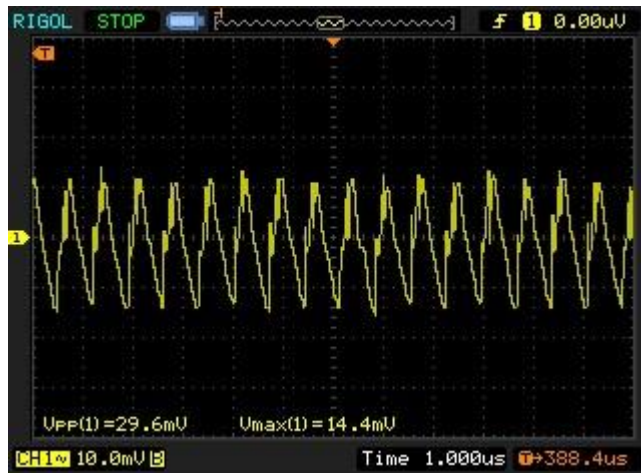

-15V dynamic response (rated input 220Vac, 25%~75% load (15V/200mA), 100Hz frequency):

