



Flat Pack Specification Sheet


PACKAGE TYPE:

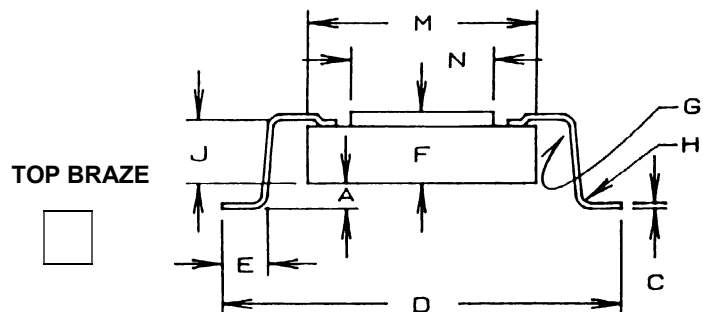

SIDE EXIT

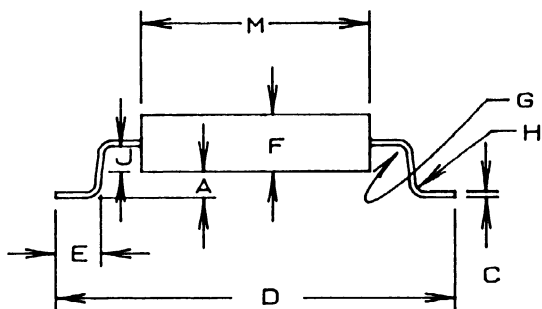


BOTTOM EXIT

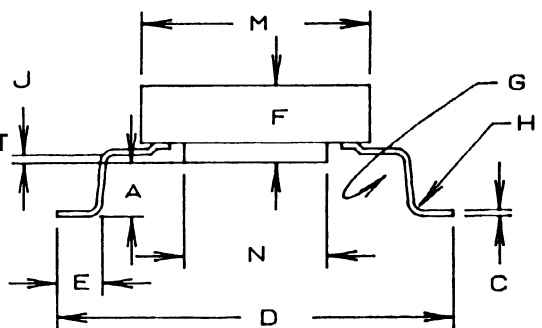


FOOT CONFIGURATION:

 OPTION 1



OPTION 2

(JEDEC)

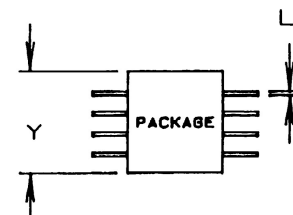

FA / FS NUMBER

PROPOSED

CUSTOMER

Texas Instruments

PART NUMBER

HKH-20 (No Gap)

DATE

7/6/2015

DRAWN BY

TOM LINNEBUR

		DIMENSIONS	TOLERANCE
A		0.000	± 0.002
C		0.006	± 0.003
D		0.510	± 0.010
E		0.050	± 0.005
X		---	---
F		0.100	MAX
G		0.012	± 0.003
H		0.012	± 0.003
J		0.035	± 0.010
M		0.298	MAX
N		0.188	MAX
PACKAGE LENGTH	Y	0.510	MAX
LEAD WIDTH	L	0.021	MAX
PITCH		0.50	
# OF LEADS PER SIDE		10	

LEADS TINNED:

YES

☐

NO

☒

CONTROLLING UNITS:

METRIC

☐

INCHES

☒

PACKAGE TYPE:

METAL

☐

CERAMIC

☒

PLASTIC

☐

GLASS SEAL

☐

LEAD TYPE: FLAT

☒

ROUND

☐

UP 0-4°

☒

DOWN 0-4°

☐