

Figure 1 – Photo of control card

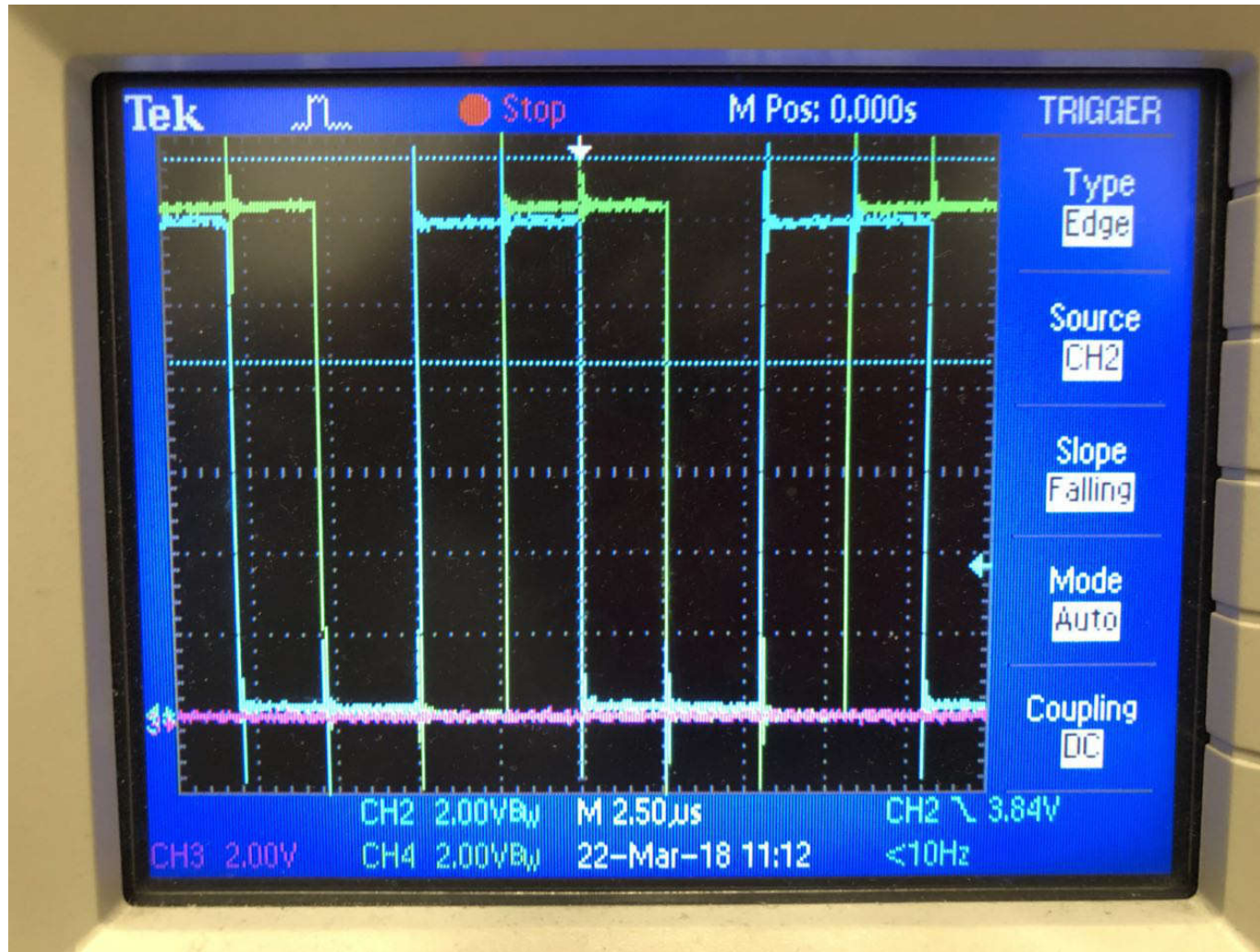


Figure 2 – PWMAmaster and PWAMA slave when control card is extracted and supplied from lab source

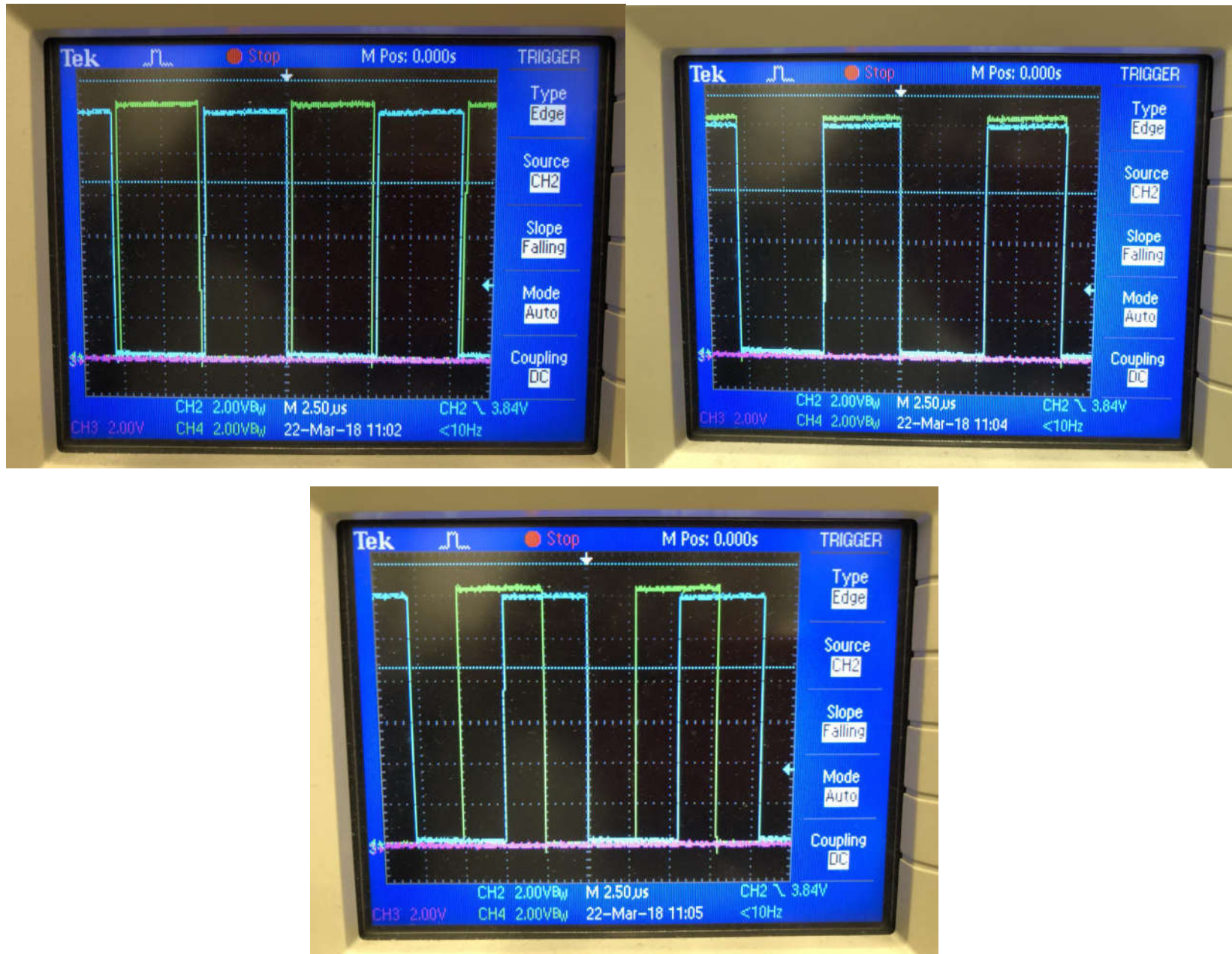


Figure 3 – PWMmaster and PWAMA slave when control card is inserted into power plate and supplied from lab source at multiple supply turn on and turn off. After supply reset shift takes one of three values: 0, 90 (the rarest case), 180 degrees