



RIGOL

STOP

H

500.00ms/

A

2.50MSa/s
Norm

25.00Mpts
400ns/pt

D

-3.88s


T

STOP
RUN

Measure

DH0924S

Waveform View(ROLL)

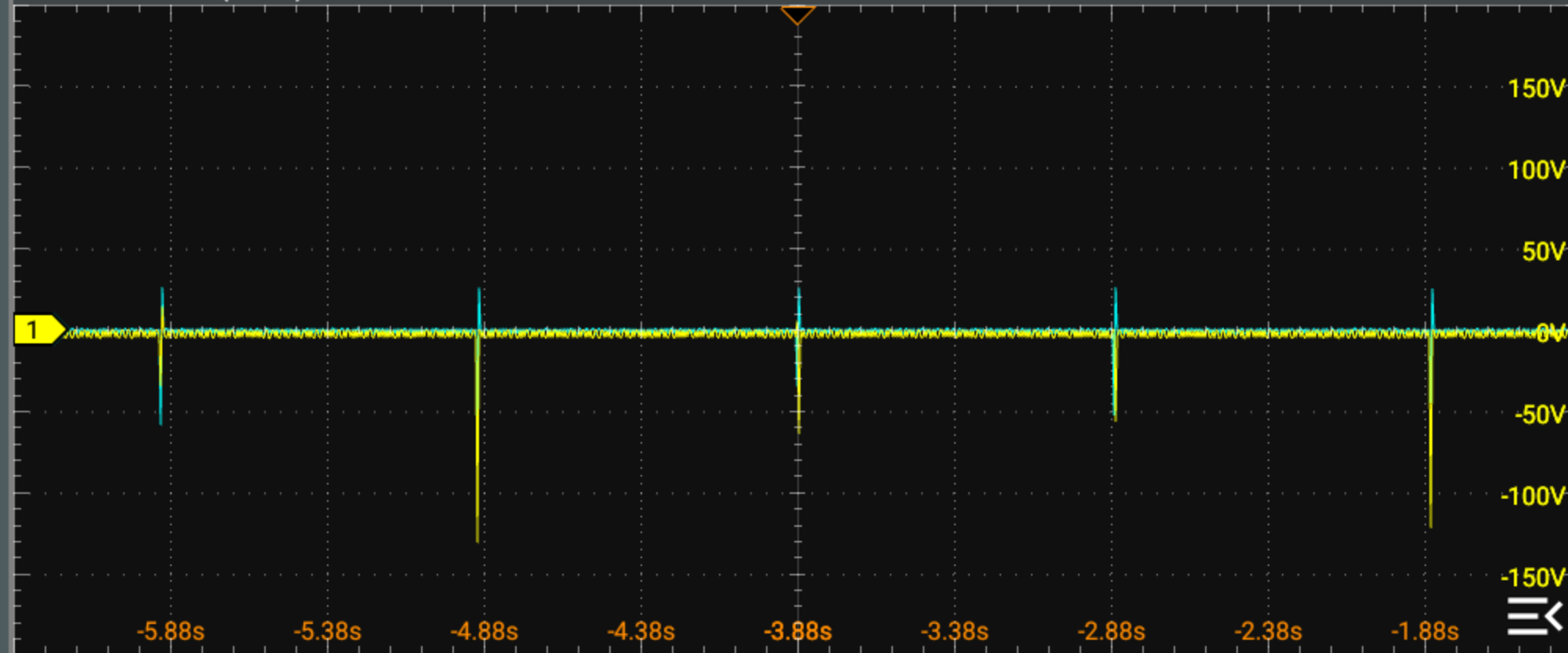

1

50.00V/
0.00V

2

1.00V/
0.00V

3

2.00V/
0.00V

4

50.00mV/
0.00V

D

0	1	2	3
4	5	6	7
8	9	10	11
12	13	14	15

G

5.00V
1.000kHz

M

M1	M3
M2	M4



RIGOL

STOP

H

500.00ms/

A

2.50MSa/s
Norm

25.00Mpts
400ns/pt

D

-3.88s


T

STOP
RUN

Measure

DH0924S

Waveform View(ROLL)

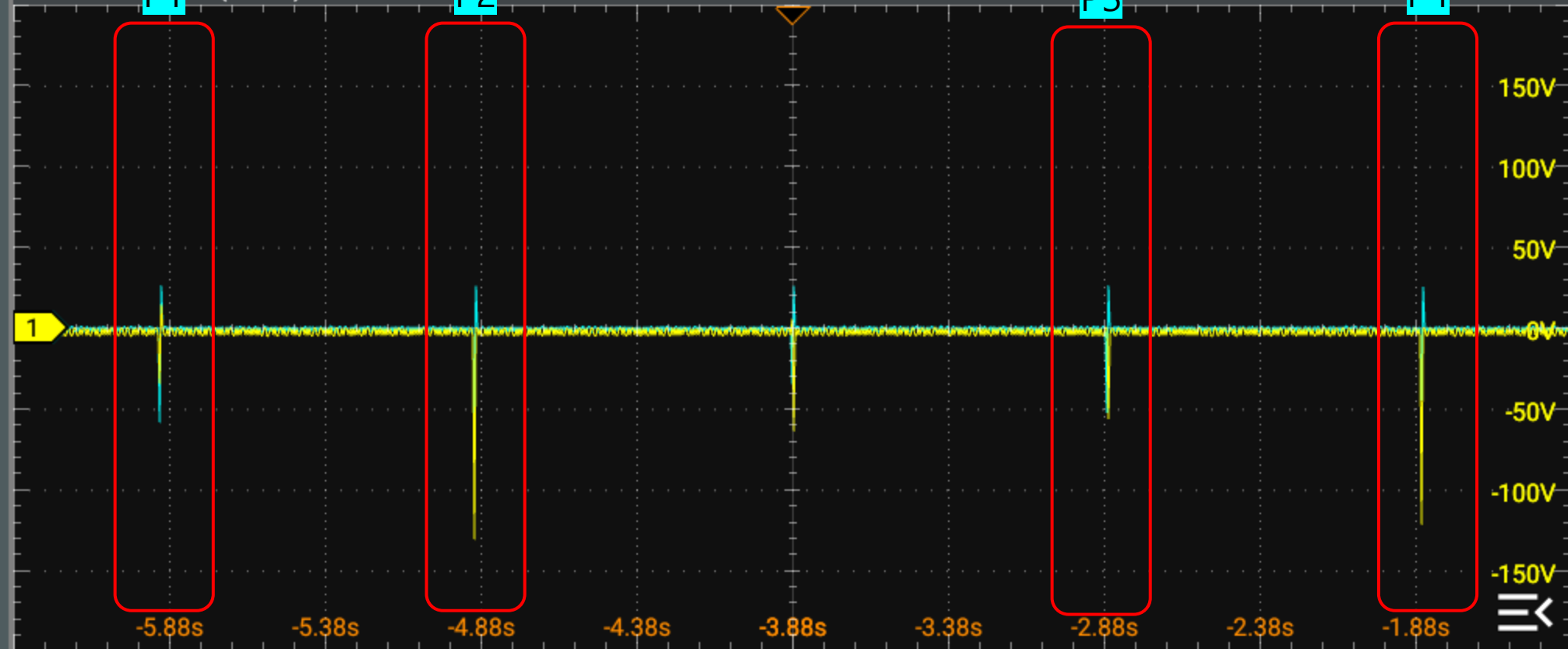

1

50.00V/
0.00V

2

1.00V/
0.00V

3

2.00V/
0.00V

4

50.00mV/
0.00V

D

0	1	2	3
4	5	6	7
8	9	10	11
12	13	14	15

G

5.00V
1.000kHz

M

M1	M3
M2	M4



P1



P2



P3



P4

