


# LM22679 Waveform comparison

Measurement points: IC\_1pin voltage  
Bad\_IC


Vin 12V  
Iout2.5A

5V/DIV  
500uS/DIV

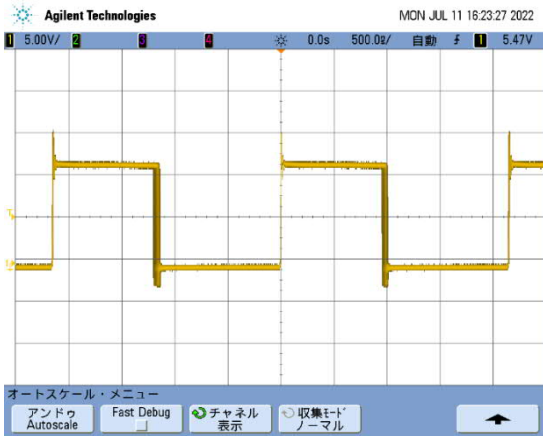


Vin 12V  
Iout3.0A

5V/DIV  
500uS/DIV

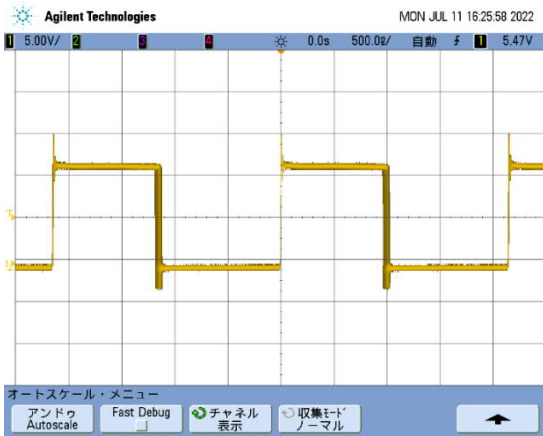

Vin 12V  
Iout2.7A (Set from 3A to 2.7A)


5V/DIV  
500uS/DIV

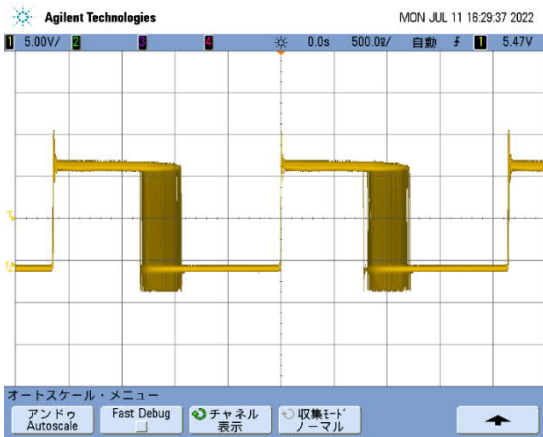

Good\_IC


Vin 12V  
Iout2.5A

5V/DIV  
500uS/DIV

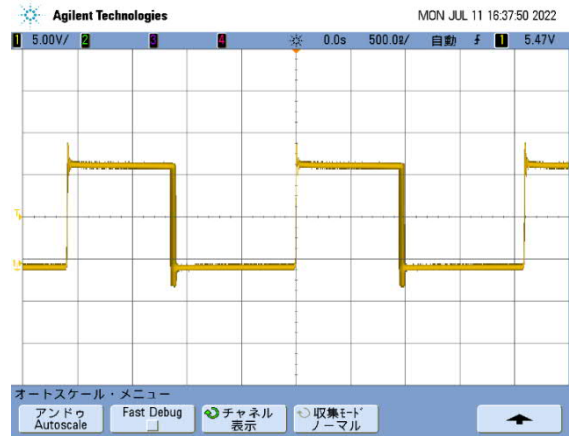

Vin 12V  
Iout3.0A

5V/DIV  
500uS/DIV

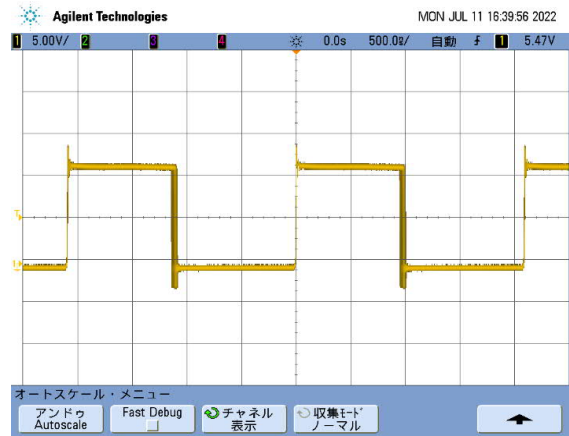

Vin 12V  
Iout2.7A (Set from 3A to 2.7A)

5V/DIV  
500uS/DIV

