


Waveforms – blue trace 12V input, 7.5V output @ 8A current.

Highside (M1) gate drive (5v/div)

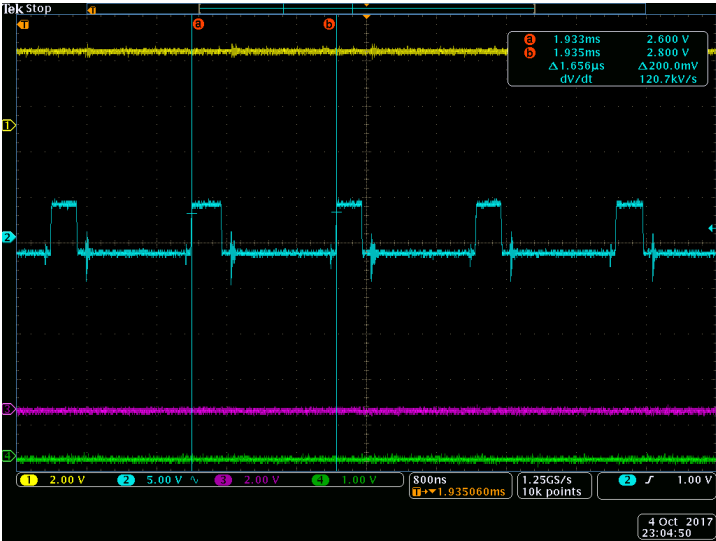

Lowside (M2) gate drive (5v/div)



Inductor input (SW node) 10V/div



Inductor output (Vout) 500mV/div

