


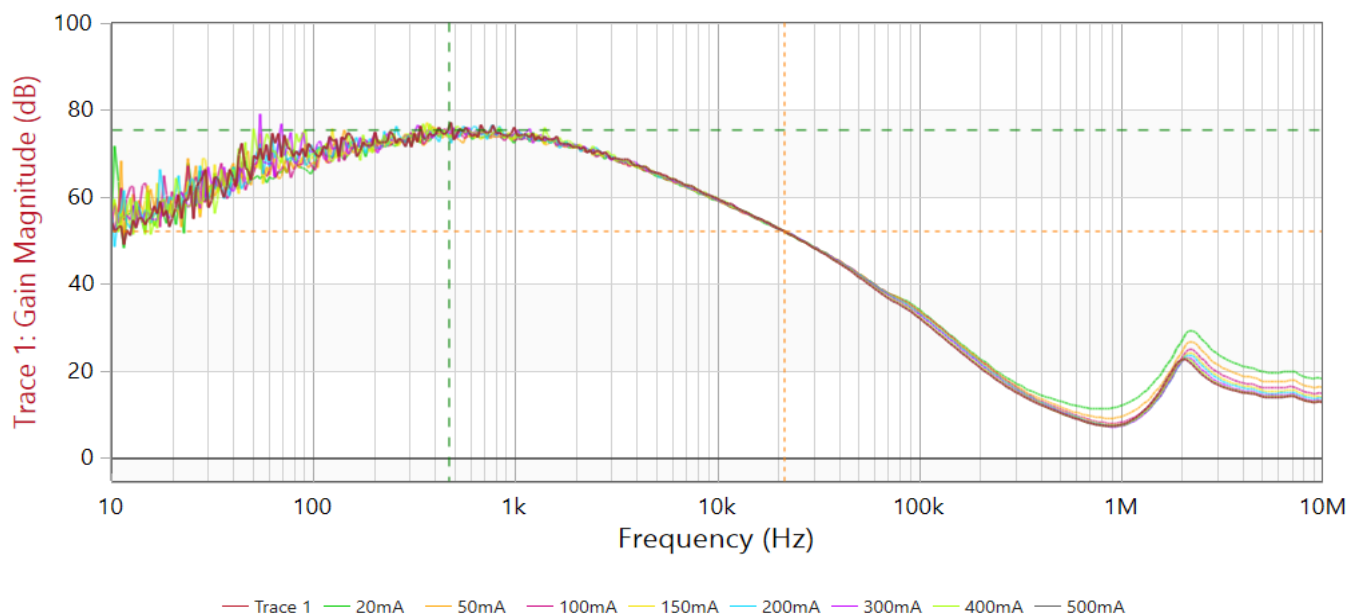

	Cursor 1	Cursor 2	Delta C2-C1
Frequency	464.159 Hz	21.544 kHz	21.08 kHz
Trace 1	Magnitude (dB)	Magnitude (dB)	Magnitude (dB)
Measurement	75.528 dB	52.232 dB	-23.297 dB

Sweep

Start frequency:	10 Hz
Stop frequency:	10 MHz
Center frequency:	5 MHz
Span:	10 MHz
Sweep mode:	Logarithmic
Numer of points:	401

Hardware setup

Device type:	Bode100R2
Serial number:	PC200H
Receiver bandwidth:	10 Hz
Output level:	40 mVpp
DUT settling time:	50 ms

Calibration

	Full-Range	User-Range
Gain	-	Active

Termination

	Channel 1	Channel 2
Gain	1 MΩ	1 MΩ

Attenuator setting

	Channel 1	Channel 2
Transmission	0 dB	0 dB